

Knockout Punch Set with Wrench

- Set includes: 1" ratcheting wrench, knockout punches, dies and draw studs for 1/2", 3/4", 1", 1-1/4", 1-1/2", and 2" conduit sizes
- Cutting capacity 10 gauge mild steel; also cuts aluminum, fiberglass and plastic
- Splits slugs for easy removal
- Punches holes cleanly and accurately
- Kit includes six different size knockout punches and dies, two draw studs and one ratcheting box end wrench



53732SEN

NOTE: Lubricate threads before each use.

Cat. No.	Set Contains	Weight																																						
53732SEN	<table border="1"> <thead> <tr> <th>Cat. No.</th> <th>Description</th> </tr> </thead> <tbody> <tr> <td colspan="2">Punch</td> </tr> <tr> <td>53819</td> <td>0.875" Knockout Punch for 1/2" Conduit</td> </tr> <tr> <td>53827</td> <td>1.115" Knockout Punch for 3/4" Conduit*</td> </tr> <tr> <td>53837</td> <td>1.362" Knockout Punch for 1" Conduit</td> </tr> <tr> <td>53849</td> <td>1.701" Knockout Punch for 1-1/4" Conduit</td> </tr> <tr> <td>53857</td> <td>1.951" Knockout Punch for 1-1/2" Conduit</td> </tr> <tr> <td>53867</td> <td>2.416" Knockout Punch for 2" Conduit</td> </tr> <tr> <td colspan="2">Die</td> </tr> <tr> <td>53820</td> <td>0.875" Knockout Die for 1/2" Conduit</td> </tr> <tr> <td>53828</td> <td>1.115" Knockout Die for 3/4" Conduit</td> </tr> <tr> <td>53838</td> <td>1.362" Knockout Die for 1" Conduit</td> </tr> <tr> <td>53850</td> <td>1.701" Knockout Die for 1-1/4" Conduit</td> </tr> <tr> <td>53858</td> <td>1.951" Knockout Die for 1-1/2" Conduit</td> </tr> <tr> <td>53868</td> <td>2.416" Knockout Die for 2" Conduit</td> </tr> <tr> <td colspan="2">Additional Items</td> </tr> <tr> <td>53873</td> <td>Ratcheting Box End Wrench, 1"</td> </tr> <tr> <td>53871</td> <td>Knockout Draw Stud 3/8" x 2-5/8"</td> </tr> <tr> <td>53872</td> <td>Knockout Draw Stud 3/4" x 4"</td> </tr> </tbody> </table>	Cat. No.	Description	Punch		53819	0.875" Knockout Punch for 1/2" Conduit	53827	1.115" Knockout Punch for 3/4" Conduit*	53837	1.362" Knockout Punch for 1" Conduit	53849	1.701" Knockout Punch for 1-1/4" Conduit	53857	1.951" Knockout Punch for 1-1/2" Conduit	53867	2.416" Knockout Punch for 2" Conduit	Die		53820	0.875" Knockout Die for 1/2" Conduit	53828	1.115" Knockout Die for 3/4" Conduit	53838	1.362" Knockout Die for 1" Conduit	53850	1.701" Knockout Die for 1-1/4" Conduit	53858	1.951" Knockout Die for 1-1/2" Conduit	53868	2.416" Knockout Die for 2" Conduit	Additional Items		53873	Ratcheting Box End Wrench, 1"	53871	Knockout Draw Stud 3/8" x 2-5/8"	53872	Knockout Draw Stud 3/4" x 4"	9.0 lb (4.1 kg)
Cat. No.	Description																																							
Punch																																								
53819	0.875" Knockout Punch for 1/2" Conduit																																							
53827	1.115" Knockout Punch for 3/4" Conduit*																																							
53837	1.362" Knockout Punch for 1" Conduit																																							
53849	1.701" Knockout Punch for 1-1/4" Conduit																																							
53857	1.951" Knockout Punch for 1-1/2" Conduit																																							
53867	2.416" Knockout Punch for 2" Conduit																																							
Die																																								
53820	0.875" Knockout Die for 1/2" Conduit																																							
53828	1.115" Knockout Die for 3/4" Conduit																																							
53838	1.362" Knockout Die for 1" Conduit																																							
53850	1.701" Knockout Die for 1-1/4" Conduit																																							
53858	1.951" Knockout Die for 1-1/2" Conduit																																							
53868	2.416" Knockout Die for 2" Conduit																																							
Additional Items																																								
53873	Ratcheting Box End Wrench, 1"																																							
53871	Knockout Draw Stud 3/8" x 2-5/8"																																							
53872	Knockout Draw Stud 3/4" x 4"																																							

PVC Cutter

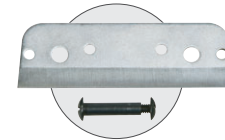
- Cuts up to 3/4" (1.9 cm) schedule 40 PVC
- Makes clean burr-free cuts in PVC and flexible pipe
- Reversible blade doubles life
- Cuts 1-3/8" (3.5 cm) outer diameter flexible plastic pipe
- Steel construction for strength
- Handle latch keeps tool closed



GUIDE HELPS CUT PIPE SQUARELY



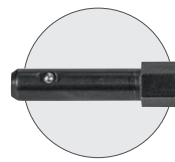
50506SEN

REPLACEMENT BLADES
50549

Cat. No.	PVC Cutting Capacity	Non-metallic Tubing Cutting Capacity	Overall Length
50506SEN	Up to 3/4" (1.9 cm) Schedule 40	1" (2.5 cm) Non-Metallic Tubing Cutting, 1-3/8" (3.5 cm) Flexible Pipe Cutting	8.5" (21.6 cm)

Ratcheting PVC Cutters

- Provide straight cuts 1/2"-2" I.D. (1.3 cm-5.1 cm) O.D. 5/8" - 2-1/2" (1.6 cm-6.4 cm) of white and gray schedule 40 and 80 PVC
- Quick, one-handed blade release
- Ratchet action allows easy, one-hand cutting
- No tools required for instant blade change
- Replacement blade and pin available

REPLACEMENT BLADE FOR 50034
50035REPLACEMENT BLADE FOR 50031
50032REPLACEMENT RETAINING PIN
50033

50031

Cat. No.	PVC Cutting Capacity	Overall Length
50031	O.D. 5/8" to 1-5/8" (1.6 to 4.1 cm); I.D. 1/2" to 1-1/4" (1.3 to 3.2 cm)	9" (22.9 cm)
50034	O.D. 5/8" to 2-1/2" (1.6 to 6.4 cm); I.D. 1/2" to 2" (1.3 to 5.1 cm)	11" (27.9 cm)

⚠ WARNING: Do NOT cut cold PVC.

⚠ WARNING: Do NOT use to cut metallic pipes, cable or wire.