

TRACK HEADS & ADAPTERS

	Product Number	Finish	CCT	Delivered Lumens	CRI	Wattage	Beam Spread	Accessories	Page Number
A-LINE TRACK FIXTURES	ATF7134	Black, White	30 K	Up to 2295 lm	80+, 90	34W	19, 23, 38		-
	ATF7233-30	Black, White	30 K	Up to 2400 lm	80	30W		Louver	28
	ATF7266-30	Black, White	30 K	Up to 4800 lm	80+	60W		Louver	29
	ATF7415	Black, White	30 K, 35 K, 40 K, Dim-to-Warm	Up to 1400 lm	80+, 90	15W	15, 20, 38, 60	Snoot, Honeycomb Louver	20
	ATF7425	Black, White, Silver	30 K, 35 K, 40 K	Up to 2375 lm	80+	25W	15, 25, 38	Snoot, Honeycomb Louver	21
	ATF7509	Black, White, Silver	30 K, 40 K, Dim-to-Warm	Up to 680 lm	80+	8.5W	15, 38, 60		22
	ATF7545	Black, White	30 K, 35 K	Up to 4428 lm	80+	45W	15, 38		23
	Flight Series™ ATF7610	Black, White, Silver	30 K, Dim-to-Warm	Up to 640 lm	90	10W	6, 25, 40, 60		14
	ATF7630	Black, White, Silver	30 K, 35 K	Up to 2200 lm	90	30W	20, 29, 35		19
	FOCUS Series™ AFT8010/20/30/40	Black, White, Silver	27 K, 35 K	Up to 3000 lm	90	10W/ 20W/ 30W/ 40W	18-50° adjustable dial		24
	TEARDROP Series™ ATF8514/22/36	Black, White, Silver	27 K, 30 K, 35 K, 40 K, 50 K	Up to 3180lm	90+	14W/ 22W/ 36W	15, 25, 40, 60	Barn Door, Honeycomb Louver, Snoot, Oval Snoot	16
	Dines Series LED SP-DNG	Black, White	Dim-to-Warm, 30 K	Up to 900 lm	90+	16W	25, 35, 40	1", 2", & 4" Snoot	10
	Flex Series 15/22/38	Black, White, Silver	27 K, 30 K, 35 K, 40 K	Up to 4200 lm	90+	15W/ 22W/ 38W	15, 25, 40, 60	Barn Door, Honeycomb Louver, Snoot, Oval Snoot, Extender, Linear Spread Lens, Softening Lens	6
LITELINE TRACK FIXTURES	APOLLO AO1008	Black, White, Silver	27 K, 30 K	Up to 605 lm	90	8W	38		12
	DELTA DA2010	Black, White, Silver	27 K, 30 K, 40 K	Up to 1000 lm	80+, 90	10W	38		13
	SORA SO1008	Black, White, Silver	27 K, 30 K	Up to 611 lm	90	8W	38		13
	VEGA VA6510	Black, White, Brushed Nickel	30 K	Up to 680 lm	80+	10W	25		-

CUSTOMIZE CONNECTOR STYLES



A-Line

Compatible with A-Line, Juno or Contech



Liteline

Compatible with Liteline



H style

Compatible with Halo, WAC or Hampton Bay



L style

Compatible with Lightolier



C style

Compatible with Capri



P2

2-Circuit compatible with Powergear and Global Trac



P3

3-Circuit compatible with Powergear and Global Trac

For other track compatibility, please contact your local rep.

TRACK



LITELINE

Light Residential

 
Single Circuit 120V

TRACK LENGTHS

Field Cuttable




FINISH



Ordering Guide

Length	Finish
TK60	
02 : 2'	WH : White
04 : 4'	BK : Black
06 : 6'	SL : Silver
08 : 8'	BN : Brushed Nickel
12 : 12''	

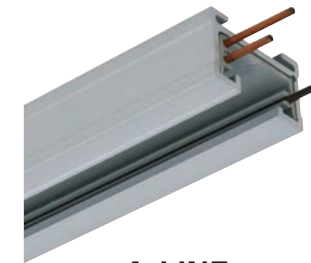

A-LINE

Residential / Commercial

 
Single / 2 Circuit 120V

TRACK LENGTHS

Field Cuttable



FINISH



Ordering Guide

Length	Circuits	Finish
ATK		
02 : 2'	Blank : 1 Circuit	WH : White
04 : 4'	2C : 2 Circuit	BK : Black
06 : 6'		SL : Silver ²
08 : 8'		BN : Brushed Nickel ³
12 : 12''		

Notes:

¹ 2 Circuit track not available in 12'. ² Silver finish only available with 2 Circuit track. ³ Brushed Nickel finish only available with 1 Circuit track.



POWERGEAR

Commercial

2 Circuit / 2 Neutral
3 Circuit / 1 Neutral

TRACK LENGTHS

Field Cuttable



FINISH



Ordering Guide

Length	Finish
PRO-04-	
04 : 4'	WH : White
06 : 6'	BK : Black
08 : 8'	
12 : 12'	

POWERGEARTRACK.COM

INFO@POWERGEARTRACK.COM

ADD RIGIDITY

Provide strength to track with A-Beam and H-Channel. Ideal for commercial applications including retail and hospitality, these rigid lighting channels require fewer suspension points allowing for a cleaner ceiling space.



A-LINE
A-BEAM

COMMERCIAL

Single / 2 Circuit 120V

FEATURES

- Ability to add up-lighting for design flexibility

TRACK LENGTHS

Not Field Cuttable




FINISH



Ordering Guide	
Length	Finish
A-BEAM122	
2 : 2-feet	WH : White
4 : 4-feet	BK : Black
6 : 6-feet	
8 : 8-feet	
12 : 12-feet	

Highlighted option denotes quick ship.

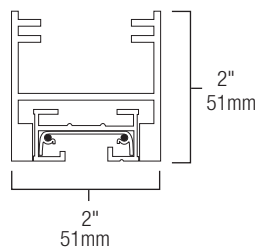

POWERGEAR
H-CHANNEL

COMMERCIAL

FEATURES

- 12 ft spacing between suspension points
- Integrate track into store fixtures in retail environment

TRACK LENGTHS

 
Field Cuttable



FINISH




MOUNTING



Ordering Guide

Length	Finish
PRO-H00	
04 : 4'	WH : White
06 : 6'	BK : Black
08 : 8'	
12 : 12'	

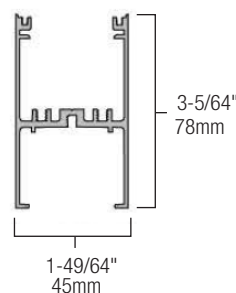

PRECISIONPRO TRIMLESS MADE EASY

A-Line and Powergear track can be trimless with the use of PrecisionPro pre-formed recessed drywall channel. PrecisionPro installs like any other drywall and then the track simply surface mounts into the channel and corner pieces, avoiding the headaches of traditional recessed track systems. PrecisionPro comes standard with a wood backing, or upgrade to a steel backing for added support. Upon order 2 pieces are packed together to ensure the drywall ships safely to the job site.

- ✓ Reduce intensive labor & costs
- ✓ Sleek finish with minimal effort
- ✓ Level 5 finish


LENGTHS




THICKNESS




Double 5/8"
Fire Rated

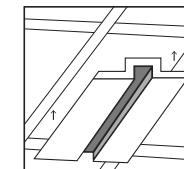

1. Install Recessed Track Kit into building's frame

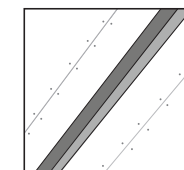

2. Tape and mud edges to complete

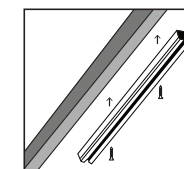

3. Install track as surface mount



A-Line's PrecisionPro drywall program is the only solution to have trimless, **fire-rated** track!


TRACK SYSTEMS

GUIDE

- A-line 1-Circuit ● Powergear 2-Circuit / 2 Neutral
- A-line 2-Circuit ● Powergear 3-Circuit / 1 Neutral

	Description	Liteline	A-Line	Powergear
A	Live-end Connector	LE6110	ATKP09 ATKP09-2C	PRO-2431(L/R)* PRO-0431(L/R)*
	Live End Conduit Feed	CA6106	ATKP06 ATKP06-2C	
B	"T" Connector	TC6103	ATKP03 ATKC03-2C	PRO-2436(L/R)(1/2)* PRO-0436(L/R)(1/2)*
C	Middle Connector	IC6101	ATKC01 ATKC01-2C	PRO-2433 PRO-0433 PRO-0433(A)* PRO-0433(A)*
D	"L" Connector	LC6102	ATKP02 ATKC02-2C	PRO-2435(L/R)* PRO-0435(L/R)* PRO-M435 PRO-M435
E	Flexible "L" Connector	FC6105	ATKC05	PRO-2439 PRO-0439
F	"X" Connector	XC6104	ATKP04-2C	PRO-2437 PRO-0437
H	End Cap	TK6000-END	ATK0-ENDCAP-1C ATK0-ENDCAP-2C	PRO-2432 PRO-0432
I	Center Feed	FC6108	ATKP08 ATKP02 ATKC02-2C	PRO-2434 PRO-0434
	Wired End	WE6110	ATKP10	
	Live End With Canopy	LE611	ATKP11 ATKP11-2C	
	Live End With Canopy For T-Bar		ATKP12-2C	
	Monopoint		ATKP109	
	Hollow Stem Suspension Rod	LL-ATKXW	ATKXW	
	Stem Rod Kit With Hollow Rod	TDR62	A-TDR62	
	Track Hook / Track Receptacle		ATKA320/ ATKA321	

TRACK SYSTEM DIAGRAM

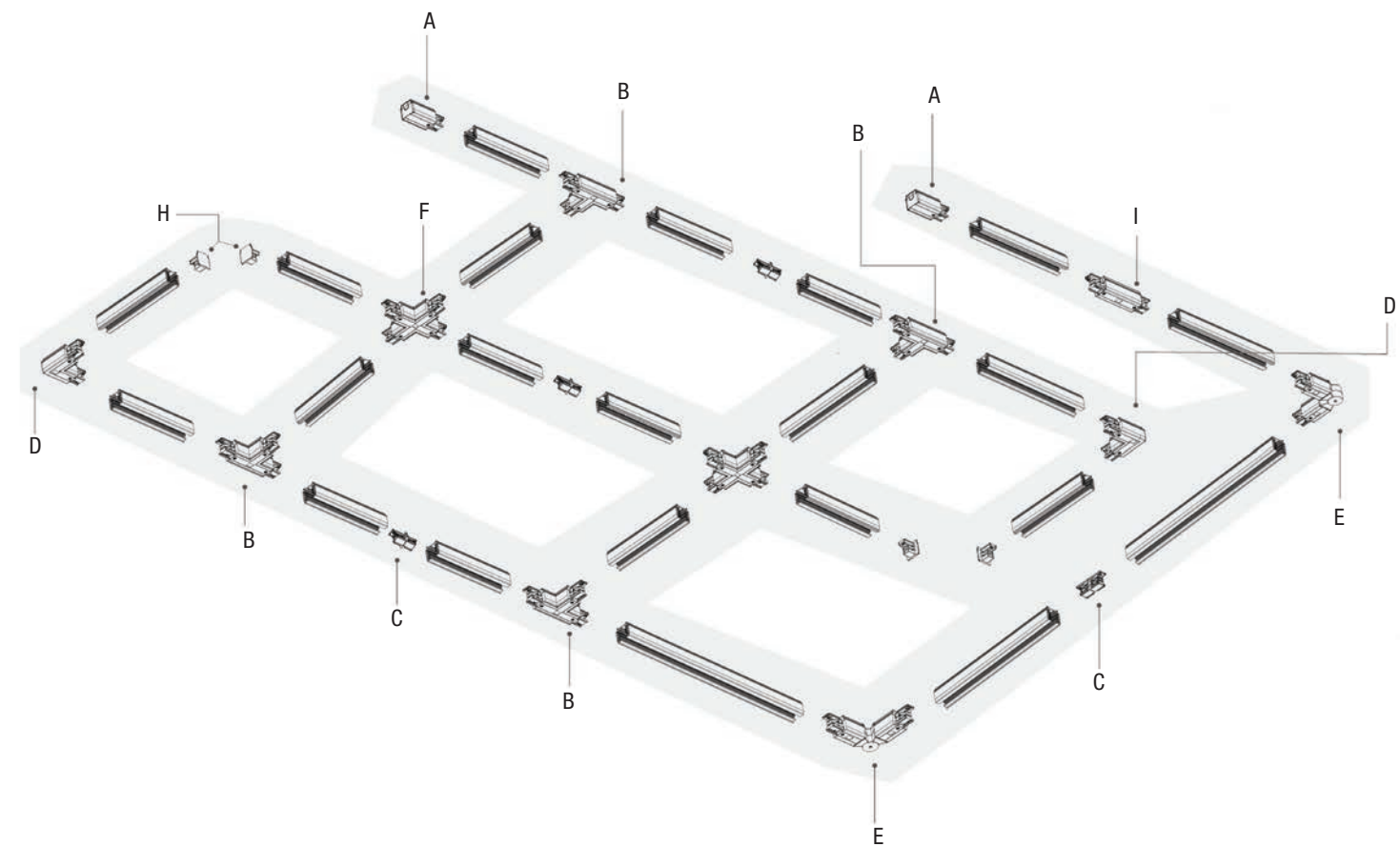

A-LINE CURRENT LIMITERS

-  **ATKPCL-06-1C**
Single circuit live end narrow current limiter
-  **ATKPCL-09-1C**
ATKPCL-09-2C
Single/two circuit dual live end canopy with current limiter
-  **ATKPCL-11-1C**
ATKPCL-11-2C
Single/two circuit live end canopy current limiter
-  **ATKP11T-2C**
Two circuit live end power feed with canopy cover for t-bar

