

M18™ FORCE LOGIC™ 6T Utility Crimper Kits



w/ BG-D3 Jaw
2678-22BG
(2678-20 Tool-Only)



w/ O-D3 Jaw
2678-22O
(2678-20 Tool-Only)



w/ Snub Nose Jaw
2678-22
(2678-20 Tool-Only)



w/ Kearney Jaw
2678-22K
(2678-20 Tool-Only)

Specifications:

Output Force	6 Tons
Adaptive Pressure Control System	Yes; PFM™
Reporting and Tool Diagnostics	Built-In; ONE-KEY™ Compatible
Cycle Time	2.9 Seconds
Head Rotation	340°
Height / Length	5.4" / 14.0"

Includes: 2678-22BG 6T Fixed BG Crimping Jaw; 2678-22O 6T Fixed O Crimping Jaw; 2678-22 6T Snub Nose Crimping Jaw; 2678-22K 6T Kearney Crimping Jaw; **All Kits Include:** (2) M18™ REDLITHIUM™ CP2.0 Battery Packs, Multi-Voltage Charger, Utility Bag

M18™ FORCE LOGIC™ 6T Pistol Utility Crimper Kits



w/ BG-D3 Jaw
2977-22BG
(2977-20 Tool-Only)



w/ O-D3 Jaw
2977-22O
(2977-20 Tool-Only)

Specifications:

Output Force	6 Tons
Adaptive Pressure Control System	Yes; PFM™
Reporting and Tool Diagnostics	Built-In; ONE-KEY™ Compatible
Cycle Time	2.9 Seconds
Head Rotation	340°
Height / Length	12.3" / 17.3"

Includes: 2977-22BG 6T Fixed BG Crimping Jaw; 2977-22O 6T Fixed O Crimping Jaw; **All Kits Include:** (2) M18™ REDLITHIUM™ CP2.0 Battery Packs, Multi-Voltage Charger, Utility Bag



M18™ FORCE LOGIC™ 6T Utility Crimper Accessories

Compatible with 2678-20, 2977-20, 2978-20

6T Utility Crimper Jaws

- 49-16-BGD3 6T Fixed BG Crimping Jaw
- 49-16-10D3 6T Fixed O Crimping Jaw
- 49-16-11D3 6T Snub Nose Crimping Jaw
- 49-16-KEAR 6T Kearney Crimping Jaw

Cutter Jaws

Also Compatible with 2672-21, 2672-21S, and 2672-21F

- 49-16-2772 750 MCM Cu/Al Cutting Jaw
- 49-16-2773 477 ACSR Cutting Jaw
- 49-16-2777 1/2" EHS Guy Wire Cutting Jaw
- 49-16-2778 Fine-Stranded Wire Cutting Jaw

Cutter Replacement Blades

- 48-44-0411 Replacement Copper Blades
- 48-44-0412 Replacement Steel Blades
- 48-44-2777 1/2" EHS Guy Wire Replacement Blades
- 48-44-2778 Fine-Stranded Wire Replacement Blades

W Style Dies

- 49-16-WBG0 W Style Die: "W-BG"
- 49-16-WO00 W Style Die: "W-O"
- 49-16-WC00 W Style Die: "W-C"
- 49-16-W161 W Style Die: "W-161"
- 49-16-W162 W Style Die: "W-162"
- 49-16-W163 W Style Die: "W-163"
- 49-16-W164 W Style Die: "W-164"
- 49-16-W165 W Style Die: "W-165"
- 49-16-W166 W Style Die: "W-166"
- 49-16-W237 W Style Die: "W-237"
- 49-16-W239 W Style Die: "W-239"
- 49-16-W243 W Style Die: "W-243"
- 49-16-W247 W Style Die: "W-247"
- 49-16-W249 W Style Die: "W-249"
- 49-16-W840 W Style Die: "W-K840"

M18™ FORCE LOGIC™ 600 MCM Crimper Kit

2679-22, 2679-750C, 2679-750A, 2679-350A, 2679-600C



Specifications:

Output Force	6 Tons
Adaptive Pressure Control System	Yes; PFM™
Reporting and Tool Diagnostics	Built-In; ONE-KEY™ Compatible
Cycle Time	2.9 Seconds
Head Rotation	350°
Height / Length	5.4" / 13.3"

Includes: 2679-750C 750 MCM Cu/Al Crimping Jaw, All Copper U Style Dies (49-16-KITC Die Kit and 49-16-750C Die Kit); 2679-750A 750 MCM Cu/Al Crimping Jaw, All Aluminum U Style Dies (49-16-KITA Die Kit and 49-16-750A Die Kit); 2679-350A 49-16-KITA Die Kit; **All Kits Include:** 2679-22 600 MCM Commercial U Crimping Jaw, (2) M18™ REDLITHIUM™ CP2.0 Battery Packs, Multi-Voltage Charger, Carrying Case

FORCE LOGIC™ 600 MCM Crimper Accessories

Compatible with 2679-22, 2679-750C, 2679-750A, 2679-350A, 2679-600C

Related Accessories:

- 49-16-U000 600 MCM Crimping Jaw
- 49-16-U111 750 MCM Cu/Al Cable Crimping Jaw
- 49-16-2780 750 MCM Cu/Al Cable Cutting Jaw

Cutter Replacement Blades

- 48-44-0411 750 MCM Cu/Al Cable Cutting Blades

Accessory Kits

- 49-16-KITA #8 AWG – 350 MCM Aluminum U Style Die Kit
- 49-16-750A 400 – 750 MCM Aluminum U Style Die & Jaw Kit
- 49-16-KITC #8 AWG – 600 MCM Copper U Style Die Kit
- 49-16-750C 750 MCM Copper U Style Die & Jaw Kit

Copper U Style Dies

- 49-16-U001C #1 Copper U Style Die
- 49-16-U002C #2 Copper U Style Die
- 49-16-U004C #4 Copper U Style Die
- 49-16-U006C #6 Copper U Style Die
- 49-16-U008C #8 Copper U Style Die
- 49-16-U01AC 1/0 Copper U Style Die
- 49-16-U02AC 2/0 Copper U Style Die
- 49-16-U03AC 3/0 Copper U Style Die
- 49-16-U04AC 4/0 Copper U Style Die
- 49-16-U250C 250 MCM Copper U Style Die
- 49-16-U300C 300 MCM Copper U Style Die
- 49-16-U350C 350 MCM Copper U Style Die
- 49-16-U400C 400 MCM Copper U Style Die
- 49-16-U500C 500 MCM Copper U Style Die
- 49-16-U600C 600 MCM Copper U Style Die
- 49-16-U750C 750 MCM Copper U Style Die

Aluminum Dual-Rated U Style Dies

- 49-16-U001 #1 Aluminum U Style Die
- 49-16-U002 #2 Aluminum U Style Die
- 49-16-U004 #4 Aluminum U Style Die
- 49-16-U006 #6 Aluminum U Style Die
- 49-16-U008 #8 Aluminum U Style Die
- 49-16-U01A 1/0 Aluminum U Style Die
- 49-16-U02A 2/0 Aluminum U Style Die
- 49-16-U03A 3/0 Aluminum U Style Die
- 49-16-U04A 4/0 Aluminum U Style Die
- 49-16-U250 250 MCM Aluminum U Style Die
- 49-16-U300 300 MCM Aluminum U Style Die
- 49-16-U350 350 MCM Aluminum U Style Die
- 49-16-U400 400 MCM Aluminum U Style Die
- 49-16-U500 500 MCM Aluminum U Style Die
- 49-16-U600 600 MCM Aluminum U Style Die
- 49-16-U750 750 MCM Aluminum U Style Die

M18™ FORCE LOGIC™ 750 MCM Dieless Crimper Kit



2877-22

Specifications:

Crimping Capacity	#6 – 750 MCM Cu & Al
Adaptive Distance Control	Yes; Auto Distance Control
Reporting and Tool Diagnostics	Built-In; ONE-KEY™ Compatible
Dimensions (L x W x H)	18.9" x 3.3" x 6.5"
Weight	9.0 lbs

Includes: (2) M18™ REDLITHIUM™ CP2.0 Battery Packs, Multi-Voltage Charger, Carrying Case




M18™ FORCE LOGIC™ 12T Utility Crimper Kit

2778-22 (2778-20 Tool-Only)

Specifications:

Output Force	12 Tons
Head Rotation	350°
Reporting and Tool Diagnostics	Built-In; ONE-KEY™ Compatible
Length / Weight	16.0" / 11.9 lbs

Includes: (1) M18™ REDLITHIUM™ XC5.0 Battery Pack, (1) M18™ REDLITHIUM™ CP2.0 Battery Pack, Carabiner, Multi-Voltage Charger and Inverter, Utility Bag

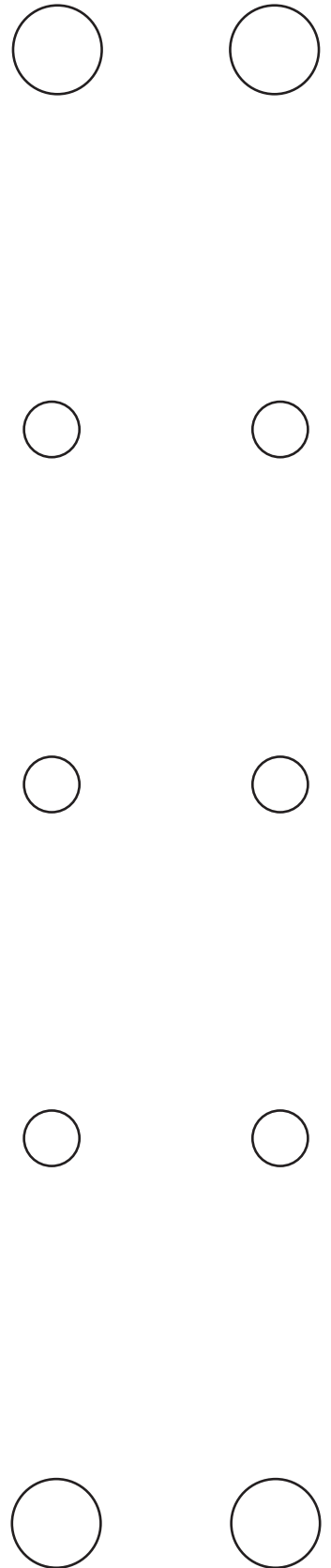



M18™ FORCE LOGIC™ 750 MCM Crimper Kit

2779-22, 2779-750A, 2779-750C

Specifications:

Output Force	12 Tons
Head Rotation	350°
Reporting and Tool Diagnostics	Built-In; ONE-KEY™ Compatible
Length / Weight	16.0" / 11.5 lbs

Includes: 2779-750A 49-12-KITA; 2779-750C 49-12-KITC; **All Kits Include:** 2779-22 (1) M18™ REDLITHIUM™ XC5.0 Battery Pack, (1) M18™ REDLITHIUM™ CP2.0 Battery Pack, Multi-Voltage Charger, Carrying Case

Related Accessories: Accessory Kits

- 49-12-KITC EXACT™ #6 AWG – 750 MCM Cu 12T U Style Die Kit
- 49-12-KITA EXACT™ #6 AWG – 750 MCM Al 12T U Style Die Kit

EXACT™ 12T Copper U Style Dies

- 49-12-U001C #1 Copper 12T U Style Die
- 49-12-U002C #2 Copper 12T U Style Die
- 49-12-U004C #4 Copper 12T U Style Die
- 49-12-U006C #6 Copper 12T U Style Die
- 49-12-U008C #8 Copper 12T U Style Die
- 49-12-U01AC 1/0 Copper 12T U Style Die
- 49-12-U02AC 2/0 Copper 12T U Style Die
- 49-12-U03AC 3/0 Copper 12T U Style Die
- 49-12-U04AC 4/0 Copper 12T U Style Die
- 49-12-U250C 250 MCM Copper 12T U Style Die
- 49-12-U300C 300 MCM Copper 12T U Style Die
- 49-12-U350C 350 MCM Copper 12T U Style Die
- 49-12-U400C 400 MCM Copper 12T U Style Die
- 49-12-U500C 500 MCM Copper 12T U Style Die
- 49-12-U600C 600 MCM Copper 12T U Style Die
- 49-12-U750C 750 MCM Copper 12T U Style Die

EXACT™ 12T Aluminum U Style Dies

- 49-12-U001 #1 Aluminum 12T U Style Die
- 49-12-U002 #2 Aluminum 12T U Style Die
- 49-12-U004 #4 Aluminum 12T U Style Die
- 49-12-U006 #6 Aluminum 12T U Style Die
- 49-12-U008 #8 Aluminum 12T U Style Die
- 49-12-U01A 1/0 Aluminum 12T U Style Die
- 49-12-U02A 2/0 Aluminum 12T U Style Die
- 49-12-U03A 3/0 Aluminum 12T U Style Die
- 49-12-U04A 4/0 Aluminum 12T U Style Die
- 49-12-U250 250 MCM Aluminum 12T U Style Die
- 49-12-U300 300 MCM Aluminum 12T U Style Die
- 49-12-U350 350 MCM Aluminum 12T U Style Die
- 49-12-U400 400 MCM Aluminum 12T U Style Die
- 49-12-U500 500 MCM Aluminum 12T U Style Die
- 49-12-U600 600 MCM Aluminum 12T U Style Die
- 49-12-U750 750 MCM Aluminum 12T U Style Die

M18™ FORCE LOGIC™ 15T Crimper Kit

2879-22 (2879-20 Tool-Only)

Specifications:

Crimping Capacity	#8 – 1500 MCM Cu, #8 – 1250 MCM Al
Output Force	15 Tons
Adaptive Pressure Control	Yes; PFM™
Reporting and Tool Diagnostics	Built-In; ONE-KEY™ Compatible
Dimensions (L x W x H)	23.3" x 3.1" x 5.5"
Weight	16.1 lbs

Includes: (1) M18™ REDLITHIUM™ XC5.0 Battery Pack, (1) M18™ REDLITHIUM™ CP2.0 Battery Pack, P-to-U Die Adapter, Carabiner, Multi-Voltage Charger, Contractor Bag

Related Accessories:

- 49-15-PUAD P-to-U Die Adapter
- 49-15-P750 15T 750 MCM Al P-Die
- 49-15-P800 15T 800 MCM Al P-Die
- 49-15-P000 15T 1000 MCM Al P-Die
- 49-15-P750C 15T 750 MCM Cu P-Die
- 49-15-P800C 15T 800 MCM Cu P-Die
- 49-15-P000C 15T 1000 MCM Cu P-Die



M18™ FORCE LOGIC™ 10,000 PSI Hydraulic Pump Kit

2674-21HD (2674-20 Tool-Only)

Specifications:

Operating Pressure	10,000 psi / 700 bar
Usable Oil Capacity	1.4 qts
Flow Rate at Low Pressure	125.0 in³/min
Flow Rate at High Pressure	25.6 in³/min
Ingress Protection	IP54
Dimensions (L x W x H)	15.8" x 11.5" x 13.9"
Weight	29.7 lbs

Includes: (1) M18™ REDLITHIUM™ HIGH OUTPUT™ HD12.0 Battery Pack, Rapid Charger

Related Accessories:

- 49-12-2776 Bucket Hanger
- 49-12-2775 6' Controller Extension



M18™ FORCE LOGIC™ Cable Cutter Kit w/ 750 MCM Cu Jaws

2672-21

Specifications:

Cut Capacity	750 MCM Cu, 1000 MCM Al
Average Cut Speed	3 Seconds
Head Rotation	350°
Auto Reset	Yes
Tool Diagnostics	Built-In; ONE-KEY™ Compatible
Height / Length	5.4" / 14.0"

Includes: (1) M18™ REDLITHIUM™ CP2.0 Battery Pack, 750 MCM Cable Cutter Jaw, Allen Wrench, Multi-Voltage Charger, Carrying Case

M18™ FORCE LOGIC™ Cable Cutter Kit w/ 477 ACSR Jaws

2672-21S

Specifications:

Cut Capacity	477 HEN ACSR
Average Cut Speed	3 Seconds
Head Rotation	350°
Auto Reset	Yes
Tool Diagnostics	Built-In; ONE-KEY™ Compatible
Height / Length	5.4" / 14.0"

Includes: (1) M18™ REDLITHIUM™ CP2.0 Battery Pack, 477 ACSR Cutting Jaw, Carabiner, Allen Wrench, Multi-Voltage Charger and Inverter, Bucket Bag

M18™ FORCE LOGIC™ Cable Cutter Kit w/ Fine-Stranded Wire Jaws

2672-21F

Specifications:

Cut Capacity	777.7 MCM Fine-Stranded Wire
Average Cut Speed	3 Seconds
Head Rotation	350°
Auto Reset	Yes
Tool Diagnostics	Built-In; ONE-KEY™ Compatible
Height / Length	5.4" / 14.0"

Includes: (1) M18™ REDLITHIUM™ CP2.0 Battery Pack, Fine-Stranded Wire Cutting Jaw, Allen Wrench, Multi-Voltage Charger, Carrying Case

M18™ FORCE LOGIC™ Cable Cutter Accessories

Compatible with 2672-21, 2672-21S and 2672-21F

Cutter Jaws

- 49-16-2772 750 MCM Cu/Al Cutting Jaw
- 49-16-2773 477 ACSR Cutting Jaw
- 49-16-2777 1/2" EHS Guy Wire Cutting Jaw
- 49-16-2778 Fine-Stranded Wire Cutting Jaw

Cutter Replacement Blades

- 48-44-0411 Copper Replacement Blades
- 48-44-0412 ACSR Replacement Blades
- 48-44-2777 1/2" EHS Guy Wire Replacement Blades
- 48-44-2778 Fine-Stranded Wire Replacement Blades



M18™ FORCE LOGIC™ 3" Underground Cable Cutter Kit w/ Wireless Remote

2776R-21

Specifications:

Cut Capacity	1500 MCM Cu 15kV
Tool Diagnostics	Built-In; ONE-KEY™ Compatible
Height / Length	12.4" / 20.8"
Weight	15.8 lbs

Includes: (1) M18™ REDLITHIUM™ XC5.0 Battery Pack, Remote, Carabiner, Multi-Voltage Charger and Inverter, Utility Bag

Related Accessory:

- 49-16-2774 3" Underground Replacement Blades

M18™ FORCE LOGIC™ 3" Underground Cable Cutter Kit

2776-21

Specifications:

Cut Capacity	1500 MCM Cu 15kV
Tool Diagnostics	Built-In; ONE-KEY™ Compatible
Height / Length	12.4" / 20.8"
Weight	15.8 lbs

Includes: (1) M18™ REDLITHIUM™ XC5.0 Battery Pack, Carabiner, Multi-Voltage Charger and Inverter, Utility Bag

Related Accessory:

- 49-16-2774 3" Underground Replacement Blades

M18™ FORCE LOGIC™ 1590 ACSR Cutter Kit

2777-21

Specifications:

Cut Capacity	Up to 1590 Falcon ACSR
Tool Diagnostics	Built-In; ONE-KEY™ Compatible
Height / Length	10.6" / 16.8"
Weight	11.8 lbs

Includes: (1) M18™ REDLITHIUM™ XC5.0 Battery Pack, Carabiner, Side Handle, Multi-Voltage Charger and Inverter, Utility Bag

Related Accessory:

- 49-16-2775 1590 ACSR Replacement Blades

M18 FUEL
16" Chainsaw Kit

2727-21HD (2727-20 Tool-Only)

Specifications:

Bar Length	16"
Chain Gauge	.043"
Chain Pitch	3/8" Low Profile
RPM	6,600
Length / Weight	33.0" / 13.9 lbs



Includes: (1) M18™ REDLITHIUM™ HIGH OUTPUT™ HD12.0 Battery Pack, 16" Oregon® Bar and Chain, Srench, Scabbard, Rapid Charger



M18 FUEL
14" Chainsaw

2727-20C Tool-Only

Specifications:

Bar Length	14"
Chain Gauge	.043"
Chain Pitch	3/8" Low Profile
RPM	6,600
Length / Weight	31.0" / 10.4 lbs



Battery and Charger Sold Separately

Includes: 14" Oregon® Bar and Chain, Srench, Scabbard

M18 FUEL
Pole Saw Kit w/ QUIK-LOK™

2825-21PS (2825-20PS Tool-Only)

Specifications:

RPM	0 – 4,600
Bar Length	10"
Chain Gauge	.043"
Chain Pitch	3/8" Low Profile
Length / Weight	84.0" / 12.7 lbs



Includes: M18 FUEL™ Power Head w/ QUIK-LOK™, M18 FUEL™ QUIK-LOK™ 10" Pole Saw Attachment, QUIK-LOK™ 3' Attachment Extension, (1) M18™ REDLITHIUM™ HIGH OUTPUT™ XC8.0 Battery Pack, Oregon® Bar and Chain, Srench, Rapid Charger

M18 FUEL
String Trimmer Kit w/ QUIK-LOK™

2825-21ST (2825-20ST Tool-Only)

Specifications:

Cutting Swath	14" – 16"
Line Diameter	.080" / .095"
RPM	0 – 4,900 / 0 – 6,200
Trigger	Variable Speed
Feed System	Bump Feed
Length / Weight	73.6" / 12.3 lbs



Includes: M18 FUEL™ Power Head w/ QUIK-LOK™, M18 FUEL™ QUIK-LOK™ String Trimmer Attachment, (1) M18™ REDLITHIUM™ HIGH OUTPUT™ XC8.0 Battery Pack, Rapid Charger



M18 FUEL
QUIK-LOK™ Attachments

Compatible with M18 FUEL™ Power Head w/ QUIK-LOK™ (2825-20)

- 49-16-2717 M18 FUEL™ String Trimmer Attachment
- 49-16-2718 M18 FUEL™ Edger Attachment
- 49-16-2719 M18 FUEL™ Articulating Hedge Trimmer Attachment
- 49-16-2720 M18 FUEL™ 10" Pole Saw Attachment
- 49-16-2721 M18 FUEL™ 3' Attachment Extension



M18™ Brushless String Trimmer Kit

2828-21 (2828-20 Tool-Only)

Specifications:

Cutting Swath	14" – 16"
Line Diameter	.080" / .095"
RPM	0 – 4,600 / 0 – 6,200
Trigger	Variable Speed
Feed System	Bump Feed
Length / Weight	73.6" / 11.5 lbs



Includes: (1) M18™ REDLITHIUM™ HIGH OUTPUT™ XC6.0 Battery Pack, Multi-Voltage Charger



M18 FUEL
Blower Kit

2724-21HD (2724-20 Tool-Only)

Specifications:

Max Air Volume	450 CFM
Max Air Speed	120 MPH
Noise Rating (db)	62 (ANSI B175)
Lock On Button	Yes
Length / Weight	36.9" / 7.3 lbs



Includes: (1) M18™ REDLITHIUM™ HIGH OUTPUT™ XC8.0 Battery Pack, Rapid Charger

M18 FUEL
24" Hedge Trimmer Kit

2726-21HD (2726-20 Tool-Only)

Specifications:

Blade Length	24"
Cut Capacity	3/4"
SPM	3,400
Gear Case	All Metal
Length / Weight	45.5" / 11.1 lbs



Includes: (1) M18™ REDLITHIUM™ HIGH OUTPUT™ XC8.0 Battery Pack, Scabbard, Rapid Charger

M18™ SWITCH TANK™ 4-Gallon Backpack Sprayer Kit

2820-21PS (2820-20PS Tool-Only)

Specifications:

Tank Capacity	4 Gallon
Pump Type	Dual Diaphragm Pump
PSI Range	20 – 120 PSI (5 Modes)
Spray Distance	Up to 25'
Flow Rate Range	0.10 – 0.51 Gal/Min
Dry Weight	18.3 lbs



Includes: M18™ SWITCH TANK™ Powered Base, SWITCH TANK™ 4 Gallon Sprayer Tank Assembly, (1) M18™ REDLITHIUM™ XC3.0 Battery Pack, Adjustable Nozzle, Fan Nozzle, Multi-Voltage Charger

Related Accessories:
49-16-28WS SWITCH TANK™ 4 Gallon Water Supply Tank Assembly
49-16-28CS SWITCH TANK™ 4 Gallon Concrete Sprayer Tank Assembly
49-16-28PS SWITCH TANK™ 4 Gallon Sprayer Tank Assembly



M18 FUEL
18" Hedge Trimmer

3001-20 Tool-Only

Specifications:

Blade Length	18"
Cut Capacity	3/4"
SPM	3,400
Gear Case	All Metal
Length / Weight	36.5" / 8.4 lbs



Battery and Charger Sold Separately

Includes: Scabbard