

ALR120-CCT

5-color selectable low profile flush mount



NAME:	
TYPE:	
DATE:	
NOTES:	

SPECIFICATIONS

WIRING:	Installs easily to traditional junction boxes (3" or 4").
OPTICS:	LED technology delivers 1500LM on the 12" version and 2400LM on the 15" version.
ELECTRICAL:	<p>Integrated LEDs are direct 120VAC with no external driver.</p> <p>For usage in interior ceilings in residential or commercial applications. Ambient operating temperature: -20°C (-4°F) to +40°C (104°F).</p> <p>Certifications: ETL listed to U.S and Canadian safety standards as well as DAMP LOCATIONS rated. Suitable for use in clothes closet storages spaces. Meets all requirements of NFPA 70, NEC section 410.16., C(1).</p>
LENS:	Frosted white acrylic lens that provides a smooth even light distribution.

COLOR TEMPERATURE:	27K, 3K, 35K, 4K, 5K selectable
OPERATING TEMPERATURE:	-20°C (-40°F) to +40°C (104°F)
CRI:	90
LUMEN OUTPUT:	1500 lumens
DIMMABLE:	Yes
WATTS:	20
LED LIFE:	50,000 hours
WARRANTY:	5 years
VOLTAGE:	120V
DIAMETER:	11.8" (300mm)
HEIGHT:	2" (52mm)
INTEGRATED MOTION SENSOR:	No


APPLICATIONS

The Allure 5CCT selectable series of LED flush mount fixture by NDR Lighting offers an affordable and stylish design that is well suited for any installation need regardless of the application. The 5 color temperature selectability and acrylic diffuser provide a high lumen level and smooth light output to suit your flush mount lighting install. The acrylic diffuser may be easily removed for installation and cleaning. The Allure is well suited for any interior surface mount installation in a residential or commercial application.

ALR120-CCT

5-color selectable low profile flush mount

DIMENSIONS

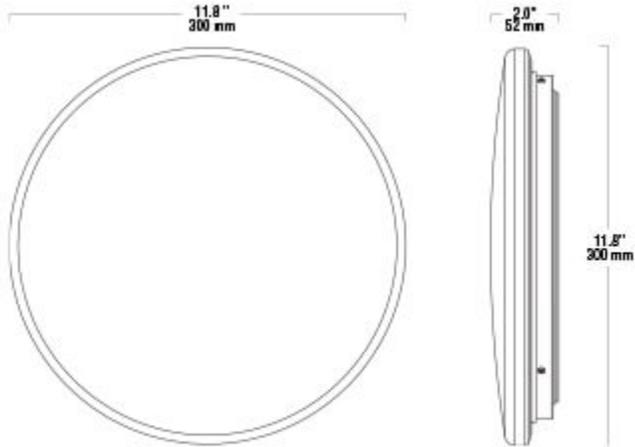

RATINGS



ORDERING GUIDE

ALR120-CCT SERIES

Series	Color Temperature	Finish
ALR120-CCT	2700K-3000K-3500K-4000K-5000K/90CRI/20W	WH White
Notes:	Configure product using BOLD options: Ex: ALR120-CCT-WH	