



SENTRON, cylindrical fuse holder, 10x38 mm, 1-pole, In: 32 A, Un AC: 690 V

Figure similar

Model	
product brand name	SENTRON
product designation	Cylindrical fuse holder
General technical data	
number of poles	1
size of fuse link	10 x 38 mm
Supply voltage	
operating voltage	
• at AC rated value	690 V
protection class IP	IP20
Mechanical Design	
height	81 mm
width	18 mm
depth	64 mm
net weight	55 g
Certificates	
reference code according to IEC 81346-2	F
Approvals Certificates	
General Product Approval	Test Certificates



[Confirmation](#)



[Miscellaneous](#)

other	Environment
-------	-------------

[Miscellaneous](#)

[Confirmation](#)

[Environmental Confirmations](#)

### Further information

- Information on the packaging  
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
- Information- and Downloadcenter (Catalogs, Brochures,...)  
<http://www.siemens.com/lowvoltage/catalogs>
- Industry Mall (Online ordering system)  
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NW7013>
- Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3NW7013>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=3NW7013](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NW7013)


CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

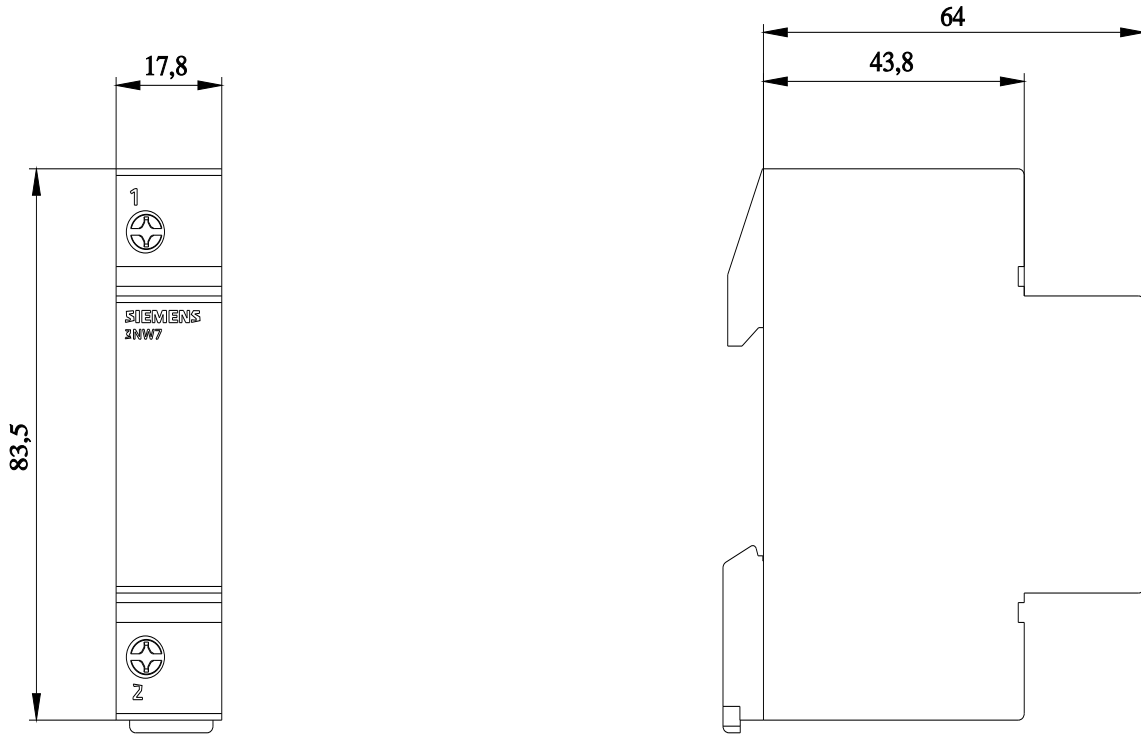

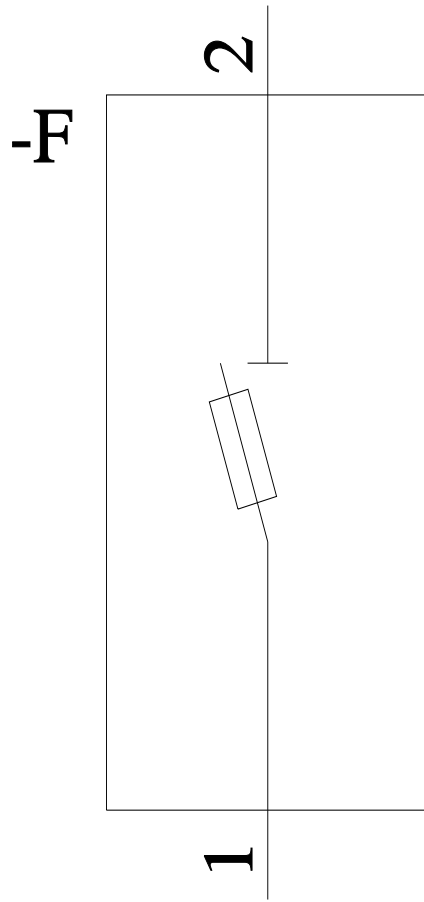

---

last modified:

7/9/2021 