




Versamate Series 150A 3 Pole 4 Wire Plug Assembly

By Killark
Catalog # [VPA15034](#)

150A 3 Pole 4 Wire Plug Assembly.

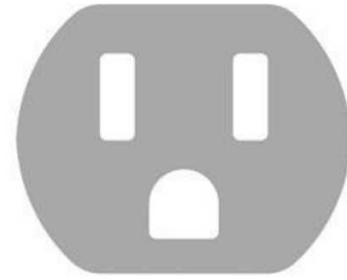

Oh No!
IMAGE COMING SOON

*Representative Image

Application

Suitable for indoor or outdoor use. Applications include the wet, cold, hosedown, hazardous or corrosive areas in such industrial applications as:Pulp & Paper Mills, Electrical Power Plants, Petrochemical Plants, Wastewater Treatment, Marine, Docks, Ports, Construction Sites, Breweries, Refineries, Chemical Plants, Grain Facilities , Textile Manufacturing, Food Processing Facilities

General

Catalog Number	VPA15034
EU RoHS Indicator	Contact Manufacturer
Finish Type	Baked Powder Epoxy/Polyester Finish
Grommet Range	0.88-1.91
Material	Body-Copper-free aluminum; Contacts-Brass; Spring tensioner-Patented beryllium copper; External screws-316 stainless steel
Series	VersaMate
Style	Style II
Type	Pin & Sleeve
UPC	783936084053

Dimensions

Dimensions	10.87 in x 4.25 in x 4.25 in
Height	4.25 in
Length	10.87 in
Width	4.25 in

Electrical Ratings

Amperage Rating	150 A
Frequency Rating	50-400 Hz
Voltage Rating	<ul style="list-style-type: none">• 600 VAC• 250 VDC

Conductor Related

Number Of Wires	3
-----------------	---

Product Assets

- [Certifications - 150A Versamate UL Certification](#)
- [Certifications - CSA Certificate - 150 Amp Versamate](#)
- [Customer Notices - Prop 65 Notice](#)
- [Specifications - VPA15034 Specification Sheet French](#)
- [Specifications - Versamate Series Receptacles Specification Sheet](#)