
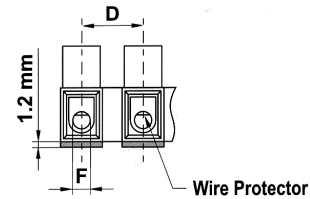
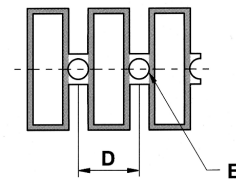
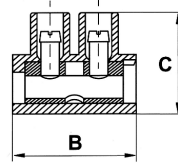


TERMINAL STRIPS (H TYPE)

(POLYAMIDE 66, 1.5-4.0 mm² / 2.5-6.0 mm²)

CE

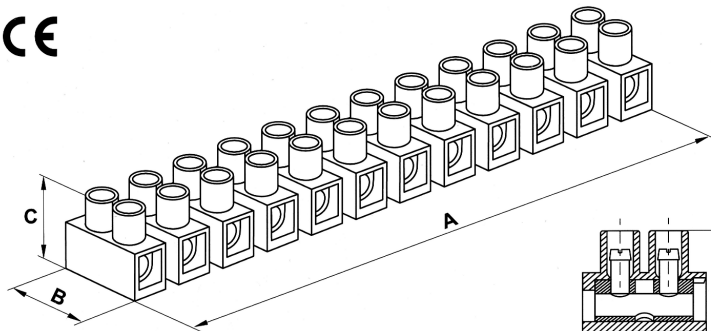


B

DIMENSIONS:

Model	Clamping Area	Wire Range (Cu, AWG)	Screw	Dimensions (mm/inch)							Packing
				Unit	A	B	C	D	E	F	
TSPA8HDS-12	1.5 mm ²	22-12 Sol/Str	M2.6x5	(mm)	96.20	17.00	14.50	8.00	2.90	2.8±0.1	50 Pcs/Bag
				(in)	3.79	0.67	0.57	0.32	0.11	0.11	500 Pcs/Ctn
TSPA10HDS-12	2.5 mm ²	22-12 Sol/Str 10 Sol	M3.0x6	(mm)	117.5	20.20	17.00	10.00	3.60	3.4±0.1	50 Pcs/Bag
				(in)	4.63	0.80	0.67	0.39	0.14	0.13	500 Pcs/Ctn

Description:

- **Base:** With 1.2 mm raised base
- **Housing Material:** Polyamide 66 (Nylon 66), UL 94V-2
- **Temperature Rating:** 105°C (UL), -30°C to T110°C (VDE)
- **Terminal Insert:** Brass metal alloy, nickel plated
- **Wire Protector (DS):** Stainless spring steel
- **Screw:** Zinc plated
- **Stripping Length:** 5.0 mm/0.20 inch for PA8; 6.5 mm/0.25 inch for PA10
- **Poles Available:** 12 poles

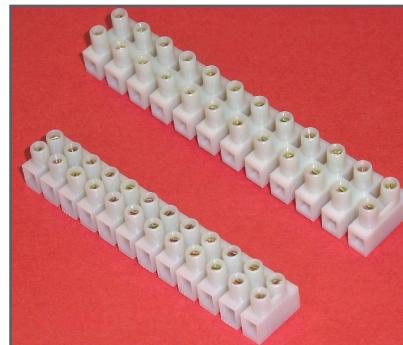

For Copper Wire Only

APPROVALS:

Model	Canada	U.S.A.	Germany
			
TSPA8HDS-12	600V, 20A #22 - #12	300V, 20A #22 - #12	450V, 17.5A 1.5 mm ²
TSPA10HDS-12	600V, 20A #22 - #12	300V, 20A #22 - #12	450V, 24A 2.5 mm ²

