

TWISTER® PRO™

WIRE CONNECTORS

WIDEST
WIRE RANGE
IN THE INDUSTRY

IDEAL
electrical™

TWISTER® PRO™

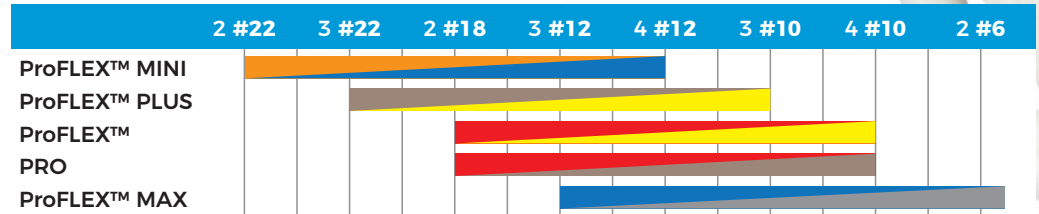
WIRE CONNECTORS








The Twister Pro® and ProFLEX™ family combines the most comfortable wire connector from IDEAL Electrical with the widest wire range of any multi-colored connectors in the industry. These connectors are designed with a live-action spring and high-leverage wings that provide excellent grip and torque. The ProFLEX™ line up is also engineered with a flexible skirt for added protection, providing performance professional electricians can trust.

Features:

- Widest Wire Range of any multi-colored wire connectors in the industry
- Flexible skirt on ProFLEX models provides improved protection and adapts to fit electrical boxes with limited space
- Swept wing design with SureGrip™ overmold offers greater comfort, leverage, and torque for faster connections
- Expanding square-wire spring and polypropylene shell deliver a secure connection every time



DESCRIPTION	MODEL	DETAILS	PART #
 Twister® ProFLEX™ Mini	343	600V* 22 to 12 AWG Min. 2 #22 - Max. 4 #12 Sol. WIDEST RANGE of any orange/blue connector	Box of 100 30-343
			Jar of 500 30-643J
			Barrel of 35K 30-843
 Twister® ProFLEX™ Plus	345	600V* 22 to 8 AWG Min. 3 #22 - Max. 3 #10 WIDEST RANGE of any tan/yellow connector	Box of 100 30-345
			Jar of 500 30-1345J
			Barrel of 25K 30-845
 Twister® ProFLEX™	347	1000V 22 to 8 AWG Min. 2 #18 - Max. 4 #10 WIDEST RANGE in the industry	Box of 75 30-1047JC
			Jar of 200 30-347JC
			Barrel of 15K 30-747
 Twister® Pro	344®	600V* 22 to 8 AWG Min. 2 #18 - Max. 4 #10 WIDEST RANGE in the industry	Jar of 250 30-244J
			Jar of 500 30-644J
			Barrel of 20K 30-944
 Twister® ProFLEX™ Max	348	1000V 14 to 6 AWG Min. 3 #12 - Max. 1 #6 w/2 #8 345 UL Listed Wire Combinations	Box of 25 30-348
			Jar of 150 30-1348J

P-6033 (10-24)
©IDEAL INDUSTRIES, INC.

*1,000V MAXIMUM IN FIXTURES AND SIGNS

IDEAL CUSTOMER SERVICE:
orderdesk@idealindustries.com
 1-800-824-3325
idealind.com

