

L2WMG LED Linkable Wraparound

Stanpro's L2WMG linkable wrap provides a superior lighting experience thanks to the high-performance and energy efficiency of LED technology. Available in 2' and 4' as well as dimming and CCT selectable options, this slim-profiled series is an ideal solution for commercial and residential applications.



■ Color Selectable

This flagship LED wraparound series is offered with the versatility of a dimmable feature with the choice of single color temperature or integrated selectable color temperature (4 000 K or 3 000/4 000/5 000 K).

■ Easily linkable

This model features a 3-pin receptacle on each end and comes standard with connector accessories to allow for easy and rapid connection between multiple luminaires, without additional wiring. Perfect for surface and row-mounted applications.

■ Modern design

The L2WMG Series offers a slim design with rounded edges for a more aesthetically pleasing result. Its light opening is narrower to reduce glare and offer a more directional light output without light leaking from the sides.


L2WMG linkable wrap

L2WMG

Our improved LED wrap luminaire!

- Slim modern design for a seamless and practical look

- CCT Selectable switch discreetly located inside the housing - Customize your lighting needs with the flick of a switch*

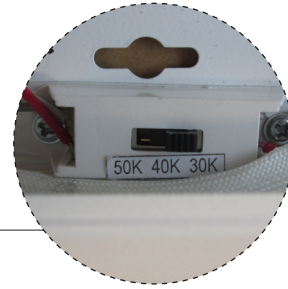

2 1/8"
(5.45 cm)

- 0-10 V dimmable driver when individually hardwired or with our end cap for conduit entry accessory*

- End-to-end linkable connectors - Link multiple luminaires for up to 32' of continuous light

- Frosted polycarbonate diffuser for a smooth light output

*If applicable

Accessories (Sold Separately)


Multiple options for fast and easy connection



End-to-end linkable connector
(included in the box)



Linkable cable connectors
(12", 48", 72", 96")

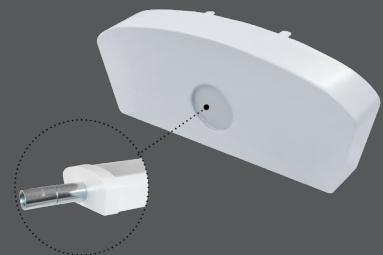

End cap for conduit entry (set of 2)
allows for continuous dimming

Specification Table

Order code	Model number	DLC unique ID	Watts (W)	Volts (V AC)	Color temp. (K)	Lumen output (lm)	Efficacy (lm/W)	CRI	Life L70 (hrs)	Tested hours LM-80 (hrs)	Dimming (Yes/No)	Power factor	THD (%)	Master case qty
Dimmable														
2' Single CCT														
68663	L2WMG-24-1-G2	PWTJBGH7	23	120-277	4 000	2 695	115	84	54 000	9 000	Yes	0.94	12	12
2' High Output CCT Selectable														
69372	L2WMG-24HO-3C-G2	S-JQ2KZH	46	120-277	3 000/4 000/5 000	5 354	116	83	>72 000	12 000	Yes	0.92	15	12
4' Single CCT														
68377	L2WMG-48-1-G2	P5HN6NQ9	47	120-277	4 000	5 420	116	84	> 54 000	9 000	Yes	0.90	13	6
4' CCT Selectable														
69165	L2WMG-48-3C-G2	S-1RF2XM	44	120-277	3 000/4 000/5 000	5 274	120	83	54 000	9 000	Yes	0.90	20	6
Non Dimmable														
4' Single CCT														
68137	L2WMG-48-1	-	47	120-277	4 000	5 043	106	84	54 000	9 000	No	0.90	15	6