

Specification Sheet

Part Number: T18S9M4


Engineered and manufactured for maximum performance and quality.

Made from 100% high-quality plastic to ensure efficient recycling.

Inside serration for a strong grip onto bundles.

Easy application either manually or with a tensioning tool.

Bent tail allows for simpler insertion.

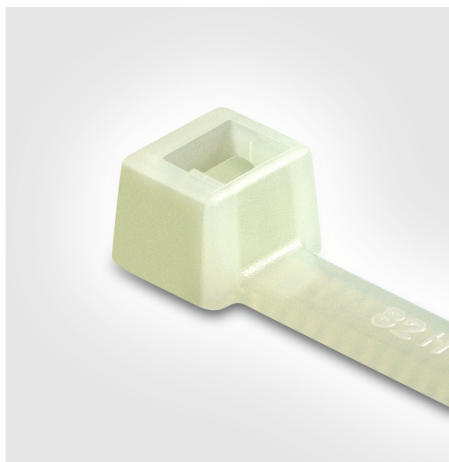

Cable Tie, 3.3" Long, UL Rated, 18lb Tensile Strength, PA66, Natural, 1000/pkg

Article Number 111-02809

Type T18S

Color Natural (NA)

Quantity Per bag

Product Description T-Series Cable Ties feature inside serrations to provide a positive hold on wire and cable bundles. The head design guarantees high tensile strength and a low insertion force. The bent tail design allows quick and simple installations by hand. For high-volume applications, tensioning tools are available to ensure consistent and safe installation.

Short Description Cable Tie, 3.3" Long, UL Rated, 18lb Tensile Strength, PA66, Natural, 1000/pkg

Global Part Name T18S-PA66-NA

Minimum Tensile Strength (Imperial) 18

Minimum Tensile Strength (Metric) 80

Length L (Imperial) 3.27

Length L (Metric) 83.0

Identification Plate Position none

Releasable Closure No

Tie Closure plastic pawl

Variant Inside Serrated

Width W (Imperial) 0.09

Width W (Metric) 2.3

Bundle Diameter Min (Imperial) 0.06

Bundle Diameter Min (Metric) 1.5

Bundle Diameter Max (Imperial) 0.63

Bundle Diameter Max (Metric) 16.0

Thickness T (Imperial) 0.039

Thickness T (Metric)	1.0
Cable Tie Head Length (Imperial)	0.18
Cable Tie Head Width (Imperial)	0.17
Height H (Imperial)	0.13
Height H (Metric)	3.2
Material	Polyamide 6.6 (PA66)
Material Shortcut	PA66
Flammability	UL 94 V-2
Halogen Free	Yes
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Plenum Rating	AH-2
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes

Certification/Specification UL | ANSI/UL 62275 UL | csa-C22.2 no. 62275

UL Recognized (US) Yes

UL Recognized (US and Canada) Yes

Package Quantity (Imperial) 1000

Package Quantity (Metric) 1000

Customs Number 3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)