



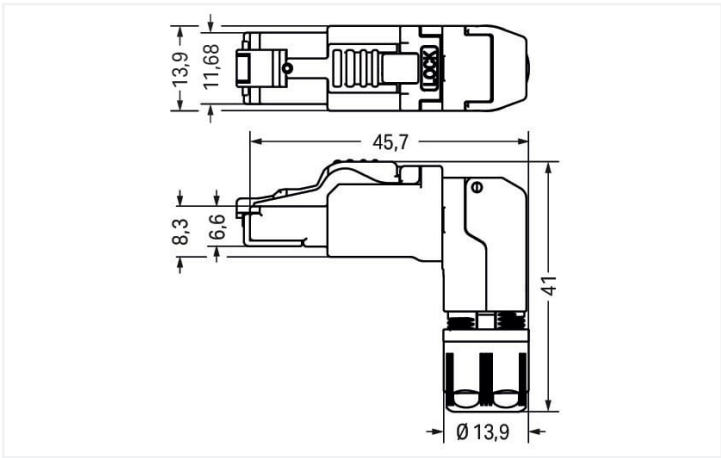

Dimensions in mm

Technical data	
Connection type	RJ-45 plug
Pole number	8
Cable connection direction to mating direction	90 °
Cable connection direction (note)	Selectable position
Communication/fieldbus	ETHERNET
Code	TIA-568B
Transmission rate	10000 Mbit/s

Connection data	
Connection type 1	IDC contact
Solid conductor	0.21 ... 0.32 mm² / 24/1 ... 22/1 AWG
Stranded conductor	0.11 ... 0.36 mm² / 27/7 ... 22/7 AWG

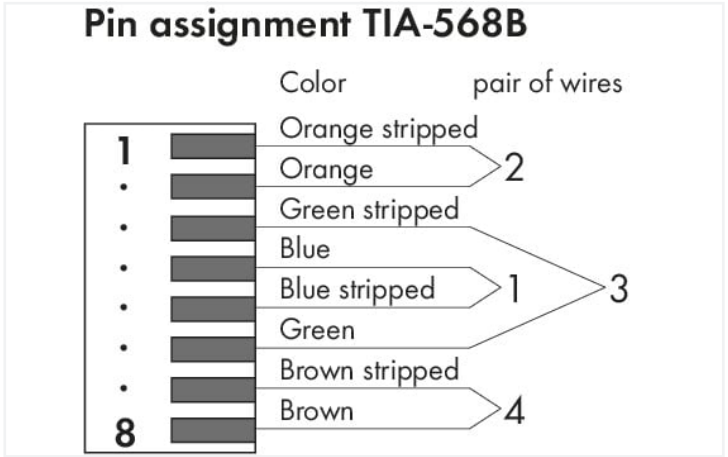

Physical data	
Width	13.9 mm
Height	41 mm
Depth	45.7 mm

Mechanical data	
Connection requirement (permissible cable type)	Cat. 6A
Connectable sheathed cable diameter	5.5 ... 10 mm
Housing material	Zinc die casting
Weight	26 g

Environmental requirements	
Ambient temperature (operation)	-40 ... +85 °C
Ambient temperature (storage)	-40 ... +85 °C
Protection type	IP20
Relative humidity (without condensation)	95 %
Fire load	0 MJ
Standards/specifications	IEC60603-7-51, ISO/IEC 11801, IEEE 802.3an EIA/TIA 568-C.2 DIN EN 50173-1 UL 1863 UL 2043

Commercial data	
eCl@ss 10.0	27-24-26-92
eCl@ss 9.0	27-24-26-92
ETIM 9.0	EC001121
ETIM 8.0	EC001121
PU (SPU)	1 pcs
Packaging type	Bag
Country of origin	TW
GTIN	4055143586290
Customs tariff number	85366990990

Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Approvals / Certificates

General approvals



Approval	Standard	Certificate Name
UL Underwriters Laboratories Inc.	UL 1977	E345416



Downloads			
Environmental Product Compliance			
Compliance Search			
Environmental Product Compliance	750-979/000-012		

Documentation			
Bid Text			
750-979/000-012	19.02.2019	xml 3.79 KB	
750-979/000-012	06.10.2017	doc 25.00 KB	
ausschreiben.de	750-979/000-012		