



Cinema Bar 3.0 - 3-Channel Passive Sound Bar for TVs 65" and Up

Add a mix of style and audio excellence to your home theater or improve your TV setup in any room of the house. The Cinema Bar 3.0 is a passive soundbar designed for use with wall mounted TVs, boasting 100W RMS Power Handling Per Channel. Three full-range drivers, three tweeters and three passive radiators provide rich and room-filling sound.

The reinforced MDF body with isolated audio chambers for each channel, the stylish satin black soundbar adds elegance and appeal beneath the television.

To complement the aesthetics the oversized area around the speaker connectors covers any wall openings for the wiring and to allows plenty of room to hide any excess when the soundbar is mounted. Cinema Bar 3.0 also mounts to any available soundbar mounting kit or TV mount.

Cinema Bar 3.0 pairs perfectly with Russound's AVA3.1 Mini-AVR.

What's in the Box

- Cinema Bar 3.0
- Wall-mount Brackets with mounting screws
- 1/4-20 x 3/8" Long Screws for using with 3rd party mounts
- Owner's Manual



Rich, room-filling sound with three 4" drivers, three 1" tweeters and three 4" passive radiators.



100 Watts Power Handling per Channel with frequency response down to 70Hz for deeper bass.



Elegant stylish aesthetic appeal with satin black finish.



Fits any TV 65" and up.



Flexible mounting options: Wall mount or TV mount or use any soundbar mounting kit.



Easy installation with included MicroSlide™ brackets or built-in threaded inserts.



Recessed speaker connector area covers wall openings for wiring and hides cables.

Mounting Options

Having multiple installation options provides the ultimate flexibility in any installation and caters to our dealers' request for fast and hassle-free installation.

TV Mount

Use the built-in threaded inserts to mount the soundbar directly to a TV mount.

3rd Party Mounting Kit


Use any available soundbar mounting kit with the threaded inserts on the rear side of the soundbar.

Wall Mount


True keyhole-style mount with the new included MicroSlide™ brackets that let you move the installed soundbar 5" (125mm) horizontally after installation so the soundbar always lines up perfectly with the TV.

Easy Wire Management

The oversized recessed area covers wall openings and provides room to hide any excess wiring.

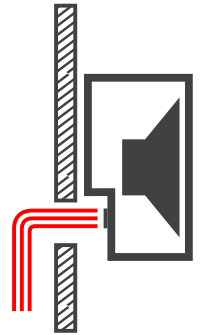

Application Example

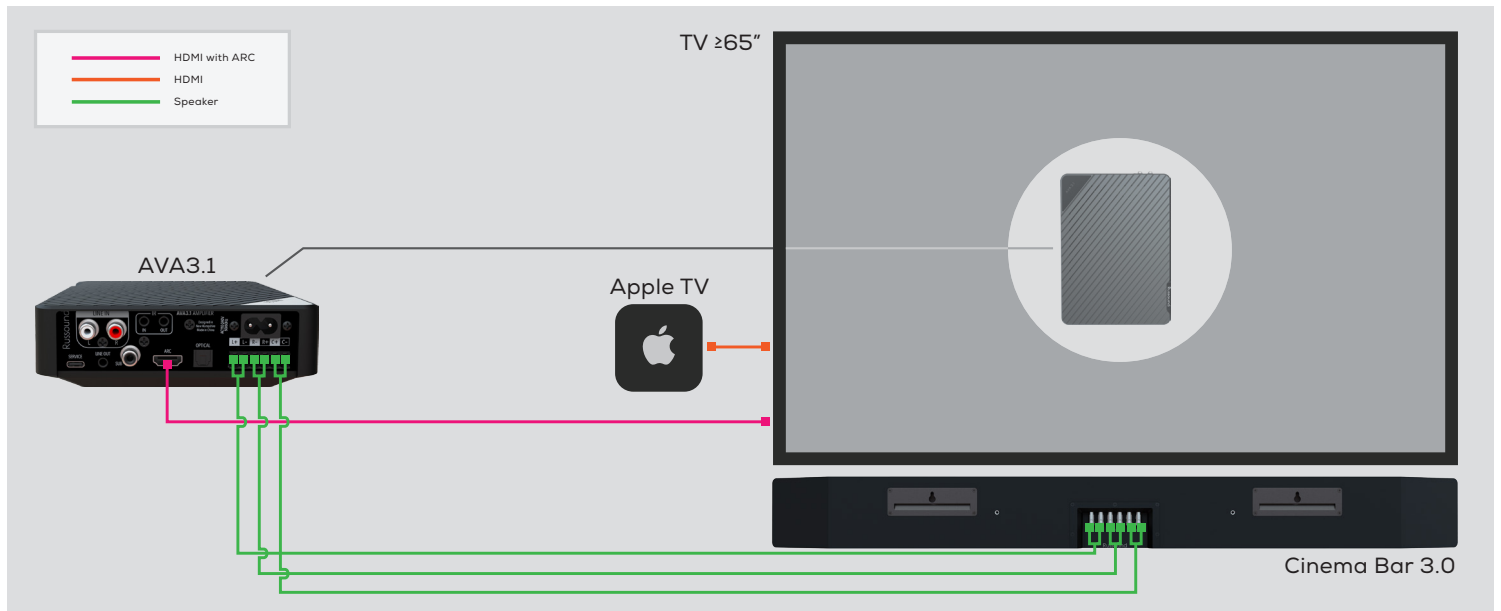

Back Panel



- 1 Keyholes for wall mounting
- 2 MicroSlide™ mounting location
- 3 Threaded holes for 3rd party TV mount or 3rd party soundbar mounting kits
- 4 Left channel speaker connectors
- 5 Center channel speaker connectors
- 6 Right channel speaker connectors
- 7 Recess to cover wall openings and to hide any excess wiring when the Cinema Bar 3.0 is mounted

Specifications

	Cinema Bar 3.0
Speaker Type	3-Channel Passive
Tweeter x3	3x 1" Soft Dome
Passive Radiators x3	3x 4" Polypropylene
Woofers x3	3x 4" Polypropylene
Frequency Response	70 Hz - 20 kHz
Crossover Frequency	3,000 Hz
Sensitivity	87.5db @ 2.83 v/1m
Max Power Input	100 Watts Per Channel RMS
Nominal Impedance	6 Ohms
Binding Posts	Easy To Use Push Connectors
Max Wire Size	12 ga
Cabinet Construction	Reinforced MDF with Isolated Chambers per Channel
Cabinet Finish	Satin Black
Grille	Black/Gray, Pin Mounted
Wall Mount	Included
TV Wall Mount	Included Inserts and 2 x 1/4-20 x 3/8" Long Screws
Environmental Friendly Design	CARB Phase 2 Compliant
Product Dimensions (LxHxD)	50" x 5" x 3.1" (127cm x 12.7cm x 7.8cm)
Product Weight	12.8 lbs (5.8 kg)
Shipping Dimensions (LxHxD)	53.9" x 7.7" x 9.1" (137cm x 19.5cm x 23cm)
Shipping Weight	17.6 lbs (8 kg)
Operating Temperature	32°F to 104°F (0°C to 40°C)
Limited Warranty	2 Years