

READ AND FOLLOW ALL SAFETY INSTRUCTIONS!
SAVE THESE INSTRUCTIONS AND DELIVER TO OWNER AFTER INSTALLATION

IMPORTANT SAFETY INSTRUCTIONS

▲ WARNING

To reduce the risk of death, injury or property damage from fire, electric shock, cuts, abrasions, falling parts, and other hazards:

- Service of the equipment must be performed by qualified service personnel.
- Installation and maintenance must be performed by a person familiar with the construction and operation of this product and any hazards involved. All applicable codes and ordinances must be followed.
- Read this document before installing, servicing, or maintaining this equipment or installing a lamp. These instructions do not cover all installation, service, and maintenance situations. If your situation is not covered, or if you do not understand these instructions or additional information is required, contact *Lithonia Lighting* or your local *Lithonia Lighting* Distributor.
- Read and follow all warnings and instructions provided by the lamp manufacturer.

▲ WARNING

Before installing, servicing, or maintaining this equipment, follow these general precautions.

To reduce the risk of electrocution:

- Make sure the equipment is properly grounded.
- Always de-energize the circuit and/or equipment before connecting to, disconnecting from, or servicing the equipment.


To reduce the risk of fire:

- Keep material away that can burn from hot lamp.
- Make sure lamps are correctly installed.
- Use supply conductors with a minimum installation temperature rating as specified on equipment.

To reduce the risk of personal injury from cuts, abrasions, or falling parts:

- Wear gloves to prevent cuts or abrasions from sharp edges when removing from carton, handling and maintaining this equipment.
- Do not use abrasive materials, glass cleaners or other solvents on reflector or lens. These substances may damage equipment and cause parts to eventually break and fall.
- Do not install a damaged fixture.

▲ CAUTION: Observe lamp manufacturer's recommendations and restrictions on lamp operation, including but not limited to ballast type, burning position, replacement and cycling. Use only lamps that comply with applicable ANSI standards.

NOTICE: If lamp is marked  it contains mercury. Follow disposal laws. See www.lamprecycle.org

Lithonia Lighting, a division of *Acuity Brands Lighting*, Inc., assumes no responsibility for claims arising out of improper or careless installation or handling of this product.

SAVE THESE INSTRUCTIONS

Installation Instructions


Outdoor Floodlighting Mounting Accessory

Mount only as pictured. Do not invert bracket.

Description: Tenon Mount Slipfitter (FTS)

Not for use with ASF, 55, 95 or 170S.

Installation: Secure the fixture yoke to the FTS by using the bolt and lockwasher provided. When using with the yoked TFM series, a 3/8" bolt, (2) lockwashers and nuts (not provided) must be used instead of 5/8". Secure to the top end of a tenon or pipe 2" to 2-1/2" (2-3/8" to 2-7/8" OD) by tightening set screws as needed.

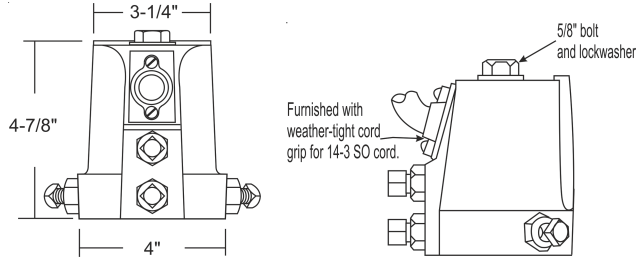


Due to yoke design, the TFM will be off center when mounted.


Description: Tenon Mount Slipfitter (TVTS)

(for use with TV sportsighting fixture)

Installation: Insert 5/8" diameter threaded bolt of the TV fixture through the clearance hole on TVTS. Place washer and nut onto bolt inside the fitter. Tighten with socket wrench. Secure to the top end of a tenon or pipe 2" to 2-1/2" (2-3/8" to 2-7/8" OD) by tightening set screws as needed.

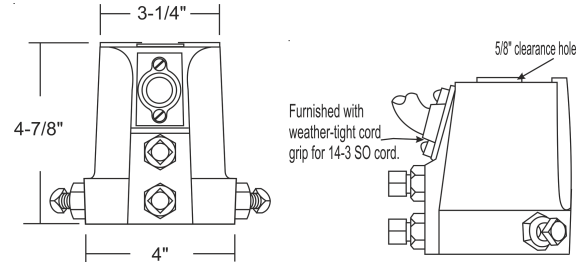


Description: Cross-arm Adapter (FCRA)

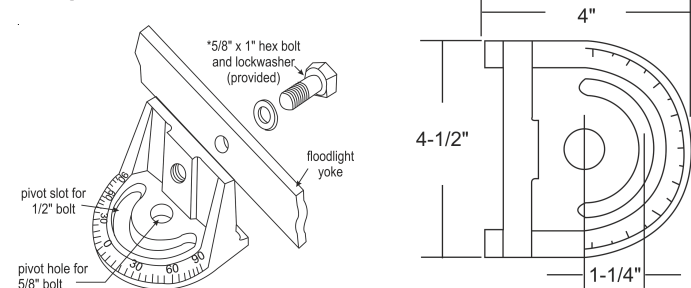

Installation: Secure the fixture yoke mount to the FCRA or FCRA45 by using the bolt and lockwasher provided. Secure the FCRA or the FCRA45 to the cross-arm with a 5/8" bolt (not provided).


Description: Cross-arm Adapter (45°) (FCRA45)

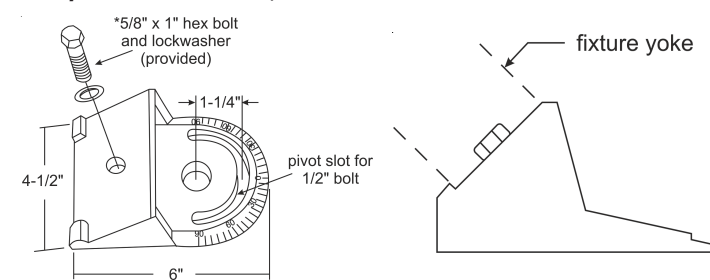

Due to yoke design, the TFM will be off center when mounted.

Description: Wall/Wood Pole/Pipe Mounting Bracket (FPMB)

Installation: Secure the yoke to the FPMB by using the bolt and lockwasher provided. Secure the FPMB to a 2" – 2-1/2" pipe with 3/8" U-bolts, nuts and lockwashers (provided). For wall or wood pole mount, discard U-bolts and secure to surface with (4) 3/8" fasteners (not provided).

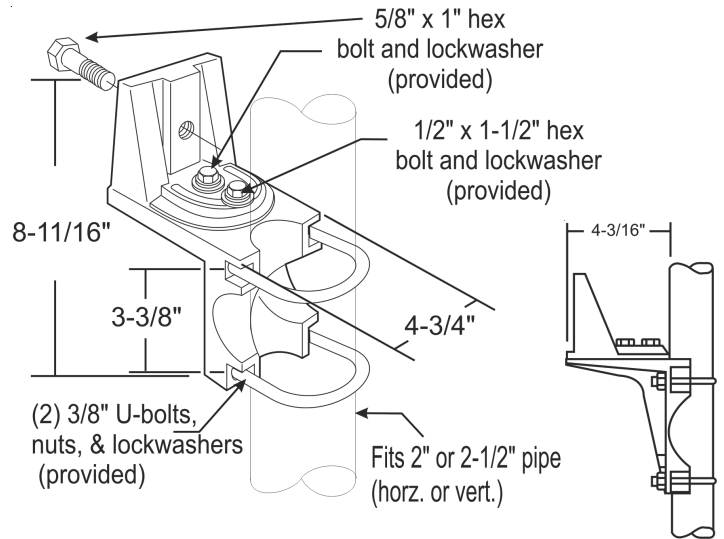


Due to yoke design, the TFM will be off center when mounted.

Description: Tenon Mount Slipfitter (TFMTS)

For use with 1/2" knuckle mount.

Installation: Attach FTMST to fixture's threaded knuckle. Secure to the top end of a 1-1/4" to 2" pipe by tightening set screws as needed. The FTMST is for ground mount use only due to its shallow height.

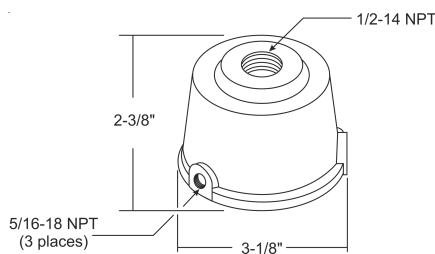

Description: Tenon Mount Slipfitter (TS)

Must be used with 55, 95, and 170S due to the width of their yoke.

Installation: Secure the fixture yoke to the TS by using the bolt and lockwasher provided. Secure to the top end of a tenon or pipe 2" (2-3/8" OD) by tightening set screws as needed.

