

VuLite[®] Economy Recessed Lighting

A new view on economy lighting



JUNO[®]

Juno® VuLite® Economy Recessed Lighting

Viewing economy recessed downlighting in a different light

Take a new "view" on economy lighting with Juno VuLite. VuLite is an economic alternative for recessed lighting offering a selection of 4", 5" and 6" downlights for use in residential and light commercial applications. The line includes a range of popular trim selections including baffles, cones, adjustables and lensed, providing choices to meet the needs of

various lighting applications. Economy does not mean sacrificing the quality and standards you have come to expect from the Juno brand. You can buy and install VuLite products with total confidence knowing that all products are designed and tested to meet UL requirements and are backed by the leader in residential recessed lighting.

VuLite Product Offering

4" Housings and Trims

Line Voltage Housings



V4IC W



V4TC W



V4TCR W

Low Voltage Housings



V4ICLV W



V4TCLV W



V4TCRLV W

4-inch Trims



Baffle



Clear Cone



Gimbal Ring



Eyeball



Flat Lens Shower

5" Housings and Trims

Line Voltage Housings



V51C W



V51CR W



V5TC W



V5TCR W

5-inch Trims



Baffle



Clear Cone



White Cone



R/PAR20 Eyeball



PAR30 Eyeball



Flat Lens

6" Housings and Trims

Line Voltage Housings



V61C W and V61CN W



V61CR W



V6TC W



V6TCR W

6-inch Trims



Baffle



Full Baffle



Clear Cone



Full Cone



Eyeball



Flat Lens Shower



Drop Opal



Open Frame


VuLite® 4" Line Voltage Housings and Trims

IC Housings

V4IC W

4" IC New Construction
Energy efficient double wall housing. May be covered with insulation.

Dimensions:
12"L x 13-3/8"W x 6"H
Ceiling Cutout: 4-1/2" Diameter

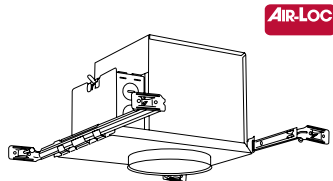

Accessories:


G2405 Set of (4) T-bar clips for installation in suspended ceilings.

TC Housings

V4TC W

4" TC New Construction
Requires 3" spacing from insulation.


Dimensions:
12-1/8"L x 13-3/8"W x 5-1/2"H
Ceiling Cutout: 4-1/2" Diameter

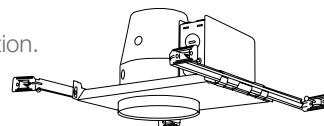

V4TCR W

4" TC Remodel
Requires 3" spacing from insulation.

Dimensions:
12"L x 4-1/4"W x 5-1/2"H
Ceiling Cutout: 4-3/8" Diameter

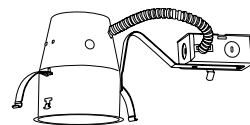

4" Compatible Trims - Line Voltage

Baffle

V4034 WWH White
V4034 BWH Black

Aperture: 3-7/8"
Outer Diameter: 5"

Juno Compatible Housings: Lamp Wattage/Type

V4IC W: 50W PAR20, 30W R20
V4TC W, V4TCRW: 50W PAR20, 50W R20
IC1P, TC1, TC1R: 50W PAR20, 50W R20
IC1: 50W PAR20, 30W R20



Eyeball

V4018 WH White

Outer Diameter: 5"

Juno Compatible Housings: Lamp Wattage/Type

V4IC W, V4TC W, V4TCR W: 60W PAR16, 40W R16
IC1, IC1P, TC1, TC1R: 60W PAR16, 40W R16



Stippled Opal Lens Shower with Reflector

V4012 WH White

Outer Diameter: 5"

Juno Compatible Housings: Lamp Wattage/Type

(Remove reflector when using Juno IC1 housing)
V4IC W: 35W PAR20, 30W R20
V4TC W, V4TCR W: 50W PAR20, 50W R20
IC1: 35W PAR20, 30W R20
IC1P: 50W PAR20, 30W R20
TC1, TC1R: 50W PAR20, 50W R20




Cone

V4017 CWH Clear

Aperture: 3-7/8"
Outer Diameter: 5"

Juno Compatible Housings: Lamp Wattage/Type

V4IC W, V4TC W, V4TCR W: 50W PAR20, 50W R20
IC1, IC1P, TC1, TC1R: 50W PAR20, 50W R20

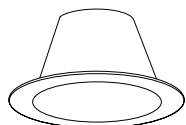


Gimbal Ring

V4010 WH White
V4010 BN Brushed Nickel

Outer Diameter: 5"

Juno Compatible Housings: Lamp Wattage/Type

 V4IC W, V4TC W, V4TCR W: 50W PAR20
IC1P, TC1, TC1R: 50W PAR20




Gimbal Ring

V4040 WH White
V4040 BN Brushed Nickel

Outer Diameter: 5"

Juno Compatible Housings: Lamp Wattage/Type

 V4IC W: 35W MR16, 35 PAR16 120V Medium Base
IC1, IC1P: 35W MR16, 35W PAR16 120V Medium Base




VuLite® 4" Low Voltage Housings and Trims

IC Housings

V4ICLV W

4" IC Low Voltage New Construction
50W Energy efficient double wall housing includes 50VA, 12V thermally protected magnetic transformer. May be covered with insulation.

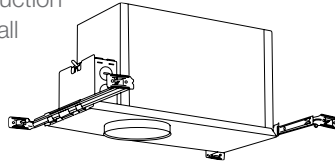

Dimensions:
18-1/2"L x 13-3/8"W x 7-5/8"H
Ceiling Cutout: 4-1/2" Diameter


Accessories:

G2405 Set of (4) T-bar clips for installation in suspended ceilings.

TC Housings

V4TCLV W


4" TC Low Voltage New Construction
50W Housing includes 50VA, 12V thermally protected magnetic transformer. Requires 3" spacing from insulation.

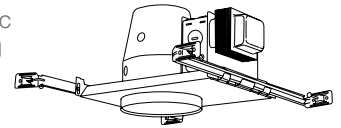

Dimensions:
12-1/8"L x 13-3/8"W x 5-1/2"H
Ceiling Cutout: 4-1/2" Diameter

V4TCRLV W

4" TC Low Voltage Remodel 50W
Housing includes 50VA, 12V magnetic transformer. Requires 3" spacing from insulation.

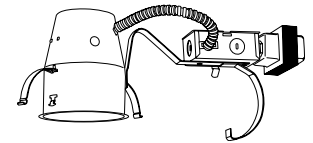


Dimensions:
14-1/2"L x 4-1/4"W x 5-1/2"H
Ceiling Cutout: 4-3/8" Diameter

4" Compatible Trims – Low Voltage

Baffle with Regressed Gimbal Ring

 V4044 WWH White
V4044 BWH Black



Aperture: 3-1/2"
Outer Diameter: 5"

Juno Compatible Housings: Lamp Wattage/Type
V4ICLV W, V4TCLV W, V4TCRLV W: 50W MR16
IC44N, TC44, TC44 V, TC44R, TC47, TC47 V: 50W MR16

Eyeball with Baffle

V4048 WH White



Outer Diameter: 5"

Juno Compatible Housings: Lamp Wattage/Type
V4ICLV W, V4TCLV W, V4TCRLV W: 50W MR16
IC44N, TC44, TC44 V, TC44R, TC47, TC47 V: 50W MR16

Cone with Regressed Gimbal Ring

V4047 CWH Clear



Aperture: 3-1/2"
Outer Diameter: 5"

Juno Compatible Housings: Lamp Wattage/Type
V4ICLV W, V4TCLV W, V4TCRLV W: 50W MR16
IC44N, TC44, TC44 V, TC44R, TC47, TC47 V: 50W MR16

Stippled Opal Lens Shower

V4041 WH White



Outer Diameter: 5"

Juno Compatible Housings: Lamp Wattage/Type
V4ICLV W, V4TCLV W, V4TCRLV W: 50W MR16
IC44N, TC44, TC44 V, TC44R, TC47, TC47 V: 50W MR16



Gimbal Ring

V4040 WH White
V4040 BN Brushed Nickel



Outer Diameter: 5"

Juno Compatible Housings: Lamp Wattage/Type
V4ICLV W, V4TCLV W, V4TCRLV W: 50W MR16
IC44N, TC44, TC44 V, TC44R, TC47, TC47 V: 50W MR16


VuLite® 5" Line Voltage Housings and Trims

IC Housings

V5IC W

5" IC New Construction
Energy efficient housing.
May be covered with insulation.

Dimensions:
11-7/8"L x 13-3/8"W x 7-1/2"H
Ceiling Cutout: 5-5/8" Diameter

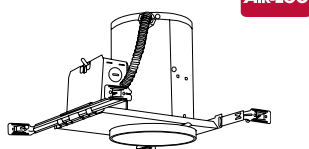


TC Housings

V5TC W

5" TC New Construction
Requires 3" spacing from insulation.


Dimensions:
11-7/8"L x 13-3/8"W x 7-1/2"H
Ceiling Cutout: 5-5/8" Diameter

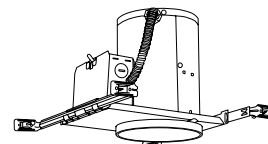

V5ICR W

5" IC Remodel
Energy efficient housing.
May be covered with insulation.


Dimensions:
14-3/8"L x 6-3/4"W x 7-1/2"H
Ceiling Cutout: 5-1/2" Diameter

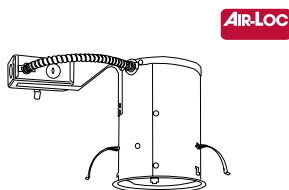

V5TCR W

5" TC Remodel
Requires 3" spacing from insulation.

Dimensions:
12-1/2"L x 5-7/8"W x 7-1/2"H
Ceiling Cutout: 5-1/2" Diameter

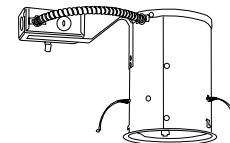

Accessories:


ALG5 Airloc® gasket kit for V5IC W housing when an Airloc® trim is not being used. **G2405** Set of (4) T-bar clips for installation in suspended ceilings.

5" Compatible Trims

Baffle

V2015 WWH White
V2015 BWH Black


Aperture: 4-3/4"
Outer Diameter: 6-1/4"

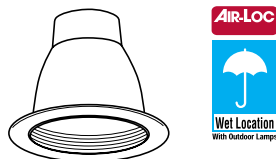

Cone

V2016 CWH Clear
V2016 WWH White

Aperture: 4-3/4"
Outer Diameter: 6-1/4"

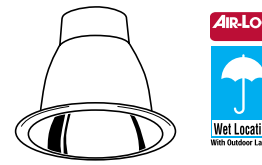

Juno Compatible Housings: Lamp Wattage/Type

V5IC W, V5ICR W: 65W BR30, 75W PAR30L, 75W PAR30 w/socket extender, 50W PAR30 (black only)

V5TC W, V5TCR W: 85W BR30, 75W PAR30L, 40W A19 (white only), 75W PAR30 (black only or use socket extender with white)

IC20, IC20R: 40W A19, 65W BR30, 75W PAR30L, 75W PAR30 w/socket extender

IC20N: 65W BR30

TC20, TC20R: 60W A19, 85W BR30, 75W PAR30L, 75W PAR30 w/socket extender

Juno Compatible Housings: Lamp Wattage/Type

V5IC W, V5ICR W: 65W BR30, 75W PAR30L, 75W PAR30 w/socket extender

V5TC W, V5TCR W: 85W BR30, 75W PAR30L, 75W PAR30 w/socket extender, 60W A19 (clear only), 40W A19 (white only)

IC20, IC20R: 40W A19, 65W BR30, 75W PAR30L, 75W PAR30 w/socket extender

IC20N: 65W BR30


TC20, TC20R: 60W A19, 85W BR30, 75W PAR30L, 75W PAR30 w/socket extender

R/PAR20 Eyeball

V2029 WH White

PAR30 Eyeball

V2030 WH White

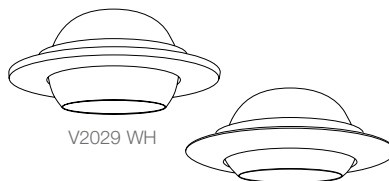

Outer Diameter (R/Par20 Eyeball): 6-1/4"

Outer Diameter (PAR30 Eyeball): 6-1/2"

Juno Compatible Housings: Lamp Wattage/Type

V2029 WH - V5IC W, V5ICR W: 50W R20, 50W PAR20

V5TC W, V5TCR W: 50W R20, 50W PAR20

IC20, IC20N, IC20R, TC20, TC20R: 50W PAR20, 50W R20

V2030 WH - V5IC W, V5ICR W: 75W PAR30


V5TC W, V5TCR W: 75W PAR30

IC20, IC20N, IC20R, TC20, TC20R: 75W PAR30

Flat Lens Shower with Reflector

V2010 WH White

Outer Diameter: 6-1/2"

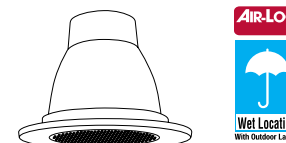

Juno Compatible Housings: Lamp Wattage/Type

V5IC W, V5ICR W: 35W PAR30L

V5TC W, V5TCR W: 75W PAR30L, 90W A19

IC20, IC20R: 35W PAR30L & 40W A19

IC20N: 35W PAR30L

TC20, TC20R: 75W PAR30L & 90W A19


VuLite® 6" Line Voltage Housings and Trims

IC Housings

V6IC W 6" IC New Construction
V6ICN W 6" IC New Construction with Floating Socket

Energy efficient housing.
 May be covered with insulation.


Dimensions:
 13-3/4"L x 13-3/8"W x 7-3/8"H
 Ceiling Cutout: 6-1/2" Diameter

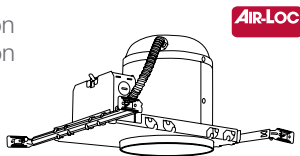

TC Housings


V6TC W
 6" TC New Construction
 Requires 3" spacing from insulation.

Dimensions:
 13-3/4"L x 13-3/8"W x 7-3/8"H
 Ceiling Cutout: 6-1/2" Diameter

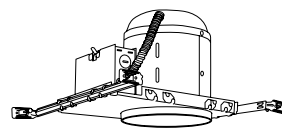


V6ICR W
 6" IC Remodel
 Energy efficient housing.
 May be covered with insulation.

Dimensions:
 13-3/4"L x 6-3/4"W x 7-3/8"H
 Ceiling Cutout: 6-1/4" Diameter

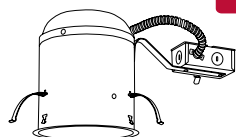

V6TCR W
 6" TC Remodel
 Requires 3" spacing from insulation.

Dimensions:
 13-3/4"L x 6-3/4"W x 7-3/8"H
 Ceiling Cutout: 6-1/4" Diameter

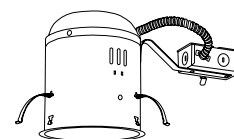


Accessories: **VALG6** Airloc® gasket kit for V6IC W housing when an Airloc® trim is not being used. **G2405** Set of(4) T-bar clips for installation in suspended ceilings.

6" Compatible Trims

Conical Baffle

V3024 WWH White
V3024 BWH Black

Aperture: 5-3/4"
 Outer Diameter: 7-3/4"

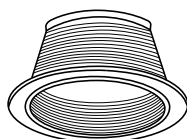


Juno Compatible Housings: Lamp Wattage/Type
V6IC W, V6ICR W: 50W PAR30, 75W PAR30L, 65W BR30
V6TC W, V6TCR W: 75W PAR30/PAR30L, 65W BR30, 120W BR40
IC22, IC22R: 50W PAR30, 75W PAR30L, 65W BR30
IC2, TC2, TC2R: 75W PAR30 w/socket extender, 75W PAR30L, 65W BR30

Straight Baffle

V3025 WWH White
V3025 BWH Black

Aperture: 5-3/4"
 Outer Diameter: 7-3/4"

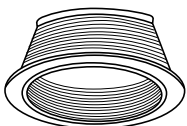


Juno Compatible Housings: Lamp Wattage/Type
V6IC W, V6ICR W: 50W PAR30/PAR30L, 75W PAR38
V6TC W, V6TCR W: 75W PAR30/PAR30L, 65W BR30, 120W BR40, 120W PAR38
IC22, IC22R: 75W PAR30/PAR30L, 65W BR30, 75W PAR38
IC2: 75W PAR30 w/socket extender, 75W PAR30L, 65W BR30, 90W PAR38, 100W BR40
TC2, TC2R: 75W PAR30 w/socket extender, 75W PAR30L, 65W BR30, 150W PAR38, 120W BR40

Full Baffle

V3034 WWH White
V3034 BWH Black
V3034T WWH White w/Torsion Springs
V3034T BWH Black w/Torsion Springs

Aperture: 5-3/4"
 Outer Diameter: 7-5/8"

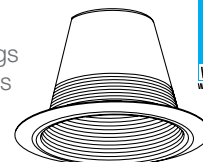

Juno Compatible Housings: Lamp Wattage/Type
V6IC W, V6ICN W, V6ICR W: 40W A19*, 75W PAR30/PAR30L, 65W BR30, 90W BR40, 90W PAR38*
V6TC W, V6TCR W: 60W A19*, 75W PAR30/PAR30L, 85W BR30, 120W BR40, 150W PAR38*
IC22, IC22R, IC23: 40W A19, 75W PAR30/PAR30L, 65W BR30, 90W BR40, 90W PAR38
IC2: 60W A19, 75W PAR30/PAR30L, 85W BR30, 100W PAR38, 120W BR40
TC2, TC2R: 60W A19, 75W PAR30/PAR30L, 85W BR30, 150W PAR38, 120W BR40
ICPL6 Series: 32W max. CFL†
PL6 Series: 42W max CFL†

* No A19 listing and 75W PAR38 max. for the V3034B Series
 † Note: For best performance, 26W is recommended.

Patent Pending

Clear Cone **V3027C WH: Clear**

Aperture: 5-3/4"
 Outer Diameter: 7-3/4"



Juno Compatible Housings: Lamp Wattage/Type
V6IC W, V6ICR W: 50W PAR30, 75W PAR30L, 65W BR30
V6TC W, V6TCR W: 75W PAR30/PAR30L, 65W BR30, 90W BR40
IC2, IC22, IC22R: 50W PAR30, 75W PAR30L, 65W BR30
TC2, TC2R: 75W PAR30/PAR30L, 65W BR30

VuLite® 6" Line Voltage Housings and Trims

6" Compatible Trims

Full Cone

V3037 WWH White
V3037T WWH White w/Torsion Springs

Aperture: 5-3/4"
 Outer Diameter: 7-5/8"



Juno Compatible Housings: Lamp Wattage/Type

V6IC W, V6ICN W, V6ICR W: 40W A19, 75W PAR30/PAR30L, 65W BR30, 75W BR40, 90W PAR38
V6TC W, V6TCR W: 60W A19, 75W PAR30/PAR30L, 85W BR30, 120W BR40, 150W PAR38

IC22, IC22R, IC23: 40W A19, 75W PAR30/PAR30L, 65W BR30, 90W BR40, 90W PAR38

IC2: 60W A19, 75W PAR30/PAR30L, 85W BR30, 100W PAR38

TC2, TC2R: 60W A19, 75W PAR30/PAR30L, 85W BR30, 120W BR40, 150W PAR38

ICPL6 Series: 32W max. CFL†

PL6 Series: 42W max. CFL†

 
†Note: For best performance, 26W is recommended.

Patent Pending

Eyeball

V3029 WH White

Outer Diameter: 7-3/4"



Juno Compatible Housings: Lamp Wattage/Type

V6IC W, V6ICN W, V6ICR W: 65W BR30, 75W PAR30L
V6TC W, V6TCR W: 75W PAR30/PAR30L, 65W BR30

IC22, IC22R, IC23, IC2, TC2, TC2R: 75W PAR30 w/socket extender, 75W PAR30L, 65W BR30

Stippled Opal Lens Shower

V3020 PW Plastic White

Outer Diameter: 8"



Juno Compatible Housings: Lamp Wattage/Type


V6TC W, V6TCR W: 40W A19, 75W PAR30/PAR30L, 65W BR30, 75W PAR38 (Not for use with V6IC/V6ICR)

TC2, TC2R: 60W A19, 75W PAR30/PAR30L, 65W BR30, 75W PAR38

Stippled Opal Lens Shower with Reflector

V3040N PW Plastic White

Outer Diameter: 8"

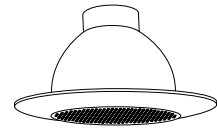

Juno Compatible Housings: Lamp Wattage/Type

V6IC W, V6ICN W, V6ICR W: 34W A19, 35W PAR30
V6TC W, V6TCR W: 75W A19

IC2, IC22, IC22R, IC23: 40W A19


TC2, TC2R: 75W A19

ICPL6/PL6 Series: 13W max. CFL

Drop Opal Lens Shower with Reflector

V3041 PW Plastic White

Outer Diameter: 8"

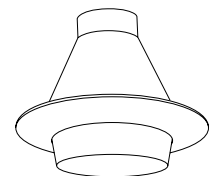

Juno Compatible Housings: Lamp Wattage/Type

V6IC W, V6ICN W, V6ICR W: 40W A19
V6TC W, V6TCR W: 100W A19

IC22, IC22R, IC23: 40W A19

IC2: 60W A19

TC2, TC2R: 100W A19

 
ICPL6/PL6 Series: 26W max. CFL

Open Frame

V3050 WH White

Aperture: 3-7/8"

Outer Diameter: 8"



Juno Compatible Housings: Lamp Wattage/Type

V6IC W, V6ICR W, V6TC W, V6TCR W: 65W BR30



All trademarks referenced are property of their respective owners. Specifications subject to change without notice. Printed in the U.S.A.