


circular conduc. terminal TA7.2 4 x 600...750 kcmil for 4 cables; 1 unit accessory for: circuit breaker, 3-pole 3VA58; 3VA68

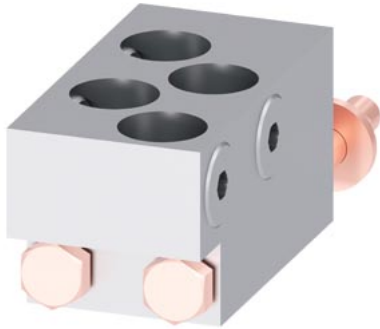

Model	
product brand name	SETRON
product designation	Circular conductor terminal 1 unit
accessories	Wire connector
General technical data	
designation / of the terminal	TA7.2
type of electrical connection / with control wire tap	No
Connections according IEC	
stripped length	30 mm
Connections according UL	
permissible temperature / of connectable conductor / according to UL 486A-486B	75 °C
stripped length	1.2 in
connectable conductor cross-section	
<ul style="list-style-type: none"> • for copper cable / stranded / minimum • for copper cable / stranded / maximum • for aluminum cable / stranded / minimum • for aluminum cable / stranded / maximum 	<ul style="list-style-type: none"> 600 kcmil 750 kcmil 600 kcmil 750 kcmil

Certificates	
General Product Approval	EMV Test Certificates



[Miscellaneous](#)



[Type Test Certificates/Test Report](#)

Marine / Shipping	other	Environment			
<p>LRS</p>	Confirmation	Miscellaneous	Miscellaneous	Environmental Confirmations	Environmental Confirmations

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
 Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
 Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mifb=3VA9771-0JJ44>
 Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/3VA9771-0JJ44>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mfb=3VA9771-0JJ44

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

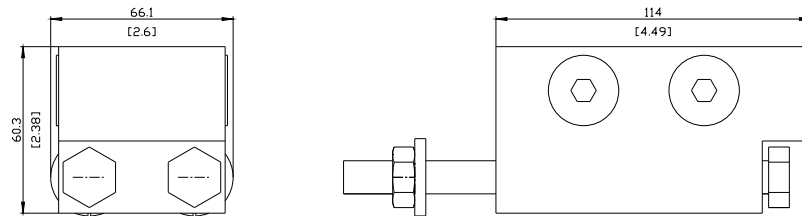

last modified:

11/27/2024 

