

# PL24V-CCT-WH

Under Cabinet



NAME:	
TYPE:	
DATE:	
NOTES:	

## SPECIFICATIONS


HOUSING DETAILS:	Includes: plastic housing, mounting bracket, 3 color finish trims and mounting screws. Trim: powder coated metal (white, black or bronze). Standard 72" wire lead.
ELECTRICAL:	<p>To be installed with a 24V driver. Recommended Driver: NDR Lighting TLD Driver Series.</p> <p>Mounting Options; Surface or Recessed mounting Suitable for Dry Location applications</p> <p>Technical Note: When using any of the NDR TLD 24V LED drivers, ensure to follow driver's listed minimum load requirement for proper dimming functions.</p>

BEAM ANGLE:	120°
COLOR TEMPERATURE:	2700K / 3000K / 4000K
SELECTABLE COLOR TEMPERATURE:	Yes
OPERATING TEMPERATURE:	-30°C (-22°F) to 40°C (104°F)
CRI:	90+
LUMEN OUTPUT:	120 Lumens
DIMMABLE:	Yes
WATTS:	3.5W
LED LIFE:	50,000 hours
WARRANTY:	5 years
VOLTAGE:	24V
DIAMETER:	3.5" (88mm)

## APPLICATIONS

The 24V LED puck lights are the most elegant solution to light your under-cabinet, bookcase, shelving or built in cabinet areas. With their ultra-thin profile (less than 0.33") and the edge lit technology, they provide a smooth diffused light output perfect to create a warm atmosphere. The PL24V-CCT item comes standard with selectable color temperature output of 2700K, 3000K or 4000K and the 3 powder coated magnetic trims (White, Black or Bronze) to suit any installation need.

DIMENSIONS

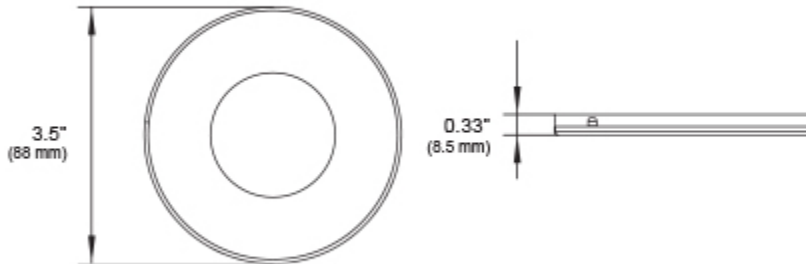

ACCESSORIES



**DRIVERS**

The pinnacle series 24v driver collection has been designed with complete flexibility in mind. the compact size with a profile height of less than 1.9" and a certificate for wet rated locations allows for unlimited installation applications. it meets all requirements for class 2 certification and is the recommended driver for use with our 24v pinnacle series led tape light. they are offered in five (5) wattage configurations to answer various installation

RATINGS

