


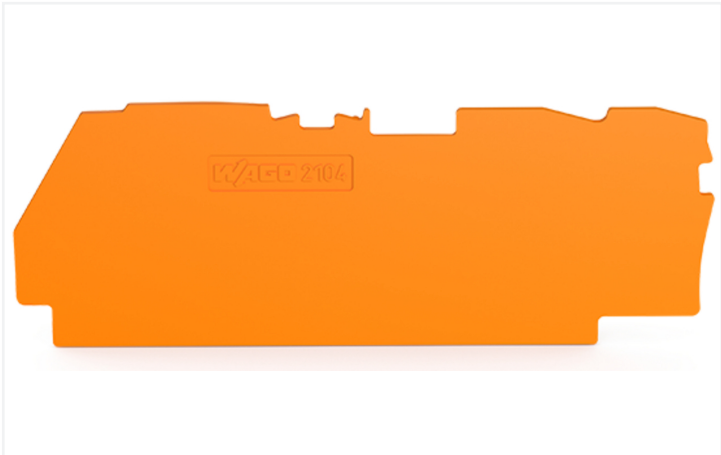

Color: ■ orange

| Physical data |                        |
|---------------|------------------------|
| Width         | 1 mm / 0.039 inches    |
| Height        | 82.7 mm / 3.256 inches |
| Depth         | 30.5 mm / 1.201 inches |

| Mechanical data |              |
|-----------------|--------------|
| Mounting type   | snap-on type |

| Material data                      |                                                                          |
|------------------------------------|--------------------------------------------------------------------------|
| Note (material data)               | <a href="#">Information on material specifications can be found here</a> |
| Color                              | orange                                                                   |
| Material group                     | I                                                                        |
| Insulation material (main housing) | Polyamide (PA66)                                                         |
| Flammability class per UL94        | V0                                                                       |
| Fire load                          | 0.079 MJ                                                                 |
| Weight                             | 2.7 g                                                                    |

| Environmental requirements       |                 |
|----------------------------------|-----------------|
| Processing temperature           | -35 ... +85 °C  |
| Continuous operating temperature | -60 ... +105 °C |

| Commercial data       |               |
|-----------------------|---------------|
| ETIM 9.0              | EC000886      |
| ETIM 8.0              | EC000886      |
| PU (SPU)              | 100 (25) pcs  |
| Packaging type        | Box           |
| Country of origin     | DE            |
| GTIN                  | 4055143975407 |
| Customs tariff number | 85389099990   |



| Environmental Product Compliance |                        |
|----------------------------------|------------------------|
| RoHS Compliance Status           | Compliant,No Exemption |