


IRRIGATION CABLE

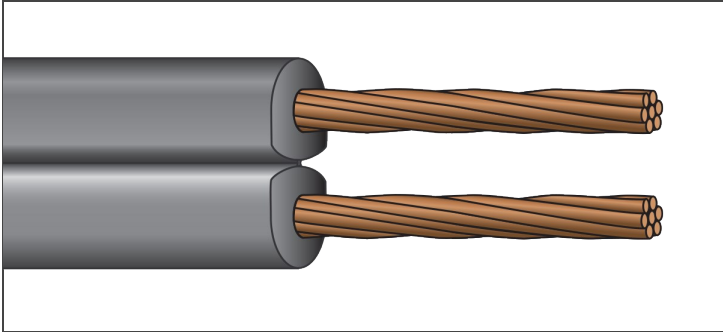

LANDSCAPE LIGHTING

ULECC or LVLL

30 Volt Copper



Description:

Extra flexible stranded copper conductors, configured flat and parallel with black PVC jacket. Conductors identified with ridges on the surface of the insulation.

Application:

Suitable for use in direct burial landscaping and lighting applications.

Standards:

ASTM Standards: B-174 (#16 AWG - #10 AWG), B-172 (#8 AWG)
 UL 1493

Temperature Rated at 60°C Wet/Dry

Acid, Alkali, Grease, Chemical, Abrasion, Crush, Oil, Moisture,
 Sunlight and Abrasion Resistant

Direct Burial

RoHS Compliant

Part Number	Conductor Solid (AWG)	Conductor Solid (no.)	Dimensions Insulation (in.)	Dimensions O.D (in.)	Standard Packaging (100')	Standard Packaging (250')	Standard Packaging (500')	Standard Packaging (1,000')	Weight (lb./1000')
ULE16/2	16/2	26	0.045	0.30 x 0.15			X		34
ULE14/2	14/2	41	0.045	0.33 x 0.16	X		X		46
ULE12/2	12/2	65	0.045	0.30 x 0.18	X	X	X	X	64
ULE10/2	10/2	104	0.045	0.41 x 0.21	X	X	X	X	91
ULE8/2	8/2	168	0.060	0.53 x 0.26	X		X		147

NOTE: The data shown is approximate and subject to standard industry tolerances.