


Unshielded Multi-Conductor FT4 600 Volts CSA

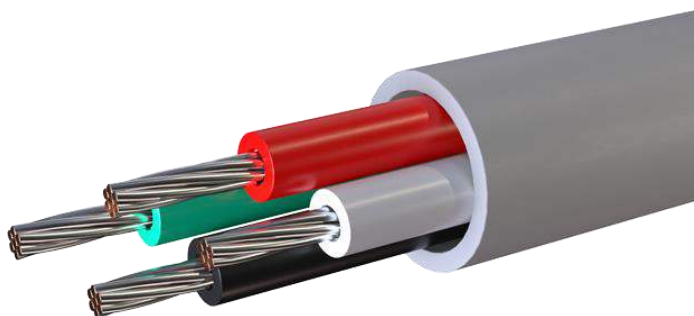

Stranded Tinned Copper Conductors, SR-PVC Insulation, Grey PVC Jacket FT-4, -20° C to 105° C, 600 Volts, CSA and UL Approved.

Specifications and Compliance

CSA Certified CMG/UL listed to CM harmonized standard C22.2 No. 214 and UL 444 Certified to CSA C22.2 No. 210.2 - Type AWM.

Flame test compliances: FT4 - CMG

22 awg

RW Item #	Conductor			Wall Thickness		Nominal O.D. (inches)	Total Weight (lbs/km)	Colour Code Chart
	AWG No.	Size	Stranding	Insulation (inches)	Jacket (inches)			
E22-02CA0-BR	2	22	7 x 30	.010	.015	.131	40	Black/Red
E22-02CA0	2	22	7 x 30	.010	.015	.131	40	1
E22-03CA0-BRG	3	22	7 x 30	.010	.015	.139	47	Black/Red/Green
E22-03CA0	3	22	7 x 30	.010	.015	.139	47	2
E22-04CA0	4	22	7 x 30	.010	.015	.152	60	1
E22-05CA0	5	22	7 x 30	.010	.015	.160	73	1
E22-06CA0	6	22	7 x 30	.010	.023	.192	107	1
E22-07CA0	7	22	7 x 30	.010	.023	.203	113	1
E22-08CA0	8	22	7 x 30	.010	.023	.215	127	1
E22-09CA0	9	22	7 x 30	.010	.023	.225	140	1
E22-10CA0	10	22	7 x 30	.010	.023	.234	153	1
E22-12CA0	12	22	7 x 30	.010	.023	.251	180	1
E22-15CA0	15	22	7 x 30	.010	.023	.275	213	2
E22-16CA0	16	22	7 x 30	.010	.023	.285	226	2
E22-18CA0	18	22	7 x 30	.010	.023	.290	230	2
E22-20CA0	20	22	7 x 30	.010	.030	.323	286	2
E22-25CA0	25	22	7 x 30	.010	.030	.354	346	2
E22-30CA0	30	22	7 x 30	.010	.030	.381	413	2
E22-40CA0	40	22	7 x 30	.010	.030	.432	526	2
E22-50CA0	50	22	7 x 30	.010	.035	.493	640	2

All dimensions are nominal and are subject to normal manufacturing tolerance. Specifications are subject to change without notice.

Unshielded Multi-Conductor FT4 600 Volts CSA

Application

- PA systems
- Unbalanced intercom systems
- Interconnecting cables
- Remote control circuits
- Low voltage
- Broadcast & studio use
- Temperature control systems

Features

- Grey FT4 CMG Rated jacket
- Dual rated CSA/UL
- Versatile application cable
- Rohs Compliant

Colour Coding

Chart #1

Conductor		Conductor		Conductor	
Number	Colour	Number	Colour	Number	Colour
1	Black	5	Brown	9	Purple
2	White	6	Blue	10	Grey
3	Red	7	Orange	11	Pink
4	Green	8	Yellow	12	Tan

Chart #2

Conductor		Conductor		Conductor		Conductor	
Number	Colour	Number	Colour	Number	Colour	Number	Colour
1	Black	14	Green/White	27	Blue/Black/White	40	Red/White/Green
2	White	15	Blue/White	28	Black/Red/Green	41	Green/White/Blue
3	Red	16	Black/Red	29	White/Red/Green	42	Orange/Red/Green
4	Green	17	White/Red	30	Red/Black/Green	43	Blue/Red/Green
5	Orange	18	Orange/Red	31	Green/Black/Orange	44	Black/White/Blue
6	Blue	19	Blue/Red	32	Orange/Black/Green	45	White/Black/Blue
7	White/Black	20	Red/Green	33	Blue/White/Orange	46	Red/White/Blue
8	Red/Black	21	Orange/Green	34	Black/White/Orange	47	Green/Orange/Red
9	Green/Black	22	Black/White/Red	35	White/Red/Orange	48	Orange/Red/Blue
10	Orange/Black	23	White/Black/Red	36	Orange/White/Blue	49	Blue/Orange/Red
11	Blue/Black	24	Red/Black/White	37	White/Red/Blue	50	Black/Orange/Red
12	Black/White	25	Green/Black/White	38	Black/White/Green		
13	Red/White	26	Orange/Black/White	39	White/Black/Green		

All dimensions are nominal and are subject to normal manufacturing tolerance. Specifications are subject to change without notice.