

PLIERS

INSULATED PLIERS

- 1000V: CERTIFIED TO IEC 60900 AND ASTM F1505 STANDARDS
- BLADES ARE FULLY FORGED AND HARDENED FOR EASY CUTS
- ERGONOMIC GRIP FOR COMFORTABLE HANDLING




PART #	DESCRIPTION	
48-22-2208	1000V Insulated Diagonal Cutting Pliers 203mm (8")	NEW
48-22-2209	1000V Insulated Lineman's Pliers 228mm (9")	NEW
48-22-2214	1000V Insulated 10-20 AWG Wire Stripper & Cutter	NEW
48-22-2215	5pc 1000V Insulated Hand Tools (48-22-2208, 48-22-2209, 48-22-2214, 48-22-2207 (PH2 x 4" and SL1/4" x 4")	NEW



WIRE STRIPPERS/COMBINATION PLIERS

- REINFORCED HEAD: ACCURATE STRIPPING
- HIGH CONTRAST MARKINGHIGH CONTRAST MARKING
- SMOOTH CUTS

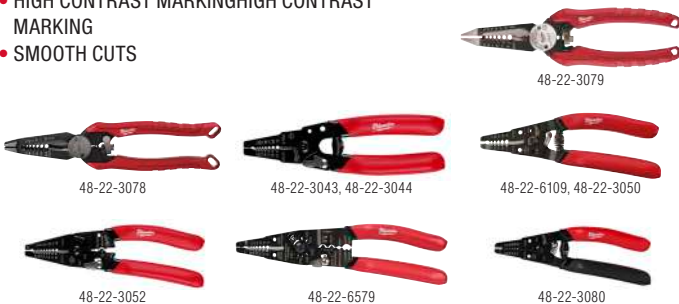

PART #	DESCRIPTION	WIRE STRIPPER	GRIP
48-22-3079	6-in-1 Combination Pliers	8-18 AWG Solid, 10-20 AWG Stranded	Comfort
48-22-3078	7-in-1 High Leverage Combination Pliers	10-20 AWG Solid, 12-22 AWG Stranded	Comfort
48-22-3043	Compact Dipped Grip Wire Stripper	10-22 AWG Solid, 12-24 AWG Stranded	Dipped NEW
48-22-3044	Compact Comfort Grip Wire Stripper	10-12 AWG Solid, 12-24 AWG Stranded	Comfort NEW
48-22-6109	Wire Stripper/Cutter For Solid & Stranded Wire	10-18 AWG Solid, 12-20 AWG Stranded	Dipped
48-22-3050	General Purpose Wire Stripper & Cutter	10-18 AWG Solid, 12-20 AWG Stranded	Comfort NEW
48-22-3052	Multi-Purpose Wire Stripper & Crimper w/ Reinforced Head	10-26 AWG Solid, 12-28 AWG Stranded	Dipped NEW
48-22-6579	Multi Purpose Wire Stripper w/ Crimper	10-20 AWG Solid, 12-22 AWG Stranded	Dipped
48-22-3080	Low Voltage Wire Stripper & Cutter	20-30 AWG Solid, 22-32 AWG Stranded	Dipped NEW

PLUMBING PLIERS

- SLIM HEAD DESIGN
- REAMING HANDLES
- ALL-METAL ADJUSTMENT MECHANISM



PART #	DESCRIPTION
48-22-6208	Hex Jaw Pliers (8")
48-22-6210	Hex Jaw Pliers (10")
48-22-6550	Hex Jaw Pliers - Dipped Grip (10")
48-22-6212	Hex Jaw Pliers (12")
48-22-6552	Hex Jaw Pliers - Dipped Grip (12")
48-22-6306	Straight Jaw Pliers (6")
48-22-6310	Straight Jaw Pliers (10")
48-22-6510	Straight Jaw Pliers - Dipped Grip (10")
48-22-6312	Straight Jaw Pliers (12")
48-22-6512	Straight Jaw Pliers - Dipped Grip (12")
48-22-6316	Straight Jaw Pliers (16")
48-22-6320	Straight Jaw Pliers (20")
48-22-6330	Straight Jaw Pliers Set (6") (10")

TORQUE LOCK LOCKING PLIERS

- FASTER SET UP AND EASY RELEASE WHEN CLAMPING FLAT AND ROUND MATERIALS FOR WELDING
- TORQUE LOCK SCREW FOR BETTER AND MORE SECURE GRIP
- CHROME PLATED TOOL REDUCE CORROSION



PART #	DESCRIPTION
48-22-3405	TORQUE LOCK Curved Jaw Locking Pliers with Durable Grip 127mm (5")
48-22-3407	TORQUE LOCK Curved Jaw Locking Pliers with Durable Grip 177mm (7")
48-22-3410	TORQUE LOCK Curved Jaw Locking Pliers with Durable Grip 254mm (10")
48-22-3423	TORQUE LOCK Curved Jaw Locking Pliers 101mm (4")
48-22-3422	TORQUE LOCK Curved Jaw Locking Pliers 127mm (5")
48-22-3421	TORQUE LOCK Curved Jaw Locking Pliers 177mm (7")
48-22-3420	TORQUE LOCK Curved Jaw Locking Pliers 254mm (10")
48-22-3406	TORQUE LOCK Long Nose Locking Pliers with Durable Grip 152mm (6")
48-22-3409	TORQUE LOCK Long Nose Locking Pliers with Durable Grip 228mm (9")
48-22-3504	TORQUE LOCK Long Nose Locking Pliers 101mm (4")
48-22-3506	TORQUE LOCK Long Nose Locking Pliers 152mm (6")
48-22-3509	TORQUE LOCK Long Nose Locking Pliers 128mm (9")
48-22-3807	TORQUE LOCK Straight Jaw Locking Pliers with Durable Grip 177mm (7")
48-22-3810	TORQUE LOCK Straight Jaw Locking Pliers with Durable Grip 254mm (10")
48-22-3507	TORQUE LOCK Straight Jaw Locking Pliers 177mm (7")
48-22-3510	TORQUE LOCK Straight Jaw Locking Pliers 254mm (10")
48-22-3607	TORQUE LOCK MAXBITE CURVED JAW LOCKING PLIERS 177mm (7")
48-22-3610	TORQUE LOCK MAXBITE CURVED JAW LOCKING PLIERS 254mm (10")
48-22-3707	TORQUE LOCK Gripped Curved Jaw Locking Pliers with MAXBITE™ 177mm (7")
48-22-3710	TORQUE LOCK Gripped Curved Jaw Locking Pliers with MAXBITE™ 254mm (10")

SCREWDRIVERS & NUTDRIVERS

INSULATED SCREWDRIVERS

- 1000V: CERTIFIED TO IEC 60900 AND ASTM F1505 STANDARDS
- COMFORTABLE TRI-LOBE HANDLE OPTIMIZED FOR MAXIMUM USER COMFORT AND HIGH TORQUE APPLICATIONS
- PERMANENT VISIBLE ID MARKINGS ALLOWS FOR QUICK TOOL IDENTIFICATION



PART #	DESCRIPTION	TIP SIZES
48-22-2211	#1 Phillips - 76mm (3") 1000V Insulated Screwdriver	
48-22-2212	#2 Phillips - 101mm (4") 1000V Insulated Screwdriver	
48-22-2213	#3 Phillips - 152mm (6") 1000V Insulated Screwdriver	
48-22-2221	1/4" Slotted - 152mm (6") 1000V Insulated Screwdriver	
48-22-2222	5/16" Slotted - 177mm (7") 1000V Insulated Screwdriver	
48-22-2223	3/8" Slotted - 203mm (8") 1000V Insulated Screwdriver	
48-22-2224	3/8" Slotted - 254mm (10") 1000V Insulated Screwdriver	
48-22-2231	3/16" Cabinet - 101mm (4") 1000V Insulated Screwdriver	
48-22-2232	3/16" Cabinet - 152mm (6") 1000V Insulated Screwdriver	
48-22-2233	3/16" Cabinet - 203mm (8") 1000V Insulated Screwdriver	
48-22-2210	10pc 1000V Insulated Screwdriver Set w/ EVA Foam Case	PH1 x 3", PH2 x 4", PH3 X 6", SL1/4" X 6", SL 5/16" X 7", SL3/8" X 8", SQ1 x 3", SQ2 x 4", SQ3 x 6", ECX1 x 4"
48-22-2204	4pc 1000V Insulated Screwdriver Set w/ Roll Pouch	PH1 x 3", PH2 x 4", SL1/4" x 6", SL3/8" x 8"
48-22-2207	2pc 1000V Insulated Slim Tip Screwdriver Set	SL1/4" x 4", PH2 x 4"
48-22-2219	4pc 1000V Insulated Slim Tip Screwdriver Set	PH2 x 4", SL3/16" x 6", SL1/4" x 4", SQ2 x 6"
48-22-2206	6pc 1000V Insulated Slim Tip Screwdriver Set	PH1 x 6", PH2 x 4", PH2 x 6", SL3/16" x 6", SL1/4" x 4", SQ2 x 6"

INSULATED MULTI BIT SCREWDRIVERS

- 1000V: CERTIFIED TO IEC 60900 AND ASTM F1505 STANDARDS
- SIZE ID ON EVERY BIT FOR QUICK IDENTIFICATION
- MOST VERSATILE - EASILY CHANGE BITS



PART #	DESCRIPTION	TIP SIZES
48-22-2216	4-in-1 1000V Insulated Slim Tip Multi-Bit Screwdriver	PH2, SL1/4", SL3/16", SQ2
48-22-2218	8-in-1 1000V Insulated Slim Tip Multi-Bit Screwdriver	PH1, PH2, SL1/4", SL3/16", SQ1, SQ2, ECX1, ECX2
48-22-2217	8-in-1 1000V Insulated Precision Multi-Bit Screwdriver	PH00, PH0, SL1/8", SL3/32", TS7, TS8, TS10, TS15

HOOK & PICK

- ALL-METAL CORE FOR LONG-LASTING DURABILITY AND RUST PROTECTION
- CHROME-PLATED SHANKS REDUCE CORROSION AND PROVIDE RUST PROTECTION
- COMFORT GRIP HANDLE AND PRECISION KNURLING INCREASE TOOL CONTROL AND USER COMFORT



PART #	DESCRIPTION
48-22-9215	4pc Hook & Pick Set
48-22-9217	4pc Hook & Pick Heavy Duty Set
48-22-9218	8pc Hook & Pick Combo Set
45-74-9211	Hose Pick - Flat Tip
45-74-9215	Hose Pick - Hook
45-74-9213	Hose Pick - Bent 90 Degree
45-74-9214	Hose Pick - Bent 45 Degree

HOLLOWCORE NUTDRIVERS

- HOLLOWCORE UNLIMITED DEPTH
- 6 POINT HEAD
- COLOR CODED ID



PART #	DESCRIPTION	INCLUDES
48-22-2542	2pc SAE HOLLOWCORE Magnetic Nut Driver Set	1/4", 5/16"
48-22-2544	4pc SAE HOLLOWCORE Magnetic Nut Driver Set	1/4", 5/16", 7/16", 9/16"
48-22-2547	7pc SAE HOLLOWCORE Magnetic Nut Driver Set	1/4", 5/16", 11/32", 3/8", 7/16", 1/2", 9/16"
48-22-2548	7pc Metric HOLLOWCORE Magnetic Nut Driver Set	5mm, 5.5mm, 6mm, 7mm, 8mm, 10mm, 13mm

PRECISION SCREWDRIVERS

- EXTENDED REACH
- ALL-METAL CORE
- COLOR CODED MARKINGS



PART #	DESCRIPTION	TIP SIZES
48-22-2604	4pc Precision Screwdriver Set	PH1, SL1/16", SL3/32", SL1/8"
48-22-2606	6pc Precision Screwdriver Set	PH00, PH0, SL1/16", SL3/32", SL1/8", SL5/32"
48-22-2610	6pc Precision Screwdriver Set	T6, T7, T8, T9, T10, T15
48-22-2612	10pc Precision Screwdriver Set	PH00, PH0, SL3/32", SL1/8", T6, T7, T8, T9, T10, T15
48-22-2614	8pc Precision Screwdriver Set	H000, PH00, PH0, PH1, SL1/16", SL3/32", SL1/8", SL5/32"

DEMO SCREWDRIVER SET

- HAMMER READY STRIKE CAPS
- ALL-METAL CORE
- COMFORTABLE TRI-LOBE HANDLE



PART #	DESCRIPTION	TIP SIZES
48-22-2702	2pc Demo Screwdriver Set	PH6 x 6", SL5/16" x 6"