 



SNAP-ON™ WIRE MARKERS

- Temperature range: -20°C to 60°C.
TECHSPAN® Snap-on Marker system is permanent since there is no adhesive to dry out.
- Easily marks pre-connected wires and marks wires in areas with limited space.
- Excellent for marking wires with more than 2 digits legends.

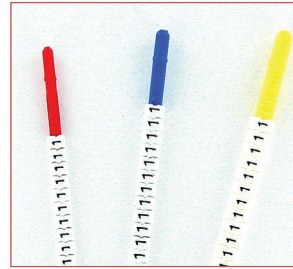

SIZE S6
FOR WIRE SIZES*
AWG 18-16
.106"
(2.7 mm) **Made of Nylon**

Part #	LEGEND
S6-0	0
S6-1	1
thru	thru
S6-9	9
*S6-0-9	0 thru 9
S6-A	A
thru	thru
S6-Z	Z
S6-+	+
S6-MINUS	-
S6-BLANK	BLANK

30 identical markers per wand
Numbers sold in 10 wands per pack
*10 pack- 1 wand of 0, 1 wand of 1, etc.

SIZE S9
FOR WIRE SIZES*
AWG 16-14
.114"
(2.9 mm) **Made of Nylon**

Part #	LEGEND
S9-0	0
S9-1	1
thru	thru
S9-9	9
*S9-0-9	0 thru 9
S9-A	A
thru	thru
S9-Z	Z
S9-+	+
S9-MINUS	-
S9-BLANK	BLANK

30 identical markers per wand
Numbers sold in 10 wands per pack
*10 pack- 1 wand of 0, 1 wand of 1, etc.

SIZE S12
FOR WIRE SIZES*
AWG 12-10
.173"
(4.4 mm) **Made of Nylon**

Part #	LEGEND
S12-0	0
S12-1	1
thru	thru
S12-9	9
*S12-0-9	0 thru 9
S12-A	A
thru	thru
S12-Z	Z
S12-+	+
S12-MINUS	-
S12-BLANK	BLANK

30 identical markers per wand
Numbers sold in 10 wands per pack
*10 pack- 1 wand of 0, 1 wand of 1, etc.


Z-MARKERS



- Soft durable PVC
- Service temperature of 85°C
- Black lettering on white background

CABLE MARKER SPOOLS			
Part #	WIRE SIZE	QTY/ROLL	STD. MARKING
CMA-1814-__	18-14 AWG	1000	Solid Number or Letter Per Roll 0, 1, 2...9 A, B, C...Z
CMA-1412-__	14-12 AWG	1000	
CMA-108-__	10-8 AWG	500	
CMA-84-__	8-4 AWG	250	

K-MARKERS

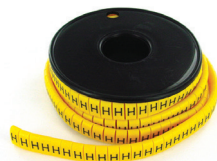

- K-Markers**
- Soft durable PVC
 - Service temperature of 85°C
 - Black lettering on yellow background

K-Marker Carriers

- Nylon 66
- UL 94-2

K-MARKERS			
Part #	DIAMETER RANGE mm²	QTY/ROLL	STD. MARKING
CMC-128-__	3.5-7.0	500	0-9, A-Z, +, -, /, m

K-MARKER CARRIERS (use with 50lb cable tie max.)		
Part #	DESCRIPTION	PCS/ BAG
PKH070	70mm (9 markers)	100
PKH110	100mm (16 markers)	100

