


CABLE CLAMPS & CLIPS

A



- Fully Radiused Inside Edges with Size Markings in Inches and Millimeters for Easy Identification
- Stocked in Natural White and Black 6/6 Nylon 94 V-2
- 11 Diameters and 5 Widths with Mounting Holes for #4 through #10 Screws
- Non-Conductive, Non-Corrosive; Resistant to Fuels, Lubricants and most Chemicals

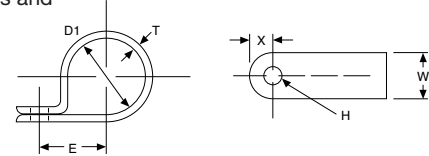

Part no.		D1 Closed Diameter		E		T Thickness		W Width		H Hole Diameter		X		Per Package
White	Black	Inch	(mm)	Inch	(mm)	Inch	(mm)	Inch	(mm)	Inch	(mm)	Inch	(mm)	
766046C	767046C	.126	(3.2)	.355	(9.0)	.060	(1.5)	.512	(13.0)	.205	(5.2)			100
766500C	767500C	.170	(4.3)	.414	(1.5)	.060	(1.5)	.414	(1.5)	.205	(5.2)			
766076C	767076C	.248	(6.3)	.414	(1.5)	.060	(1.5)	.374	(9.5)	.189	(4.8)			
766053C	767053C	.300	(7.6)	.414	(1.5)	.060	(1.5)	.374	(9.5)	.189	(4.8)			
766054C	767054C	.343	(8.7)	.493	(12.5)	.060	(1.5)	.488	(12.4)	.189	(4.8)			
766047C	767047C	.496	(12.6)	.591	(15.0)	.060	(1.5)	.473	(12.0)	.189	(4.8)			
766077C	767077C	.622	(15.8)	.709	(18.0)	.060	(1.5)	.473	(12.0)	.189	(4.8)			
766078C	767078C	.764	(19.4)	.709	(18.0)	.060	(1.5)	.473	(12.0)	.189	(4.8)			
766079C	767079C	1.000	(25.4)	.866	(22.0)	.060	(1.5)	.473	(12.0)	.189	(4.8)			
766050C	767050C	1.252	(31.8)	1.024	(26.0)	.060	(1.5)	.473	(12.0)	.189	(4.8)			
766503C	767503C	1.445	(36.7)	1.187	(3.0)	.060	(1.5)	.473	(12.0)	.189	(4.8)			
Tolerance ±		.010 (.254)	.030 (.762)	.005 (.127)	.015 (.381)	.010 (.254)	.030 (.762)							

MARKING PENS

MKR-PEN-2	Red Marking Pen
MKR-PEN-6	Blue Marking Pen
MKR-PEN-0	Black Marking Pen

Ideal for marking applications. Permanently marks most materials, including plastics. Quick drying; fine point.

