




APPLICATION SPECIFIC PLIERS

IRONWORKER'S PLIERS

UP TO 2X MORE CUTS

IRON-CARBIDE EDGE

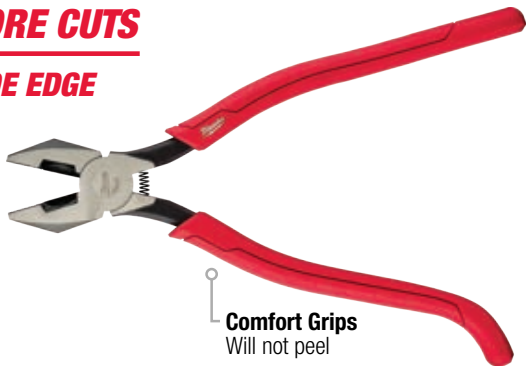

Comfort Grips
Will not peel



For Twisting & Cutting Rebar Ties

Model #	Description
48-22-6102	Ironworker's Pliers

CABLE CUTTING PLIERS

CLEAN CUTS



Comfort Grips
Will not peel



Cuts up to 2/0 Cu, 4/0 Al

Model #	Description
48-22-6104	Cable Cutting Pliers

NIPPING PLIERS

CURVED HEAD.
PROTECTS SURFACES.



Comfort Grips
Will not peel



Blades Will Not Mar Surfaces

Model #	Description
48-22-6407	7" Nipping Pliers

CRIMPING PLIERS

UP TO 2X CRIMPING FORCE



Reaming Head

Wire Cutter

Comfort Grips
Will not peel



Crimper for Insulated & Non-Insulated Terminals

Model #	Description
48-22-6103	Crimping Pliers

PVC / OIL FILTER PLIERS

3-1/2" JAW CAPACITY



Comfort Grips
Will not peel



3.5" Jaw Capacity

Model #	Description
48-22-6321	PVC / Oil Filter Pliers

FENCING PLIERS

FORGED STRENGTH



Staple Gripper

Staple Puller

Wire Cutter

Wire Crimper

Hammer

Comfort Grips
Will not peel



Wire Puller

Model #	Description
48-22-6410	Fencing Pliers

TORQUE LOCK™ PLIERS, C-CLAMPS & SPECIALTY

TORQUE LOCK™
FASTER SET-UP



LOCKING PLIERS w/ MAX BITE™

MAX BITE™
3X GRIPPING FORCE



CHROME
Chrome plated rust protection



GRIPPED
Rubber overmold

Model #	Description
48-22-3607	7" TORQUE LOCK™ MAX BITE™ Curved Jaw Locking Pliers
48-22-3610	10" TORQUE LOCK™ MAX BITE™ Curved Jaw Locking Pliers
48-22-3702	2 Pc 7" & 10" TORQUE LOCK™ MAX BITE™ Curved Jaw Locking Pliers

Model #	Description
48-22-3710	10" TORQUE LOCK™ MAX BITE™ Curved Jaw Locking Pliers w/ Grip
48-22-3707	7" TORQUE LOCK™ MAX BITE™ Curved Jaw Locking Pliers w/ Grip

LOCKING PLIERS



CURVED JAW
Maximizes pressure points for any bolt, nut or locking tool application



STRAIGHT JAW
Maximizes contact points on jobsite work surfaces



LONG NOSE
Best for long reach applications

Model #	Description
48-22-3405	5" TORQUE LOCK™ Curved Jaw Locking Pliers w/ Grip
48-22-3407	7" TORQUE LOCK™ Curved Jaw Locking Pliers w/ Grip
48-22-3410	10" TORQUE LOCK™ Curved Jaw Locking Pliers w/ Grip
48-22-3406	6" TORQUE LOCK™ Long Nose Locking Pliers w/ Grip
48-22-3409	9" TORQUE LOCK™ Long Nose Locking Pliers w/ Grip
48-22-3807	7" TORQUE LOCK™ Straight Jaw Locking Pliers w/ Grip
48-22-3810	10" TORQUE LOCK™ Straight Jaw Locking Pliers w/ Grip
48-22-3402	2 Pc 7" & 10" TORQUE LOCK™ Curved Jaw Locking Pliers w/ Grip Set
48-22-3602	2 Pc. 10" Curved Jaw & 6" Long Nose TORQUE LOCK™ Locking Pliers Set
48-22-3423	4" TORQUE LOCK™ Curved Jaw Locking Pliers

Model #	Description
48-22-3422	5" TORQUE LOCK™ Curved Jaw Locking Pliers
48-22-3421	7" TORQUE LOCK™ Curved Jaw Locking Pliers
48-22-3420	10" TORQUE LOCK™ Curved Jaw Locking Pliers
48-22-3504	4" TORQUE LOCK™ Long Nose Locking Pliers
48-22-3506	6" TORQUE LOCK™ Long Nose Locking Pliers
48-22-3507	7" TORQUE LOCK™ Straight Jaw Locking Pliers
48-22-3509	9" TORQUE LOCK™ Long Nose Locking Pliers
48-22-3510	10" TORQUE LOCK™ Straight Jaw Locking Pliers
48-22-3541	12" TORQUE LOCK™ Large Jaw Locking Pliers

C-CLAMPS & SPECIALTY

STANDARD JAW C-CLAMP
Greater clamping versatility on a variety of shapes and surfaces



SWIVEL JAW C-CLAMP
Pads provide surface stabilization and protect work surfaces from damage



Model #	Description
48-22-3521	11" TORQUE LOCK™ Swivel Jaw Locking C-Clamp
48-22-3522	6" TORQUE LOCK™ Swivel Jaw Locking C-Clamp
48-22-3531	11" TORQUE LOCK™ Locking C-Clamp
48-22-3532	6" TORQUE LOCK™ Locking C-Clamp
48-22-3520	18" TORQUE LOCK™ Swivel Jaw Locking C-Clamp
48-22-3529	18" TORQUE LOCK™ Deep Reach Locking C-Clamp
48-22-3530	18" TORQUE LOCK™ Locking C-Clamp

Model #	Description
48-22-3540	8" TORQUE LOCK™ Locking Seamer
48-22-3542	9" TORQUE LOCK™ Locking Chain Wrench
48-22-3543	9" TORQUE LOCK™ Locking Welding Clamp
48-22-3523	9" TORQUE LOCK™ Deep Reach Swivel Jaw Locking C-Clamp
48-22-3533	9" TORQUE LOCK™ Deep Reach Locking C-Clamp
48-22-3631	11" TORQUE LOCK™ Locking C-Clamp
48-22-3632	6" TORQUE LOCK™ Locking C-Clamp

CHEATER

CHEATER ALUMINUM ADAPTABLE PIPE WRENCH

MOST ADAPTABLE.
ALL-IN-ONE.

Lightweight Aluminum Body

Longer Spine
For increased capacity

QUICK-ADJUST HANDLE
11"-24"

OVERBITE JAW™
Largest Grip Surface

11" Length
For tight spaces

MULTI LENGTH DESIGN
18" – 24" Length
For general purpose – maximum leverage



Ergonomic Handle
Maximum Comfort

Model #	Description	Material	Max Jaw Capacity
48-22-7318	CHEATER Aluminum Adaptable Pipe Wrench	Aluminum	2-1/2"

CHEATER STEEL ADAPTABLE PIPE WRENCH

3 LENGTH DESIGN

MAXIMUM LEVERAGE
24"

GENERAL PURPOSE
18"

TIGHT SPACES
10"

Dual Coil Spring Design
Increased durability and life

OVERBITE JAW™
Largest Grip Surface

Lanyard Hole

Threaded Fit & Security



Hardened Jaws
Increased Durability and Grip

Model #	Description	Material	Max Jaw Capacity
48-22-7314	CHEATER Steel Adaptable Pipe Wrench	Steel	2-1/2"

STEEL & ALUMINUM PIPE WRENCHES

LARGEST GRIP SURFACE



Steel



Aluminum

Dual Coil Spring Design
Increased durability and life

Lanyard Hole

OVERBITE JAW™
Largest Grip Surface

Ergonomic Handle

Model #	Description	Length	Material	Max Jaw Capacity
48-22-7106	6" Steel Pipe Wrench	6"	Steel	3/4"
48-22-7108	8" Steel Pipe Wrench	8"	Steel	1"
48-22-7110	10" Steel Pipe Wrench	10"	Steel	1-1/2"
48-22-7112	12" Steel Pipe Wrench	12"	Steel	2"
48-22-7114	14" Steel Pipe Wrench	14"	Steel	2"
48-22-7118	18" Steel Pipe Wrench	18"	Steel	2-1/2"
48-22-7124	24" Steel Pipe Wrench	24"	Steel	3"
48-22-7136	36" Steel Pipe Wrench	36"	Steel	5"
48-22-7148	48" Steel Pipe Wrench	48"	Steel	6"

Model #	Description	Length	Material	Max Jaw Capacity
48-22-7160	60" Steel Pipe Wrench	60"	Steel	8"
48-22-7210	10" Aluminum Pipe Wrench	10"	Aluminum	1-1/2"
48-22-7212	12" Aluminum Pipe Wrench	12"	Aluminum	2"
48-22-7214	14" Aluminum Pipe Wrench	14"	Aluminum	2"
48-22-7218	18" Aluminum Pipe Wrench	18"	Aluminum	2-1/2"
48-22-7224	24" Aluminum Pipe Wrench	24"	Aluminum	3"
48-22-7236	36" Aluminum Pipe Wrench	36"	Aluminum	5"
48-22-7248	48" Aluminum Pipe Wrench	48"	Aluminum	6"

STEEL OFFSET HEX PIPE WRENCH

SMOOTH JAW WON'T MAR SURFACES



Protects Chrome Surfaces

Offset Jaw
Better access

Secure Grip
Up to 3 points of contact

Smooth Jaws

Lanyard Hole

Ergonomic Handle

Model #	Description	Material	Max Jaw Capacity
48-22-7171	Steel Offset Hex Pipe Wrench	Steel	2-5/8"

STEEL SMOOTH JAW PIPE WRENCH

SMOOTH JAW PROTECTS SURFACES



Protects Chrome Surfaces

Parallel Grip

Smooth Jaws

Lanyard Hole

Ergonomic Handle

Model #	Description	Material	Max Jaw Capacity
48-22-7186	12" Steel Smooth Jaw Pipe Wrench	Steel	2-5/8"

ALUMINUM OFFSET HEX PIPE WRENCHES

BETTER ACCESS



Offset Head

Model #	Description	Material	Max Jaw Capacity
48-22-7184	14" Aluminum Offset Pipe Wrench	Aluminum	2"
48-22-7185	18" Aluminum Offset Pipe Wrench	Aluminum	2"
48-22-7182	24" Aluminum Offset Pipe Wrench	Aluminum	3"

10L ALUMINUM PIPE WRENCH w/ POWERLENGTH™ HANDLE

BETTER ACCESS.
MAXIMUM LEVERAGE.





Jaw Capacity 1-1/2"

Model #	Description	Material	Max Jaw Capacity
48-22-7313	10L Aluminum Pipe Wrench w/ POWERLENGTH™ Handle	Aluminum	1-1/2"

ADJUSTABLE WRENCHES

JAWS WON'T
BACK OFF
Proprietary Screw

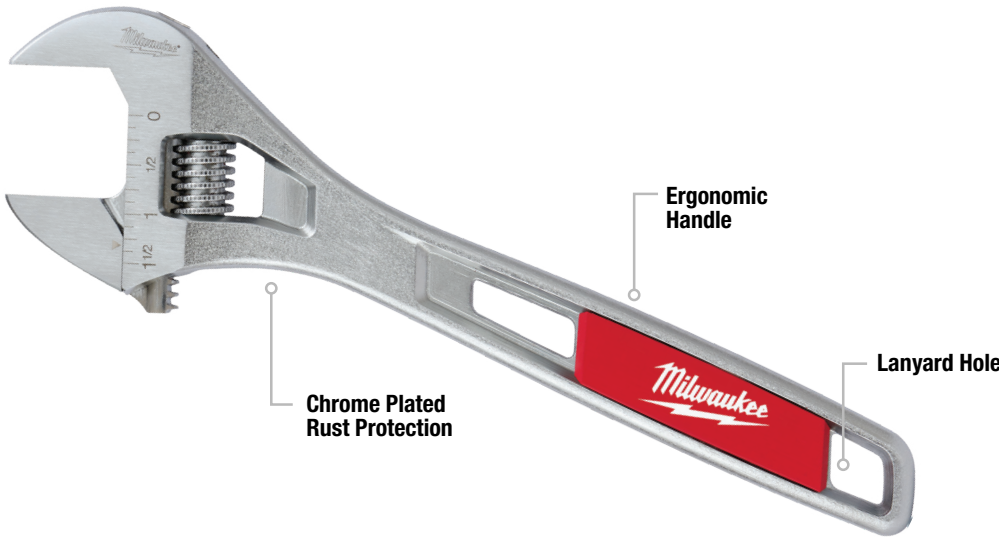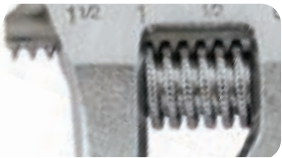

Perfectly Parallel Jaws

Model #	Description
48-22-7400	2 Pc 6" & 10" Adjustable Wrench Set
48-22-7406	6" Adjustable Wrench
48-22-7408	8" Adjustable Wrench
48-22-7410	10" Adjustable Wrench
48-22-7412	12" Adjustable Wrench
48-22-7415	15" Adjustable Wrench
48-22-7508	8" Wide Jaw Adjustable Wrench

BASIN WRENCHES


EASIEST
SWAP-OUTS



Ratchet-Ready
Less jaw readjusting



Screwdriver-Ready
Up to 2X breakaway torque

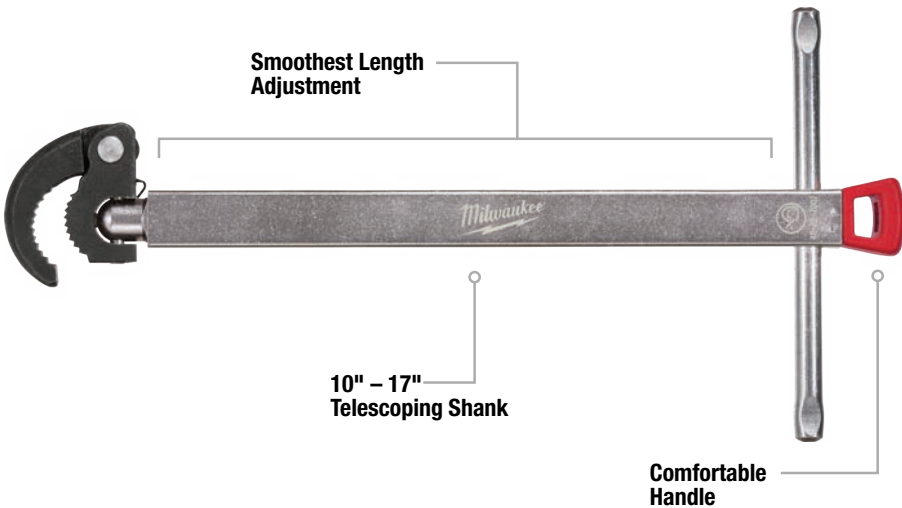

Model #	Description
48-22-7001	1-1/4" Basin Wrench
48-22-7002	2-1/2" Basin Wrench