



STUD™

STUD™ TAPE MEASURES

INDUSTRY'S MOST DURABLE TAPE MEASURE

17' REACH*



Rip & Wear Resistant Blade


Model #	Description
48-22-9716	16ft STUD™ Tape Measure w/ 16' Reach*
48-22-9725	25ft STUD™ Tape Measure w/ 17' Reach*
48-22-9735	35ft STUD™ Tape Measure w/ 17' Reach*

Model #	Description
48-22-9717	5m/16ft STUD™ Tape Measure w/ 16' Reach*
48-22-9726	8m/26ft STUD™ Tape Measure w/ 17' Reach*
48-22-9725M	25ft STUD™ Magnetic Tape Measure w/ 17' Reach*

WIDE BLADE TAPE MEASURES

LONGEST REACH STRAIGHTEST STANDOUT†

17' REACH*

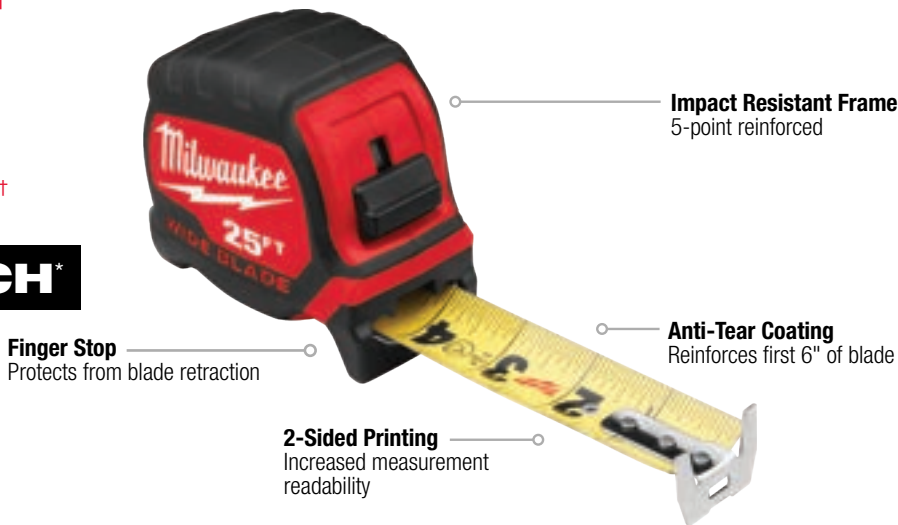


Long Reach for Efficient Measuring

Model #	Description
48-22-0216	16ft Wide Blade Tape Measure w/ 16' Reach*
48-22-0225	25ft Wide Blade Tape Measure w/ 17' Reach*
48-22-0230	30ft Wide Blade Tape Measure w/ 17' Reach*
48-22-0235	35ft Wide Blade Tape Measure w/ 17' Reach*
48-22-0240	40ft Wide Blade Tape Measure w/ 17' Reach*

Model #	Description
48-22-0217	5m/16ft Wide Blade Tape Measure w/ 16' Reach*
48-22-0226	8m/26ft Wide Blade Tape Measure w/ 17' Reach*
48-22-0216M	16ft Wide Blade Magnetic Tape Measure w/ 16' Reach*
48-22-0225M	25ft Wide Blade Magnetic Tape Measure w/ 17' Reach*

COMPACT WIDE BLADE TAPE MEASURES

15' REACH*

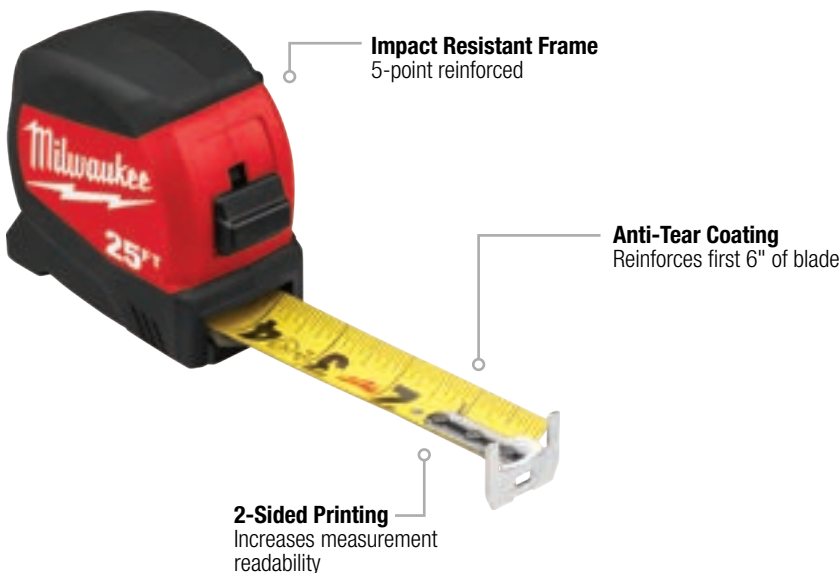

2-Sided Printing

Model #	Description
48-22-0416	16ft Compact Wide Blade Tape Measure w/ 15' Reach*
48-22-0425	25ft Compact Wide Blade Tape Measure w/ 15' Reach*
48-22-0430	30ft Compact Wide Blade Tape Measure w/ 15' Reach*
48-22-0417	5m/16ft Compact Wide Blade Tape Measure w/ 15' Reach*
48-22-0426	8m/26ft Compact Wide Blade Tape Measure w/ 15' Reach*
48-22-0316	16ft Compact Wide Blade Magnetic Tape Measure w/ 15' Reach*

Model #	Description
48-22-0325	25ft Compact Wide Blade Magnetic Tape Measure w/ 15' Reach*
48-22-0335	35ft Compact Wide Blade Magnetic Tape Measure w/ 15' Reach*
48-22-0317	5m/16ft Compact Wide Blade Magnetic Tape Measure w/ 15' Reach*
48-22-0326	8m/26ft Compact Wide Blade Magnetic Tape Measure w/ 15' Reach*

COMPACT TAPE MEASURES

12' REACH*



Also Available:



25ft Compact Tape Measure w/ Engineer Scale w/ 12' Reach*
48-22-6625E



Nylon Blade Coating

Model #	Description
48-22-6612	12ft Compact Tape Measure w/ 12' Reach*
48-22-6616	16ft Compact Tape Measure w/ 12' Reach*
48-22-6625	25ft Compact Tape Measure w/ 12' Reach*
48-22-6630	30ft Compact Tape Measure w/ 12' Reach*
48-22-6613	3m/12ft Compact Tape Measure w/ 12' Reach*
48-22-6617	5m/16ft Compact Tape Measure w/ 12' Reach*
48-22-6626	8m/26ft Compact Tape Measure w/ 12' Reach*

Model #	Description
48-22-6816	16ft Compact Auto-Lock Tape Measure w/ 12' Reach*
48-22-6825	25ft Compact Auto-Lock Tape Measure w/ 12' Reach*
48-22-6817	5m/16ft Compact Auto-Lock Tape Measure w/ 12' Reach*
48-22-6826	8m/26ft Compact Auto-Lock Tape Measure w/ 12' Reach*
48-22-5506	2m/6ft Keychain Tape Measure
48-22-6601	10ft/3m Keychain Tape Measure w/ LED



LONG TAPES & MEASURING WHEELS

OPEN REEL STEEL LONG TAPES

50% LESS STRETCH



Model #	Description
48-22-5201	100ft Open Reel Steel Long Tape
48-22-5203	30m/100ft Open Reel Steel Long Tape
48-22-5230	300ft Open Reel Steel Long Tape

FIBERGLASS LONG TAPES


SMOOTHEST RETRACTION



Model #	Description
48-22-5301	100ft Fiberglass Open Reel Long Tape
48-22-5302	200ft Fiberglass Open Reel Long Tape
48-22-5303	300ft Fiberglass Open Reel Long Tape
48-22-5310	100m/330ft Fiberglass Open Reel Long Tape
48-22-5330	30m/100ft Fiberglass Open Reel Long Tape
48-22-5360	60m/200ft Fiberglass Open Reel Long Tape

CLOSED REEL LONG TAPE

LONGEST LIFE

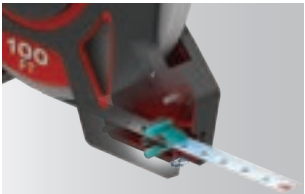

GRIME GUARD™
Industry's First Blade Wiper




Model #	Description
48-22-5101	100ft Closed Reel Long Tape

MEASURING WHEELS

MOST EFFICIENT.
ONE-HANDED CONTROL.



IP54 Rated Backlit LCD Screen

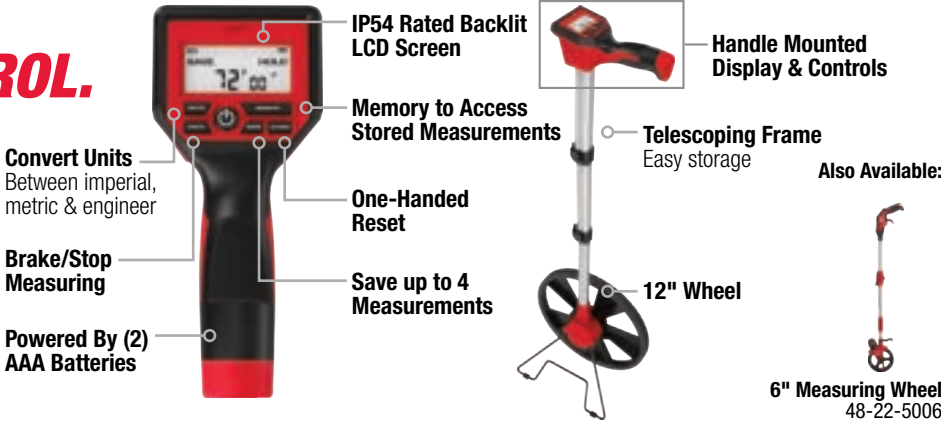

Model #	Description
48-22-5112	12" Digital Measuring Wheel
48-22-5012	12" Measuring Wheel

Model #	Description
48-22-5013	12" Engineer's Measuring Wheel
48-22-5006	6" Measuring Wheel

REDSTICK™ LEVELS

REDSTICK™

REDSTICK™ DIGITAL LEVELS

SUPERIOR ACCURACY.
DYNAMIC READOUT.




PINPOINT™ Measurement
Technology


Model #	Description
MLDIG14	14" REDSTICK™ Digital Level w/ PINPOINT™ Measurement Technology
MLDIG24	24" REDSTICK™ Digital Level w/ PINPOINT™ Measurement Technology
MLDIG48	48" REDSTICK™ Digital Level w/ PINPOINT™ Measurement Technology
MLDIG72	72" REDSTICK™ Digital Level w/ PINPOINT™ Measurement Technology

REDSTICK™ BOX LEVELS

MOST DURABLE.
GUARANTEED ACCURACY.

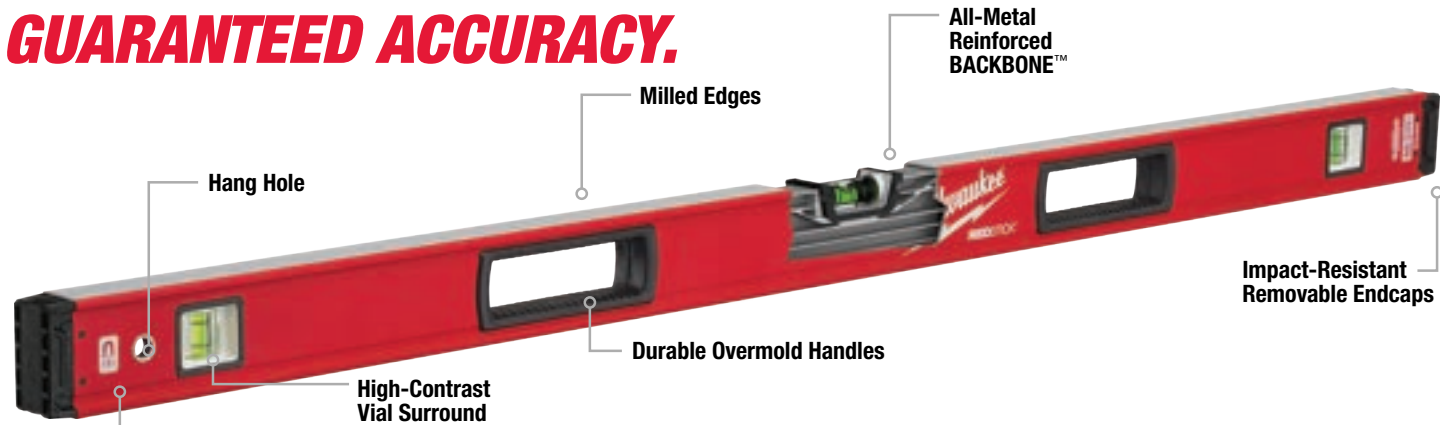

Model #	Description
MLBX16	16" REDSTICK™ Box Level
MLBXM16	16" REDSTICK™ Magnetic Box Level
MLBX24	24" REDSTICK™ Box Level
MLBXM24	24" REDSTICK™ Magnetic Box Level
MLBX32	32" REDSTICK™ Box Level
MLBXM32	32" REDSTICK™ Magnetic Box Level
MLBX36	36" REDSTICK™ Box Level
MLBXM36	36" REDSTICK™ Magnetic Box Level
MLBX48	48" REDSTICK™ Box Level
MLBXM48	48" REDSTICK™ Magnetic Box Level
MLBX59	59" REDSTICK™ Box Level
MLBXM59	59" REDSTICK™ Magnetic Box Level
MLBX72	72" REDSTICK™ Box Level
MLBXM72	72" REDSTICK™ Magnetic Box Level

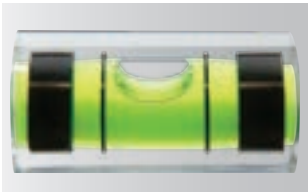

SHARPSITE™ Vial Technology

Model #	Description
MLBX78	78" REDSTICK™ Box Level
MLBXM78	78" REDSTICK™ Magnetic Box Level
MLBX96	96" REDSTICK™ Box Level
MLBXM96	96" REDSTICK™ Magnetic Box Level
MLBXS1648	16" / 48" REDSTICK™ Box Level Set
MLBXS48	24" / 48" REDSTICK™ Box Level Set
MLBXS48M	24" / 48" REDSTICK™ Magnetic Box Level Set
MLBXJB	78" / 32" REDSTICK™ Box Level Jamb Set
MLBXJBM	78" / 32" REDSTICK™ Magnetic Box Level Jamb Set
MLSB48	48" Level Bag
MLSB78	78" Level Bag
MLBXC48	4 Pc REDSTICK™ Starter Set
MLBXC78	5 Pc REDSTICK™ Master Set

REDSTICK™ COMPACT BOX LEVELS

COMPACT DURABILITY

Hang Hole

High-Contrast Vial Surround

Amplified Rare-Earth Magnets

SHARPSITE™ Vial Technology

Replaceable Endcaps

SHARPSITE™ Vial Technology

Model #	Description
MLCM24	24" REDSTICK™ Compact Box Level
MLCMM24	24" REDSTICK™ Magnetic Compact Box Level
MLCM48	48" REDSTICK™ Compact Box Level
MLCMM48	48" REDSTICK™ Magnetic Compact Box Level

Model #	Description
MLCM72	72" REDSTICK™ Compact Box Level
MLCMM72	72" REDSTICK™ Magnetic Compact Box Level
MLCMS48	24" / 48" REDSTICK™ Compact Box Level Set
MLCMSM48	24" / 48" REDSTICK™ Magnetic Compact Box Level Set

REDSTICK™ EXPANDABLE LEVELS

FRAME MORE. NO MAINTENANCE.

Also Available:
Expandable Level Storage Bag MLXPSB

SHARPSITE™ Vial Technology

High-Contrast Vial Surround

Durable Inset Lock

Hang Hole

Amplified Rare-Earth Magnets

Full Grip I-Beam Frame

Replaceable Endcaps

Reinforced Components & Durable Lock

Model #	Description
MLXPM78	48" – 78" REDSTICK™ Magnetic Expandable Level
MLXP712	6-1/2' – 12' REDSTICK™ Expandable Level

REDSTICK™ CONCRETE LEVELS

BUILT FOR CONCRETE

SHARPSITE™ Vial Technology

Ergonomic Keyhole Frame

Squared Edge
Screeding and striking

Rounded Edge
Smoothing

Magnesium Base
Easy to clean

All Metal Core

Screed

Smooth

Clean

Model #	Description
MLCON24	24" REDSTICK™ Concrete Level
MLCON48	48" REDSTICK™ Concrete Level
MLCON72	72" REDSTICK™ Concrete Level

MAGNETIC I-BEAM LEVELS

STRONGEST FRAME. SETS PITCH.

High Contrast Vial Surrounds

1% & 2% Pitch Lines

Top View Window
For overhead viewing

Strong Magnetic Edge

Impact Resistant Vial Covers
Protects from damage and fogging

Hi-Vis Vial Spirits
For easy readability

High Density Non-Removable Endcaps

Strong Magnetic Edge

Model #	Description
MLIBM24	24" Magnetic I-Beam Level
MLIBM48	48" Magnetic I-Beam Level
MLIBM78	78" Magnetic I-Beam Level

BILLET TORPEDO LEVELS

STRONGEST MAGNETS. EASIEST PITCH SET.

Maximized Viewing Area

Impact Resistant Vials

2" Dual Pitch Vial

Ruled Edge

Billet Aluminum Frame

4 Amplified Rare-Earth Magnets

Model #	Description
48-22-5107	Billet Torpedo Level
48-22-5207	Metric Billet Torpedo Level

BLOCK TORPEDO LEVELS

STRONGEST MAGNETS. 360° ACCURACY.

SHARPSITE™ Vial Technology

High-Contrast Vial Surround

Vial Lock

Lanyard Hole

Die-Cast Aluminum Body

360° Vial
Locks at any angle

Amplified Rare-Earth Magnets

Model #	Description
48-22-5210	Block Torpedo Level
48-22-5102	360° Pocket Level

Model #	Description
48-22-5603	Pocket Level
48-22-5001	Pipe Lock Level