




SQUARES & LASER
DISTANCE METERS

FOLDING RULES
& CHALK REELS

RAFTER SQUARES

STRONGER FRAME.
MOST VERSATILE.

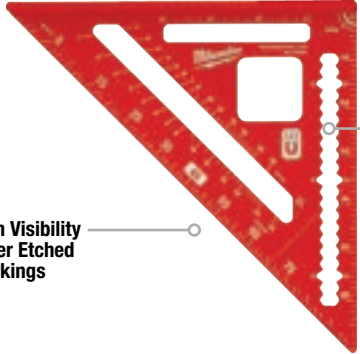

High Visibility Laser Etched Markings

Scribe Notches

1" Cutout Props Pipe

Model #	Description
MLSQM070	7" Magnetic Rafter Square
MLSQ170	180mm Rafter Square

TRIM SQUARE

MOST COMPACT.
MOST VERSATILE.



High Visibility Laser Etched Markings


Precision Scribe Notches at 1/8" Increments

Dual Reference Heel

Model #	Description
MLSQ040	4-1/2" Trim Square

FRAMING SQUARES

STRONGER THAN STEEL.
MOST VERSATILE.

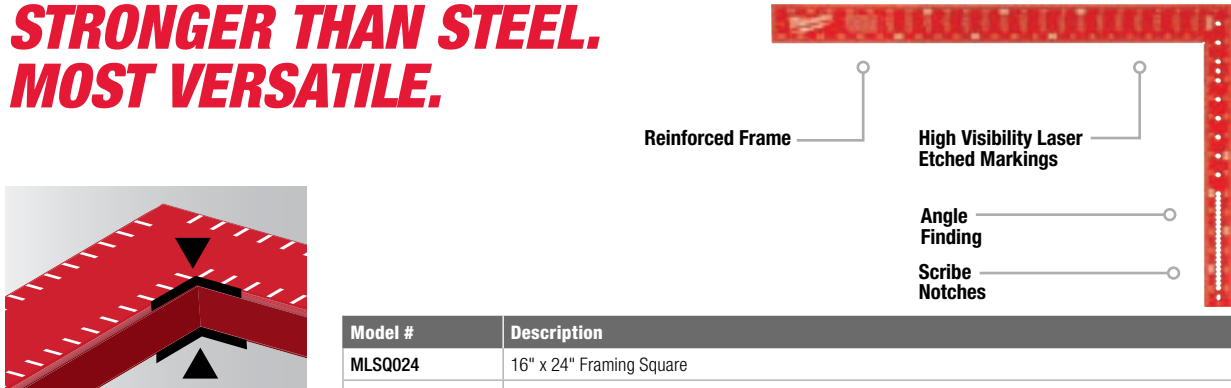

Reinforced Frame

High Visibility Laser Etched Markings

Angle Finding


Scribe Notches

Thicker Frame

Model #	Description
MLSQ024	16" x 24" Framing Square
MLSQ124	400mm x 600mm Framing Square

LASER DISTANCE METERS

EASIEST
MEASUREMENTS

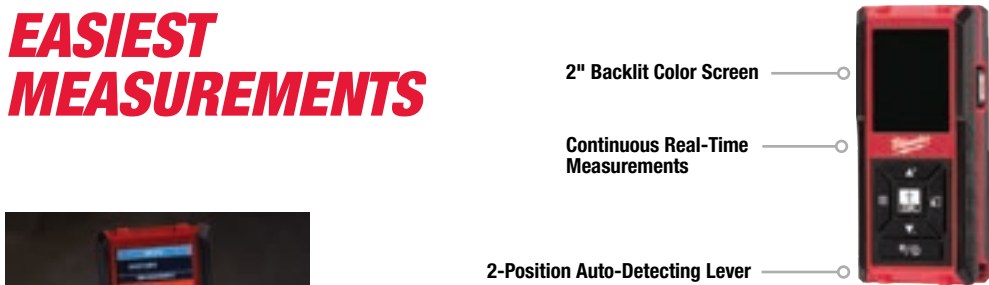

2" Backlit Color Screen

Continuous Real-Time Measurements

2-Position Auto-Detecting Lever

Impact-Resistant Overmolding

Side-Shot Button
Allows for one-handed measurement in all situations

Simplified User Interface

Also Available:



65ft Laser Distance Meter
48-22-9801

Model #	Description
48-22-9801	65ft Laser Distance Meter
48-22-9802	150ft Laser Distance Meter

Model #	Description
48-22-9803	330ft Laser Distance Meter

FOLDING RULES

MOST DURABLE
MARKINGS & BLADES



Water & Scratch Resistant Laminate

Quick Reference Bend Angles
22.5°, 30°, 45° & 60°

Heat-Stamped Markings
Won't wear

Corrosion-Free Embedded Joints
Locks at 0°, 90° & 180°

Model #	Description
48-22-3801	6-1/2ft Composite Folding Rule
48-22-3802	6-1/2ft Engineer's Composite Folding Rule

CHALK REELS

LONGEST GEAR LIFE.
BEST PERFORMANCE.




1.5mm High-Strength Braided Line

6X Faster Retraction

StripGuard™ Clutch & Planetary Gears

Bold Line

Model #	Description
48-22-3980	100ft Bold Line Chalk Reel
48-22-3982	100ft Bold Line Chalk Reel & Blue Chalk Refill
48-22-3986	100ft Bold Line Chalk Reel & Red Chalk Refill
48-22-3989	Bold Replacement Line

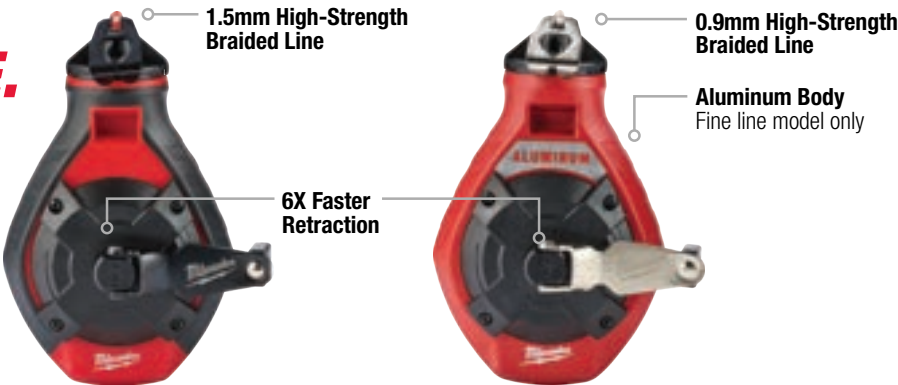

0.9mm High-Strength Braided Line

Aluminum Body
Fine line model only


6X Faster Retraction

Fine Line

Model #	Description
48-22-3990	100ft Fine Line Chalk Reel
48-22-3992	100ft Fine Line Chalk Reel & Blue Chalk Refill
48-22-3993	100ft Chalk Reel Kit w/ Blue Chalk Refill
48-22-3999	Fine Replacement Line

EXTRA BOLD LARGE CAPACITY CHALK REELS

LONGEST GEAR LIFE.
BEST PERFORMANCE.

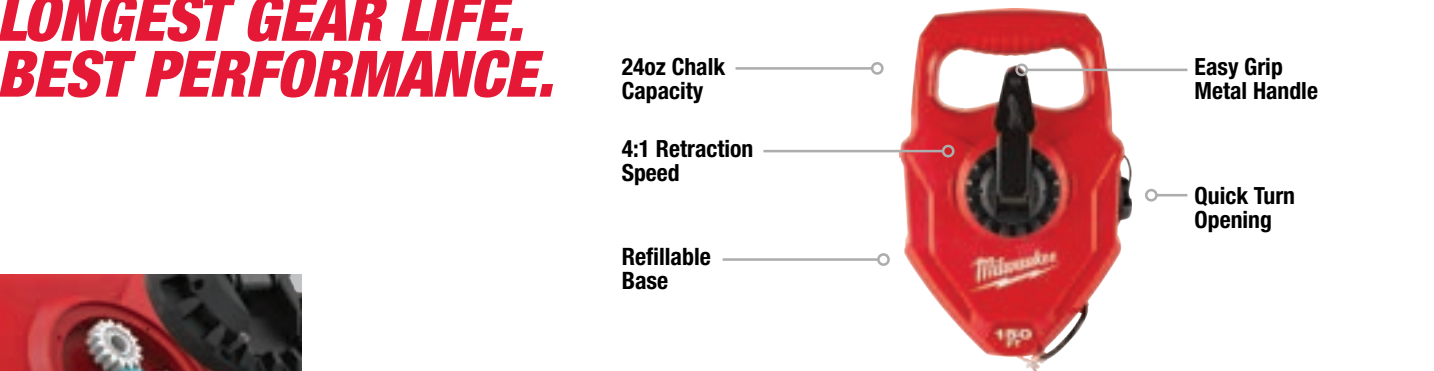

24oz Chalk Capacity

4:1 Retraction Speed

Refillable Base

Easy Grip Metal Handle

Quick Turn Opening

Planetary Gears Prevent Stripping

Model #	Description
48-22-3910	100ft Extra Bold Large Capacity Chalk Reel
48-22-3900	100ft Extra Bold Replacement Line

Model #	Description
48-22-3915	150ft Extra Bold Large Capacity Chalk Reel
48-22-3905	150ft Extra Bold Replacement Line



INKZALL™ JOBSITE MARKERS

INKZALL™

INKZALL™ JOBSITE MARKERS

WRITES ON
DUST
WET
OILY
SURFACES



Model #	Description
48-22-3150	12 Pc INKZALL™ Ultra Fine Point Black Jobsite Markers
48-22-3154	4 Pc INKZALL™ Ultra Fine Point Black Jobsite Markers
48-22-3104	4 Pc INKZALL™ Fine Point Black Jobsite Markers
48-22-3105	2 Pc INKZALL™ Fine Point Black Jobsite Markers
48-22-3107	8 Pc INKZALL™ Fine Point Color Jobsite Markers
48-22-3106	4 Pc INKZALL™ Fine Point Color Jobsite Markers
48-22-3101	INKZALL™ Stylus and Fine Point Black Jobsite Markers
48-22-3102	2 Pc INKZALL™ Medium Point Black Jobsite Markers
48-22-3103	INKZALL™ Chisel Tip Black Jobsite Markers
48-22-3109	4 Pc INKZALL™ Chisel Tip Color Jobsite Markers
48-22-3100	INKZALL™ Fine Point Black Jobsite Markers (Bulk 36 Pc)
48-22-3130	INKZALL™ Chisel Tip Black Jobsite Markers (Bulk 36 Pc)

Model #	Description
48-22-3170	INKZALL™ Fine Point Red Jobsite Markers (Bulk 36 Pc)
48-22-3180	INKZALL™ Fine Point Blue Jobsite Markers (Bulk 36 Pc)
48-22-3190	INKZALL™ Fine Point Green Jobsite Markers (Bulk 36 Pc)
48-22-3209	12 Pc INKZALL™ Fine Point Black Jobsite Markers
48-22-3250	3 Pc INKZALL™ Large Chisel Tip Black Jobsite Markers
48-22-3255	INKZALL™ Large Chisel Tip Black Jobsite Markers (Bulk 12 Pc)
48-22-3256	INKZALL™ Large Chisel Tip Red Jobsite Markers (Bulk 12 Pc)
48-22-3257	INKZALL™ Large Chisel Tip Blue Jobsite Markers (Bulk 12 Pc)
48-22-3260	INKZALL™ Extra Large Chisel Tip Black Jobsite Markers
48-22-3265	INKZALL™ Extra Large Chisel Tip Black Jobsite Markers (Bulk 12 Pc)
48-22-3266	INKZALL™ Extra Large Chisel Tip Red Jobsite Markers (Bulk 12 Pc)
48-22-3267	INKZALL™ Extra Large Chisel Tip Blue Jobsite Markers (Bulk 12 Pc)

INKZALL™ METALLIC MARKERS



Visible on Dark Surfaces




Model #	Description
48-22-3121	2 Pc INKZALL™ Fine Point Silver Metallic Markers
48-22-3122	2 Pc INKZALL™ Fine Point Gold Metallic Markers
48-22-3123	2 Pc INKZALL™ Fine Point Silver/Gold Metallic Markers

INKZALL™ PAINT MARKERS,
PENS & HIGHLIGHTERS

INKZALL™ LIQUID PAINT MARKERS

BLEED &
SMEAR
RESISTANT

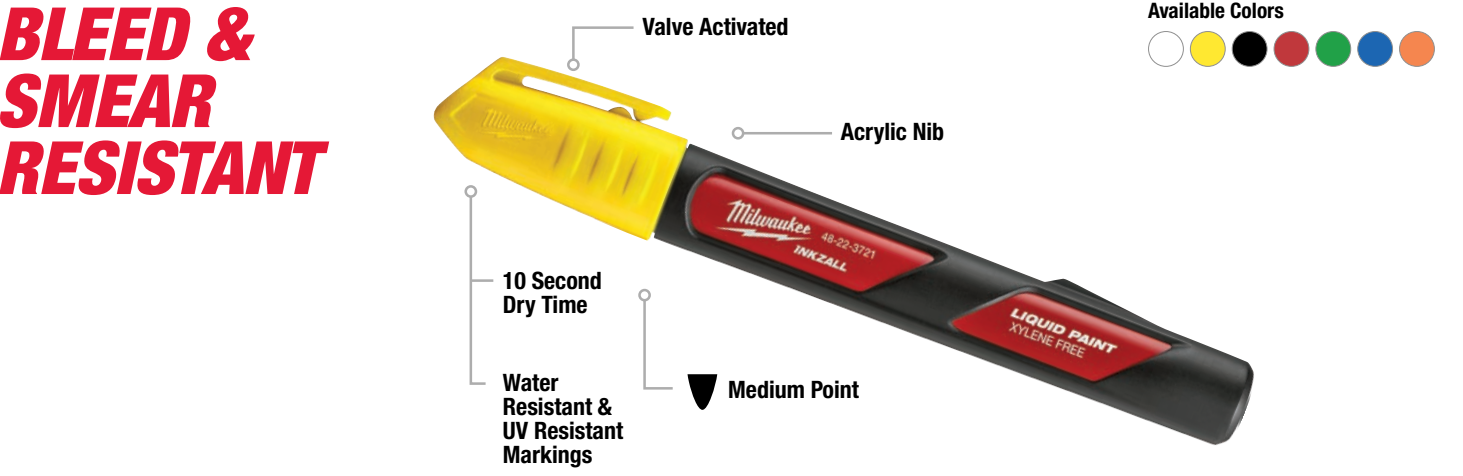


Marks on Surfaces up to 300°F

Model #	Description
48-22-3712	INKZALL™ Medium Point White Liquid Paint Marker
48-22-3722	INKZALL™ Medium Point Yellow Liquid Paint Marker
48-22-3711	INKZALL™ Medium Point White Liquid Paint Markers (Bulk 12 Pc)
48-22-3721	INKZALL™ Medium Point Yellow Liquid Paint Markers (Bulk 12 Pc)
48-22-3731	INKZALL™ Medium Point Black Liquid Paint Markers (Bulk 12 Pc)

Model #	Description
48-22-3741	INKZALL™ Medium Point Red Liquid Paint Markers (Bulk 12 Pc)
48-22-3751	INKZALL™ Medium Point Green Liquid Paint Markers (Bulk 12 Pc)
48-22-3761	INKZALL™ Medium Point Blue Liquid Paint Markers (Bulk 12 Pc)
48-22-3771	INKZALL™ Medium Point Orange Liquid Paint Markers (Bulk 12 Pc)

INKZALL™ JOBSITE PENS

SHARP,
PRECISE
LINES

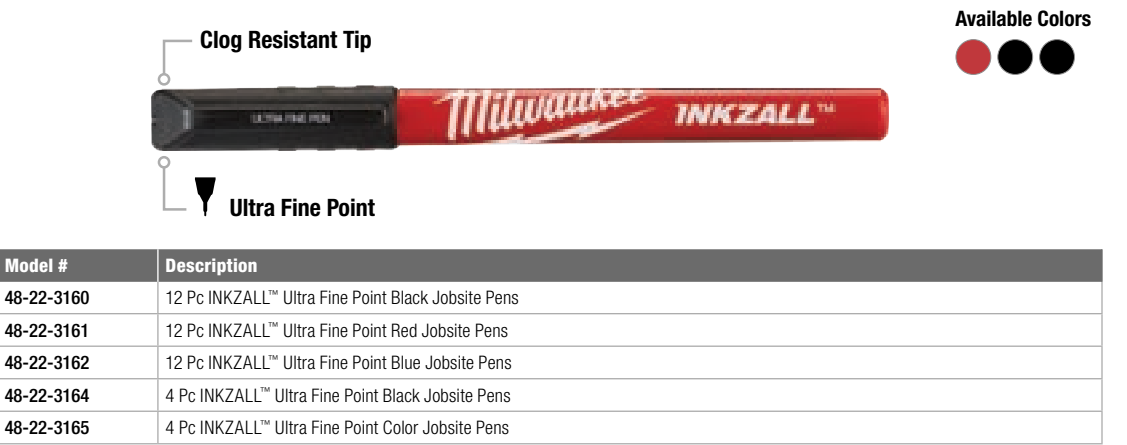

Model #	Description
48-22-3160	12 Pc INKZALL™ Ultra Fine Point Black Jobsite Pens
48-22-3161	12 Pc INKZALL™ Ultra Fine Point Red Jobsite Pens
48-22-3162	12 Pc INKZALL™ Ultra Fine Point Blue Jobsite Pens
48-22-3164	4 Pc INKZALL™ Ultra Fine Point Black Jobsite Pens
48-22-3165	4 Pc INKZALL™ Ultra Fine Point Color Jobsite Pens

INKZALL™ JOBSITE HIGHLIGHTERS

UP TO
4x LONGER LIFE



Model #	Description
48-22-3201	5 Pc INKZALL™ Chisel Tip Yellow Jobsite Highlighters
48-22-3206	5 Pc INKZALL™ Chisel Tip Colored Jobsite Highlighters

COMFORT GRIP STRAIGHT JAW PLIERS

REAM
AND PUNCH™



Ream

Punch



Model #	Description	Jaw Capacity	Reaming Capacity
48-22-6306	6" Comfort Grip Straight Jaw Pliers	1"	3/4"
48-22-6310	10" Comfort Grip Straight Jaw Pliers	2"	2"
48-22-6312	12" Comfort Grip Straight Jaw Pliers	2-1/4"	2-3/4"
48-22-6316	16" Comfort Grip Straight Jaw Pliers	4-1/4"	3"
48-22-6320	20" Comfort Grip Straight Jaw Pliers	5-1/2"	3-1/2"
48-22-6330	2 Pc 6" & 10" Comfort Grip Straight Jaw Pliers Set	1" & 2"	3/4" & 2"
48-22-6331	3 Pc Comfort Grip Pliers Set	2"	2"

STRAIGHT JAW PLIERS

MAXIMUM GRIP.
FORGED STRENGTH.



Dipped Grips



Reaming Head

Model #	Description	Jaw Capacity	Reaming Capacity
48-22-6510	10" Straight Jaw Pliers	2"	2"
48-22-6512	12" Straight Jaw Pliers	2-1/4"	2-3/4"

SMOOTH JAW PLIERS

SMOOTH JAW
PROTECTS SURFACES



Non-Marring Smooth Jaw
for Finish Applications




Model #	Description	Jaw Capacity	Reaming Capacity
48-22-6550	10" Smooth Jaw Pliers	2"	2"
48-22-6552	12" Smooth Jaw Pliers	2-1/4"	2-3/4"

COMFORT GRIP V-JAW PLIERS



Ream

Punch

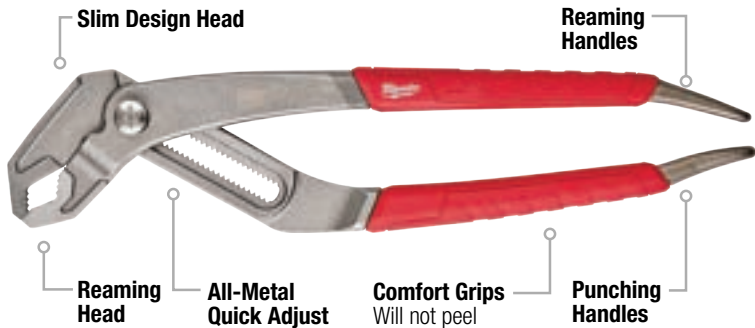


Model #	Description	Jaw Capacity	Reaming Capacity
48-22-6208	8" Comfort Grip V-Jaw Pliers	1-1/2"	1-1/2"
48-22-6210	10" Comfort Grip V-Jaw Pliers	2"	2"
48-22-6212	12" Comfort Grip V-Jaw Pliers	2-3/4"	2-3/4"

LINEMAN'S PLIERS

MAXIMUM LEVERAGE.
EASIER CUTS.*



Easily Cuts #2 ACSR

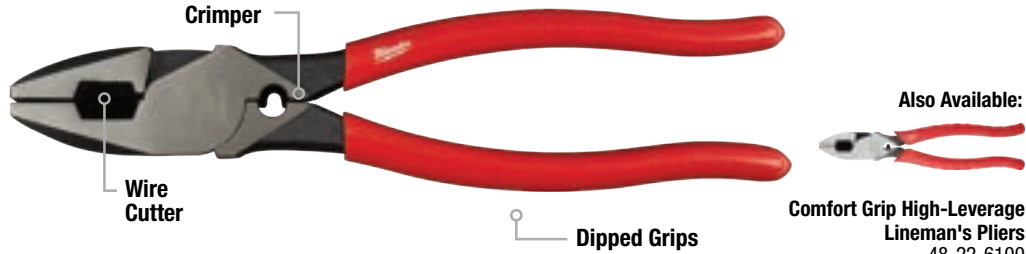

Model #	Description
48-22-6100	Comfort Grip High-Leverage Lineman's Pliers w/ Crimper
48-22-6500	High-Leverage Lineman's Pliers w/ Crimper
48-22-6502	High-Leverage Lineman's Pliers
48-22-6503	High-Leverage Lineman's Pliers w/ Thread Cleaner

ANGLED HEAD PLIERS

BETTER ACCESS



Angled Head



Comfort Grips
Will not peel



Also Available:
8" Angled Head Diagonal
Cutting Pliers
48-22-6528

Model #	Description
48-22-6128	8" Comfort Grip Angled Head Diagonal Cutting Pliers
48-22-6528	8" Angled Head Diagonal Cutting Pliers

* When compared to other ACSR cutting lineman pliers