

STRIPE

LED Linear linkable lightbar, 700-1800 Lumens,
8-20 Watt, Color Selectable
General Illumination

Job Information		
Project Name		Type
Location		
Quantity		Date
Contact/Phone		
Notes		

Features

Housing

Durable extruded aluminum frame with frosted smooth lens. Suitable for damp location applications only. 5-position 2700-5000K CCT select switch are provided for individual control.

LED Driver

Fixture is provided with built-in silent non-flicker electronic LED driver, 120V, 50 / 60Hz.

Light Output

Providing up to 1800 lumens, 93 lumens per watt, this lightbar fixture also features a 5-position 2700-5000K CCT select switch.

Dimming

Fixture is 100~10% dimmable with industry standard TRIAC and ELV dimmers.

LED Characteristics

Powered by LED integrated strip that maintains uniform intensity with a rated

life of 50,000 hours average life; at 90 CRI.

Beam Spread

The fixture lens provides for 125° beam spread.

Linking

Complete with a joiner, these no shadow linking fixtures can be linked up to 150'.

Mounting Kit

Hardware provided for mounting fixture to standard horizontal surfaces or vertical wall surface.


Operating Temperature

-18°C~40°C (0°F~104°F).

Application


Accent lighting, general illumination (recessed, flushmount, suspended), wall grazer, vanity light, sconce, picture light, closet light, vertical wall light, cove lighting, corner light, under cabinet and millwork.

SPECIFICATION	
Approved Location	Damp
Beam Angle	125°
CCT (switch)	2700 K / 3000 K / 3500 K / 4000 K / 5000 K
Certification	cETLus
CRI	90+
Dimming	Yes
Dimming Technology	TRIAC / ELV
Fixture length	18" / 24" / 36" / 48"
Lumens	Up to 1800
Lumens per watt	Up to 93
Min. Start Temp.	-18°C
Power Factor	>0.95
R9	>60
Rated Life	50,000 hrs
THD	<15
Voltage	120V
Warranty	3 Years
Wattage	8 / 10 / 15 / 20

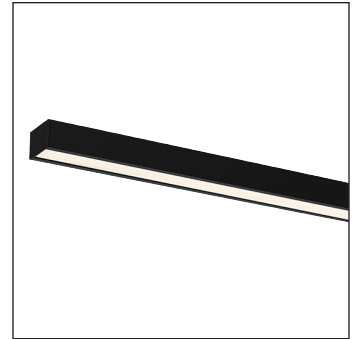

Description

This LED lightbar is a linear light with an integrated LED strip. Available in various lengths and CCT select switch to meet any installation application.

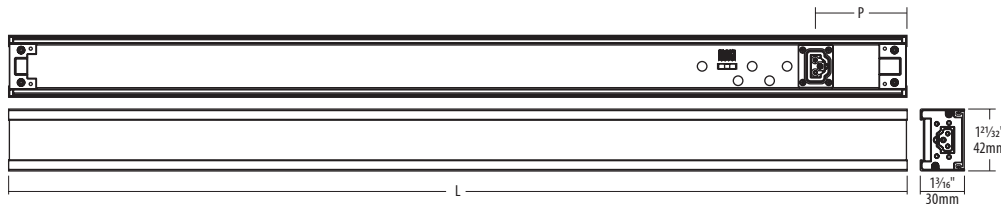

	STRIPE18	STRIPE24	STRIPE36	STRIPE48
Length (L)	18 1/8" 460mm	24 1/8" 611mm	35 7/8" 911mm	47 3/4" 1213mm
Powerfeed Outlet Location (P)	2 1/8" 62mm	2 1/8" 62mm	18" 457mm	23 7/8" 607mm
Wattage (W)	8	10	15	20



Ordering Guide

STRIPE - 5CCT -

18 : 18"
 24 : 24"
 36 : 36"
 48 : 48"

BK : Black
 WH : White

Notes:

Fixture includes one small end cap, two large end caps, two surface mount clips, one I-connector and one back cover. Accessories are sold separately. For additional options consult your Liteline representative. Due to our continued efforts to improve our products, product specifications are subject to change without notice.

Accessories (Power feed required)

Power Cords & Covers



ALFT6000-BK-3
ALFT6000-WH-3
6' Flexible 3-wire power cord.



ALFT6000S-BK-3
ALFT6000S-WH-3
6' Flexible 3-wire power cord with on/off switch.



ALFT6016-BK-3
ALFT6016-WH-3
16' Flexible 3-wire power cord.



ALFT60901-BK03
ALFT60901-WH-3
6' Flexible 3-wire power cord with 90° connector (top connection).



ALFT60902-BK-3
ALFT60902-WH-3
6' Flexible 3-wire power cord with 90° connector (left connection).



ALFT60903-BK-3
ALFT60903-WH-3
6' Flexible 3-wire power cord with 90° connector (bottom connection).



ALFT60904-BK-3
ALFT60904-WH-3
6' Flexible 3-wire power cord with 90° connector (right connection).



FBT6106-BK-3
FBT6106-WH-3
6" Flexible 3-wire connector.



FBT6100-BK-3
FBT6100-WH-3
12" Flexible 3-wire connector.



FBT6124-BK-3
FBT6124-WH-3
24" Flexible 3-wire connector.



FBT6136-BK-3
FBT6136-WH-3
36" Flexible 3-wire connector.



STRIPE-SEND CAP-BK
STRIPE-SEND CAP-WH
End cap for STRIPE, small.



STRIPE-LEND CAP-BK
STRIPE-LEND CAP-WH
End cap for STRIPE, large.



STRIPExx-WMBC-BK
STRIPExx-WMBC-WH
Wall mount back cover for STRIPE, available in 18", 24", 36" and 48".

Accessories



STRIPE-FC2LV-BK
STRIPE-FC2LV-WH
2-Leg flexible corner for vertical direction.



STRIPE-FC2LH-BK
STRIPE-FC2LH-WH
2-Leg flexible corner for horizontal direction.



STRIPE-FC3LH-BK
STRIPE-FC3LH-WH
3-Leg flexible corner for horizontal direction.



STRIPE-UBRACKET-BK
STRIPE-UBRACKET-WH
U-shape bracket for enforcing in-line connections in suspension applications.



STRIPE-MAGCLIP
Magnetic mounting clips for STRIPE, 3-pack.



STRIPE-SURMCLIP
Surface mount clips for STRIPE, 3-pack.



STRIPE-ISCLIP
I-connector.



STRIPE-CANOPY-BK
STRIPE-CANOPY-WH
Octagon box mount canopy.



STRIPE-DEVICEBOX-BK
STRIPE-DEVICEBOX-WH
Electrical device box mount canopy.



STRIPE-ROTBKT-BK
STRIPE-ROTBKT-WH
Adjustable wall mount bracket.



STRIPE-HWB-BK
STRIPE-HWB-WH
In-line hardwire box.



ALFT6300-OS-BK
ALFT6300-OS-WH
Hardwire with motion sensor.



SR-2421-TR5-V
0-10V to Triac Phase-Cut dimmer converter.



STRIPE-WMBRAC-BK
STRIPE-WMBRAC-WH
Mounting bracket.



STRIPE-WMBRAC-IN-BK
STRIPE-WMBRAC-IN-WH
Indirect mounting bracket.



STRIPE-WMBRAC-OUT-BK
STRIPE-WMBRAC-OUT-WH
Direct mounting bracket.



STRIPE-SUSPKIT-BK
STRIPE-SUSPKIT-WH
Suspension kit for STRIPE, 8' wire, FT6.



STRIPE-SUSPEND
Suspension Aircraft for STRIPE, 150".