

# OS4600LED-2HO

High Power Twin-Head Flood



NAME:	
TYPE:	
DATE:	
NOTES:	

## SPECIFICATIONS

LIGHT UNIT:	<p>Rugged cast-aluminum, corrosion-resistant housing with dark bronze, black or white powder paint for lasting durability.</p> <p>LED lamp heads are thermally isolated from the driver that is located in the rear housing, promoting a long service life.</p> <p>Adjustable Photocell Sensitivity</p> <p>Adjustable brightness control allows for selectable lumen output of 4000 or 6000 lumens.</p> <p>Twin head lenses are sealed to keep out moisture, dirt and bugs.</p> <p>LEDs maintain 70% of light output at 50,000 hours of service life.</p>
INSTALLATION:	<p>Crossbar and hardware provided.</p> <p>Wet location listed for mounting 4 feet above ground.</p> <p>Tool-less adjustable heads allow for precise aiming.</p> <p>Dual mount system: Can be mounted on walls or soffits.</p>
ELECTRICAL:	<p>Energy efficient LED provides 4000 or 6000 lumens, consumes 43W or 65W utilizing 120-277V 60Hz driver.</p> <p>Selectable Color Temperature, choice of 4000K or 5000K</p> <p>Rated for outdoor installations, -40°C minimum ambient.</p> <p>LISTINGS</p> <p>UL/cUL listed Listed to U.S. and Canadian safety standards for wet locations.</p>

COLOR TEMPERATURE:	4K - 5K
CRI:	80
LUMEN OUTPUT:	4000 - 6000 lumens
WATTS:	43 Watts - 63 Watts
LED LIFE:	50,000 hrs
WARRANTY:	5 years
VOLTAGE:	120-277V


## APPLICATIONS

The high performance LED oval twin-head security light offers security and general lighting for outdoor residential and commercial applications. Long lasting, energy saving illumination ideal for yards, driveways, walkways, lots and loading areas.

# OS4600LED-2HO

High Power Twin-Head Flood

## DIMENSIONS

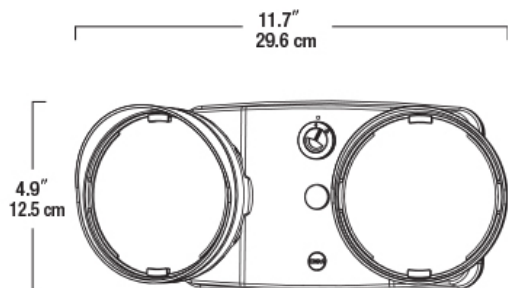

## ORDERING GUIDE

### TRITON

Series	Color Temperature	Finish
OS4600LED-2HO	4000K-5000K/80CRI/63W	<b>BK</b> Black
	4000K-5000K/80CRI/63W	<b>DB</b> Dark Bronze
	4000K-5000K/80CRI/63W	<b>WH</b> White

**Notes:** Configure product using **BOLD** options: Ex: **OS4600LED-2HO-BK**