




Color: ■ gray

Similar to illustration

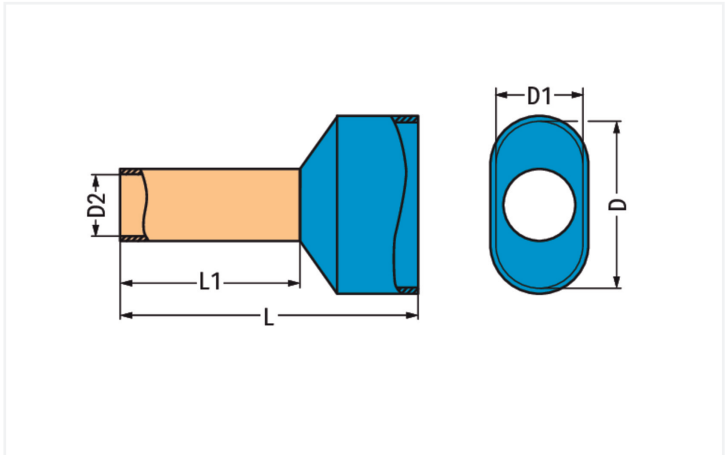

Connection data	
Strip length	13.5 ... 14.5 mm / 0.53 ... 0.57 inches
Cross-section metric	4 mm²
Cross-section AWG	2 x 12 AWG

Physical data	
Wall thickness plastic collar	0.5 mm
Inner dimension plastic collar small	5.2 mm
Inner dimension plastic collar large	9 mm
Total length	22 mm
Wall thickness crimp sleeve	0.2 mm
Crimp length (length of sleeve)	12 mm
Diameter crimp sleeve inside	3.7 mm

Mechanical data	
Plastic collar	Standard collar

Material data	
Color	gray
Fire load	0 MJ
Weight	1.1 g

Commercial data	
PU (SPU)	100 (100) pcs
Packaging type	Box
Country of origin	DE
GTIN	4055143583350
Customs tariff number	85369010000



Product classification		
UNSPSC		39121405
eCl@ss 10.0		27-40-02-01
eCl@ss 9.0		27-40-02-01
ETIM 9.0		EC000005
ETIM 8.0		EC000005
ECCN		NO US CLASSIFICATION

Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Downloads

Environmental Product Compliance


Compliance Search

Environmental Product Compliance 216-546

↓

Documentation				
Bid Text				
216-546	19.02.2019	xml	2.62 KB	↓
216-546	28.04.2017	doc	22.50 KB	↓

Installation Notes

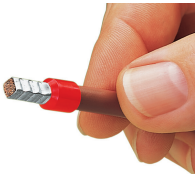

A perfect gas-tight crimp – both electrical-ly and mechanically reliable