

Product data sheet

Specifications



Mini circuit breaker, Homeline Canadian, 40A, 1 pole, 120VAC

CHOM140

Main

Range of product	Homeline
Product or component type	Miniature circuit-breaker
[In] rated current	40 A
[Ue] rated operational voltage	120/240 V AC
Mounting mode	Plug-on
Poles description	1P
Short-circuit current	10 kA
Circuit breaker type	Standard
Circuit breaker application	HACR rated
Electrical connection	Screw clamp terminals

Complementary

Number of spaces required	1
AWG gauge	AWG 8...AWG 2 aluminum/copper

Environment

Product certifications	CSA
Ambient air temperature for operation	104 °F (40 °C)

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	1.00 in (2.54 cm)
Package 1 Width	3.10 in (7.87 cm)
Package 1 Length	3.00 in (7.62 cm)
Package 1 Weight	0.33 lb(US) (0.15 kg)
Unit Type of Package 2	CAR
Number of Units in Package 2	100
Package 2 Height	10.50 in (26.67 cm)
Package 2 Width	7.00 in (17.78 cm)
Package 2 Length	16.50 in (41.91 cm)
Package 2 Weight	36.189 lb(US) (16.415 kg)

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications


Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.


[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Use Better


 Materials and Substances	
Packaging made with recycled cardboard	No
Packaging without single use plastic	Yes
EU RoHS Directive	Compliant
REACH Regulation	REACH Declaration

Use Again

 Repack and remanufacture	
Circularity Profile	No need of specific recycling operations
Take-back	No

Technical Illustration

Dimensions

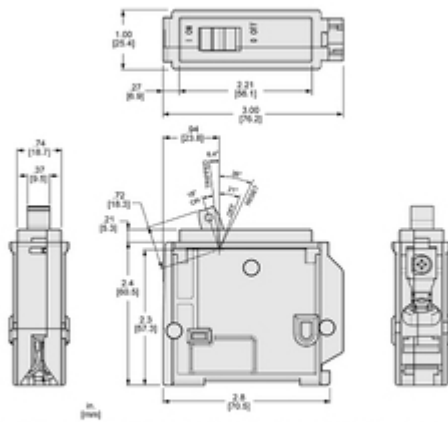

All dimensions are approximate. Also refer to technical drawings and documentation.