

Project: _____

Type: _____

Drawn by: _____ Catalogue #: _____

Date: _____

Individual Spec Sheet

SWIVEL CHOICE GEN. 2

4" LED DOWNLIGHT

5 CCT Selectable

ORDERING INFORMATION

Order Code: 70532
Model Number: SWDL4R-G2-9A-5CWH/CHOICE
UPC: 069549035454
Case Quantity: 32

PHYSICAL DATA

Size in (cm): 4 3/4 (12)
Shape: Round
Finish: White
Lens Type: Frosted Polycarbonate
Mounting: Recessed

PERFORMANCE DATA

Watts (W): 9
Volts (V AC): 120
Color Temperature (K)¹: 2 700/3 000/3 500/4 000/5 000
Lumen Output (lm)²: 805
Efficacy (lm/W): 89
CRI: 90+
Life L70 (h)³: 50 000
Beam Angle (°): 45
Environment: Wet location
THD (%): <20
Power Factor: >0.9
Cable Rating: FT4
Frequency (Hz): 60
Operating Temp. Range: -30 °C to 40 °C (-22 °F to 104 °F)
Dimmable: Phase cut (ELV / Triac)

¹ Typical colour temperature range: +/- 5 %.

² Lumen values are derived from Energy Star reported data. Initial lumens range: +/- 10 %.

³ Life hours are derived from IESNA LM-80 testing report and projected per IESNA TM-21 extrapolations.

LUMEN SPECIFICATION TABLE

Watts (W)	2 700 K		3 000 K		3 500 K		4 000 K		5 000 K	
	Lumen output (lm)	Efficacy (lm/W)	Lumen output (lm)	Efficacy (lm/W)	Lumen output (lm)	Efficacy (lm/W)	Lumen output (lm)	Efficacy (lm/W)	Lumen output (lm)	Efficacy (lm/W)
9	769	85	816	90	869	96	872	96	813	90

DEFAULT PROGRAMMING

2 700 K



LED
fixture



dimmable
fixture



airtight



wet
location



IC
rated



ICES
005



This lighting equipment complies with Canadian standard ICES-005 for use in residential applications.
Data is based upon tests performed in a controlled environment.
Actual performance can vary depending on operating conditions. Specifications are subject to change without notice.

ACCESSORIES (order separately)


Order code	Model number	Type
62771 ¹	ACC/MPLATE/3.75IN/HANG.BARS/STD	Mounting plate with hanger bars
66050 ¹	ACC/MPLATE/3.75IN/SQR/STD	Square mounting plate
66057 ¹	ACC/MPLATE/3.75IN/ADJ/STD	Adjustable mounting plate
68986 ²	GOOF RING-4.25IN	Goof ring
64264	LPDL/ACC/6FT/EXTCABLE/STD	6' Extension cord

¹ Includes brackets and screws.

² Please note that the white finish of the goof rings differs from the white finish of the Swivel Choice Series.

DIMENSIONS AND WEIGHTS

4"

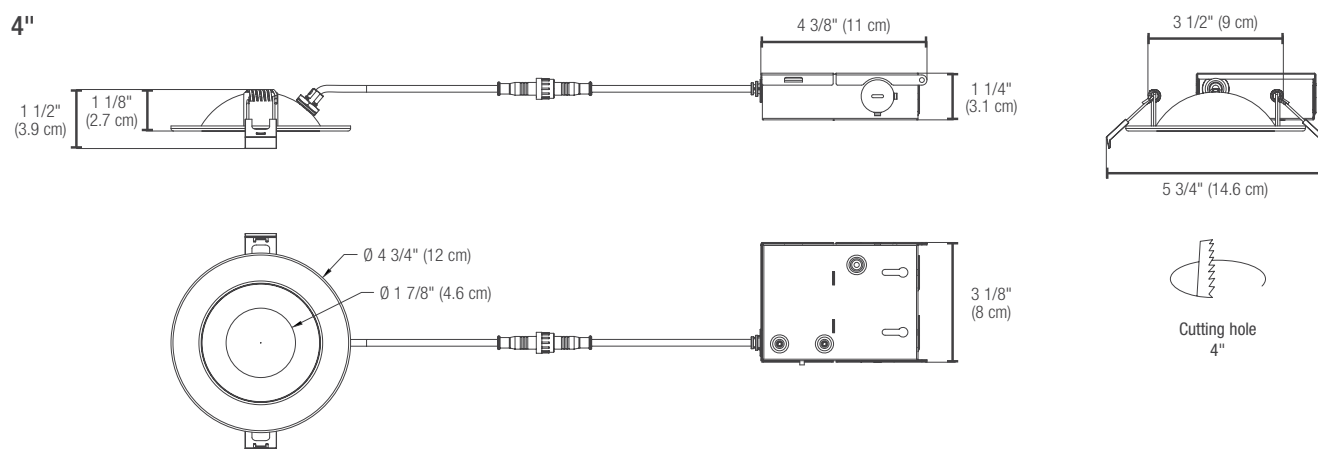

Net weight (lbs)	0.94
------------------	------

Qty	Description	Price

I accept the specifications of the luminaire configuration mentioned above.

Name:

Company:

Signature:

Date:

Data is based upon tests performed in a controlled environment. Actual performance can vary depending on operating conditions.
All products are subject to change or may be discontinued any time without notice.