



Xitanium LED Driver Outdoor Fixed (US)

XITANIUM 80W 3.3A 24V 120V 60HZ

Xitanium Outdoor LED Drivers are available in wattages from 40W to 150W for hard-wire integration into outdoor luminaires for the most rugged applications. These drivers operate to specification under wide temperature and electrical ranges to ensure reliability.


Product data

General Information	
Lighting Technology	LED
Wiring	
Connector Type Input Terminals	Wago 250
Output Wire Length	660.4 mm
Approval and Application	
Short Circuit Protection	Protected
EMI Standard	FCC Title 47 Subpart 18 Class A
Environmental Standard	UL Damp & Dry
Approval Marks	RoHS compliance UL certificate CSA certificate

Product Data	
Order product name	XITANIUM 80W 3.3A 24V 120V 60HZ
Full product name	XITANIUM 80W 3.3A 24V 120V 60HZ
Full product code	871016319603900
Order code	913700508991
Material Nr. (12NC)	913700508991
Numerator - Quantity Per Pack	1
Net Weight (Piece)	0.622 kg
EAN/UPC - Product/Case	781087030691
Numerator - Packs per outer box	20
EAN/UPC - Case	50781087030702

Xitanium LED Driver Outdoor Fixed (US)

Dimensional drawing

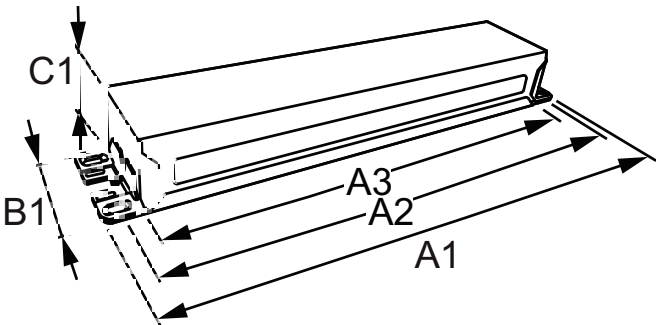

Product	A1	B1	C1	A2
XITANIUM 80W 3.3A 24V 120V 60HZ	240 mm	43.2 mm	29 mm	228.7 mm

