

DL205T-4-10W-5CCT-R90

4" Round Disk Downlight 10W

Project:

Location:

Model:Qty:

Notes:

DESCRIPTION


4" Round Surface Mount, Multi-Purpose Energy-Efficient Fixture

FEATURES & BENEFITS

- Fast & Easy to Install in J-Box or as 4" Can Retrofit
- Wet Location Approved - Suitable For Indoor & Outdoor Installations
- 5CCT User Selectable 2700-3000-3500-4000-5000K
- CRI 90+ for True Color Rendering
- Flicker Free AC Design
- White & Black trims in stock


DIMENSIONS

OD 6" Thickness 1"

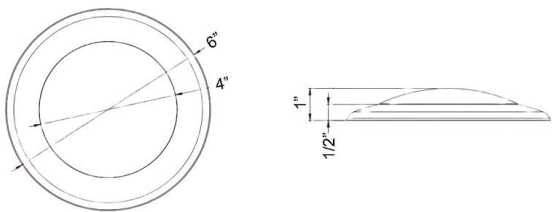


SPECIFICATION	
Applications	Residential, Commercial, Hospitality, Multi Family
Energy Used	10 W
Color Temperature (K)	2700 - 3000 - 3500 - 4000 - 5000
Light Output (lm)	760 - 790 - 820 - 805 - 760
Halogen Equivalent	75 W
Beam Angle	115°
CRI	90 +
Voltage Input	120V AC
Dimming	TRIAC Dimmers 10% - 100%
Approved Location	Wet Locations
Air Tight	No
Ambient Temperature	-4°F (-20°C) to +104°F (+40°C)
Projected Life	70% Light Output at 50,000 Hours
Certification	cETLus, Energy Star, JA8
Warranty	5 Year

INSTALLATION INSTRUCTIONS FOR J-BOX

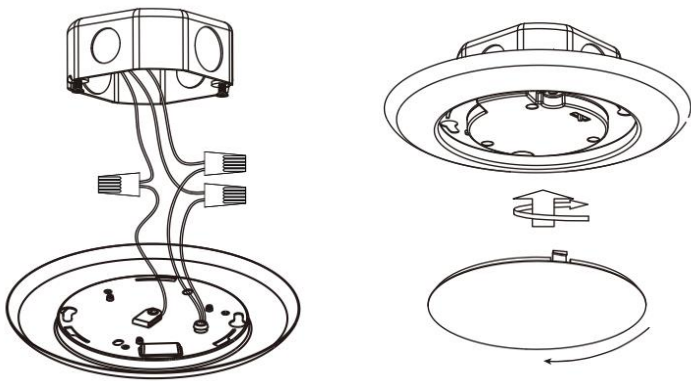

Compatible with 2.75", 3" & 4" J-Boxes


RETROFIT INSTALLATION - ACCESSORIES NOT INCLUDED IN PACKAGE

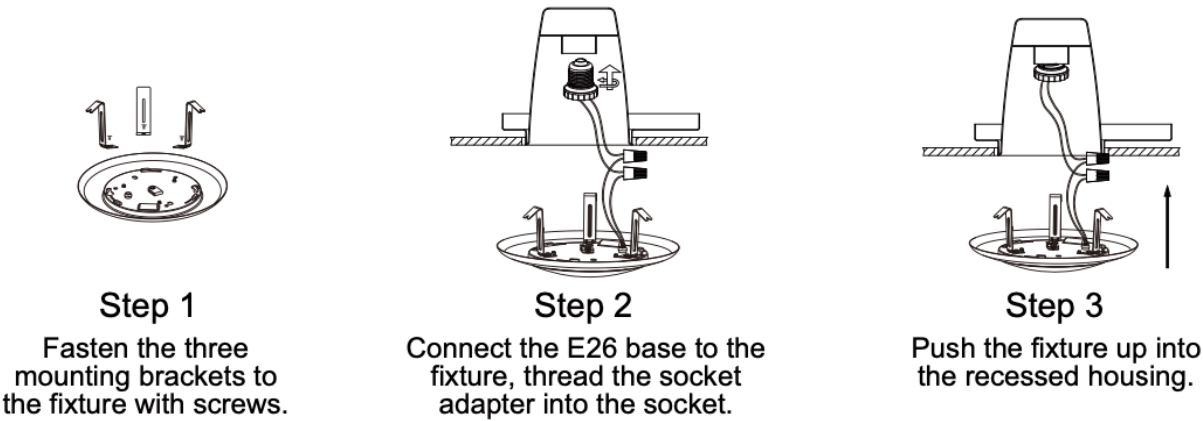

AVAILABLE TRIMS




ACCESSORIES - SOLD SEPARATELY

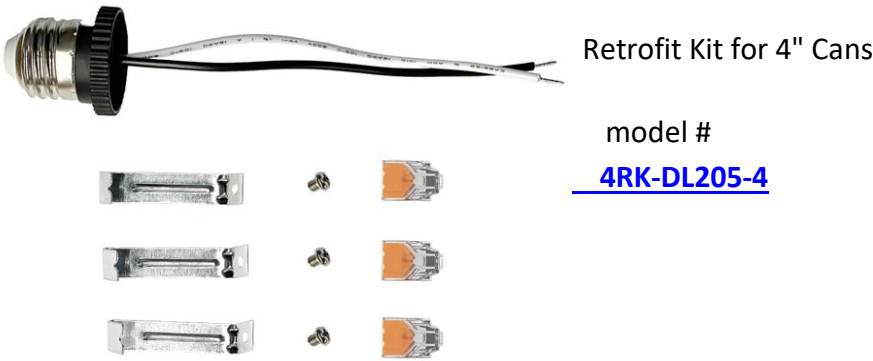

ORDERING GUIDE

	Trim
DL205T-4-10W-5CCT-R90-0081-WH	White
DL205T-4-10W-5CCT-R90-0082-BK	Black

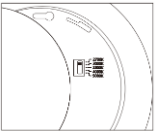

Lotus LED Lights USA

250 H Street # 301, Blaine WA 98230 tel 360-200-5500
Hainesport NJ, Naples FL, Vancouver WA

www.LotusLEDLights.com

mailing addresses
warehouses

Lotus LED Lights CANADA

1080 Cliveden Ave # 6, Delta BC V3M 6G6 tel 604-538-3090
Delta BC, Mississauga ON