

ACCESSORIES - SPLITTER BLOCKS

Pad type splitter blocks



CAT No:	Amp	Incoming Wire Range	Branch Wire Range
PAD-T-125	125	One 14 - 1/0	Six 14 - 2
PAD-T-225	225	One 6 - 300 MCM	Six 14 - 2/0
PAD-T-400	400	Two 1/0 - 250 MCM or One 4 - 600 MCM	Two 14 - 3/0 four 6 - 4/0
PAD-T-600	600	Four 1/0 - 250 MCM or Two 4 - 600 MCM	Two 14 - 3/0 Four 6 - 4/0
PAD-TB-125	125	One 14 - 2/0	Three 14 - 2/0
PAD-TB-225	225	One 6-300	1-6-300 2-14-2/0


CAT No:	Wire Range
LUG-PA-SHR-100	Four 14 - 2/0
LUG-PA-LNG-100	Seven 14 - 2/0
LUG-PA-SHR-200	Two 6 - 300 MCM Two 14 - 2/0
LUB-PA-LNG-200	Two 6 - 300 MCM Two 300 MCM-6 Six 14 - 2/0

SPLITTERS, BUSGUTTERS & LUGS

ACCESSORIES - MECHANICAL SPLITTER LUGS

Lugs are suitable for either copper or aluminum conductors. They provide low contact resistance and reduce material content while maintaining the same performance standards as full sized connectors.

- 6061-T6 aluminum
- Electro-tin plated
- I-Beam construction
- 90 degree
- CSA Certified/UL listed

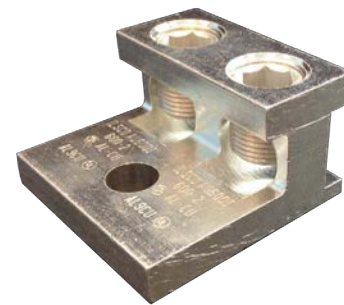


CAT No:	Wire Range
Lug-PA-1-2/0	2/0-6
Lug-PA-1-0250	250 MCM-6
Lug-PA-1-0350	350 MCM-6
Lug-PA-1-0500	500 MCM-4
Lug-PA-1-0600	600 MCM-2
Lug-PA-1-0800	800 MCM - 300 MCM
Lug-PA-1-1000	1000 MCM - 350 MCM
Lug-PA-2-2/0	Two 2/0-6
Lug-PA-2-0250	Two 250 MCM-6
Lug-PA-2-0350	Two 350 MCM-6
Lug-PA-2-0600	Two 600 MCM-2

CAT No:	Wire Range
Lug-PA-2-0800	Two 800 MCM - 300 MCM
Lug-PA-2-1000	Two 1000 MCM - 350 MCM
Lug-PA-2PB-0500	Two 500 MCM-4
Lug-PA-2PB-0600	Two 600 MCM-2
Lug-PA-2PB-0750	Two 750 MCM-4
Lug-PA-3-2/0	Triple 2/0-6
Lug-PA-3-3/0	Triple 3/0-6
Lug-PA-3-0250	Triple 250 MCM-6
Lug-PA-3-0500	Triple 500 MCM-4
Lug-PA-3-0600	Triple 600 MCM-2

Other sizes available upon request.

ACCESSORIES - STANDARD STOCKING LUGS

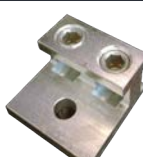LUG	PART NUMBER ILSCO reference #	WIRE RANGE	DIMENSIONS width in inches
	LUG-PA-1-2/0	2/0-6	0.591in W 1.220in L
	LUG-PA-1-0250	250 MCM-6	0.866in W 1.890in L
	LUG-PA-1-0350	350 MCM-6	0.984in W 2.126in L
	LUG-PA-1-0600	600 MCM-2	1.339in W 2.600in L
	LUG-PA-1-0800	800-300 MCM	1.575in W 3.031in L
	LUG-PA-2-0250	250 MCM-6	1.654in W 1.850in L
	LUG-PA-2-0350	350 MCM-6	1.930in W 2.126in L
	LUG-PA-2-0800	800-350 MCM	3.071in W 3.071in L

SPLITTERS, BUSGUTTERS & LUGS

Other sizes available upon request.

ACCESSORIES - STANDARD STOCKING LUGS

LUG	PART NUMBER ILSCO reference #	WIRE RANGE	DIMENSIONS width in inches
	LUG-PA-2-1000	1000-350 MCM	3.228in W 3.268in L
	LUG-PA-A-600	600 MCM 2 x 250 MCM-1/0	1.220in W 1.220in L
	LUG-PA-2PB-0500	500 MCM-4/0	1.417in W 2.913in W
	LUG-PA-SHR-100	4 x 2/0-14	0.551in W 2.402in L
	LUG-PA-SHR-200	2 x 300 MCM-6 2 x 2/0-14	0.984in W 2.953in L
	LUG-PA-LNG-100	7 x 210-14	0.551in W 4.567in L
	LUG-PA-LNG-200	2 x 300 MCM-6 6 x 2/0-14	0.984in W 5.591in L

SPLITTERS, BUSGUTTERS & LUGS

Other sizes available upon request.