

FEATURES & SPECIFICATIONS

INTENDED USE

For use with housings L3 and L3R.

CONSTRUCTION

Finishes are one piece aluminum open reflectors with integral flange.

INSTALLATION

Socket to trim interface.

Retaining clips pull and snap onto top of reflector to hold trim inside housing.

LISTINGS

UL Listed to U.S. and Canadian safety standards.

Damp location listed.

Pull on clip Patent # (U.S.) 5707143, (Canada) 2193902.

WARRANTY

1-year limited warranty. This is the only warranty provided and no other statements in this specification sheet create any warranty of any kind. All other express and implied warranties are disclaimed. Complete warranty terms located at: www.acuitybrands.com/support/warranty/terms-and-conditions

Note: Actual performance may differ as a result of end-user environment and application.

Specifications subject to change without notice.

Catalog
Number

Notes


Type

3" Finishing Trim

3B1

BAFFLE SHALLOW

Narrow Flange

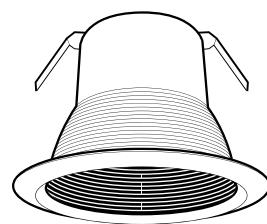


Specifications

Height: 4-3/4 (12.1)

Lamp opening: 3-1/2 (8.9)

Diameter: 4-7/8 (12.4)

All dimensions are inches (centimeters)
unless otherwise indicated.

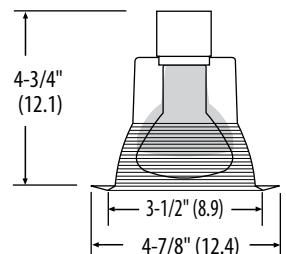

ORDERING INFORMATION

For shortest lead times, configure product using **bolded options**.

Example: 3B1W

3B1

| Series | Finish |
|------------|-----------------------|
| 3B1 | W White baffle |
| | MW Matte white baffle |

Housing Compatibility: Housing and trim ordered separately.

| Application | Source | Maximum wattage | Housing |
|-------------|--------------|-----------------------|---------|
| IC | Incandescent | 35 PAR20 | L3, L3R |
| | | 50 PAR20 ¹ | |
| | | 50 R20 ¹ | |
| Non-IC | Incandescent | 50 PAR20 | L3, L3R |