

FEATURES & SPECIFICATIONS

INTENDED USE — Recessed housing rated IC or Non-IC. For new construction only.

Approved for all ceiling and wiring types.

Approved for direct burial in insulation.

CONSTRUCTION — Air-tight standard. Tested to meet current energy codes.

Aluminum housing with galvanized steel pan.

Galvanized bar hangers span up to 24" o.c. and feature stepped shank nail and positioning guide with integral T-bar locks. Two locking screws hold fixture in position.

Galvanized steel junction box with four built-in Romex clamps. Four 1/2" and two 3/4" knockouts with slots for pryout. Rated for through branch wiring.

Maximum 4 (2 in, 2 out) No. 12 AWG conductors. Rated for 90°C.

Ground wire provided.

Removable J-box doors for easy access.

ELECTRICAL — Durable medium-base porcelain socket with nickel plated copper alloy screw shell and contact.

Socket clips to top of housing to prevent paint overspray in socket screw shell.

Socket attaches to reflector to ensure proper and consistent lamp position.

Thermal protection provided against improper lamp usage.

120 volt only.

INSTALLATION — Air-tight housing suitable for air-tight installations. Refer to energy codes for proper installations.

2x8 and 2x6 wood joist or T-bar installation.

Expandable bar hangers allow for off-center mounting in wood joist or T-bar ceilings. Length of 25-1/2" maximum 13-1/4" minimum or cut to fit 5-1/2" on center joist construction.

Vertical adjustment of housing allows for flush mounting with ceiling face.

Suitable for ceilings up to 1-1/2" thick.

LISTINGS — UL Listed to US and Canadian safety standards. Damp location listing (See trim selection for wet location listing).

WARRANTY — 1-year limited warranty. This is the only warranty provided and no other statements in this specification sheet create any warranty of any kind. All other express and implied warranties are disclaimed. Complete warranty terms located at: www.acuitybrands.com/support/warranty/terms-and-conditions

Note: Actual performance may differ as a result of end-user environment and application.

Specifications subject to change without notice.

Catalog Number
Notes
Type



4" Housing

L3

INCANDESCENT

IC/Non-IC

New Construction

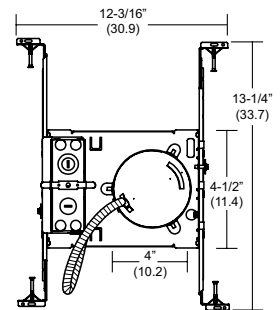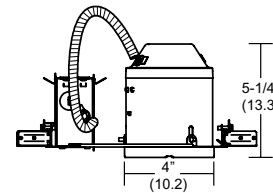

Specifications

Height: 5-1/4 (13.3)

Length: 13-1/4 (33.7)

Width: 12-3/16 (30.9)

Ceiling opening: 4 (10.2)

All dimensions are inches (centimeters) unless otherwise specified.

ORDERING INFORMATION

For shortest lead times, configure product using **bolded options**.

Example: L3 R6

L3		
Series	Options	Packaging
L3	Shipped installed in fixture PHC Poke-home wire connector GSKT Foam gasketing. Aids in air-tight installation.	R6 Resale pack of six U Unit

Notes

See trim summary on reverse side for maximum wattages.


Description Catalog number	Maximum wattage ¹	Description Catalog number	Maximum wattage ¹
General/Task		Accent/Wallwash	
Open Narrow Flange		Eyeball Narrow Flange	
301	White	3E1MW	Matte white
301MW	Matte white		
301A	Clear diffuse, white plastic flange		
301AZ	Clear specular anodized		
301BLZ	Black specular anodized	<i>IC</i>	50 PAR20

Eyeball Narrow Flange
3E1MW Matte white

IC

50 PARZO
 50 RZO

Open Narrow Flange	
301	White
301MW	Matte white
301A	Clear diffuse, white plastic flange
301AZ	Clear specular anodized
301BLZ	Black specular anodized

 

3B1W White
3B1MW Matte white



3B2W White



5 YEAR warranty

DIMMABLE
LED

DAMP LOCATION™

ORDERING INFORMATION For shortest lead times, configure product using **bolded options**.

4G1		LED		
Series/Finish		Lamps	CCT / CRI / W / Lumens ²	Voltage
<u>Series</u>	<u>Finish</u>	LED	30K 90CRI 3000K / 93CRI / 7.7W / 500L 40K 90CRI 4000K / 94CRI / 8W / 560L	(blank) 120V
4G1	4" Gimbal module	MB Matte black ² BN Brush nickel ²		

Notes

- 1 L3 must be ordered on separate line.
2 Total system delivered lumens.