



Trac-Master™ Classics Series

Timeless track lighting solutions

juno®



Trac-Master™ Classics - Stylish Familiarity

Juno Classics are benchmark fixture designs that incorporate timeless shapes and themes. These simple yet elegant fixtures provide economical track lighting solutions in extremely practical, functional packages. Comprised mainly of gimbal rings, cylinders, and universals, Juno design Classics are offered in a variety of


finishes to suit most any décor. Familiar lines and traditional shapes create levels of visual comfort typically not encountered in more contemporary styles. Primarily designed for PAR and R/BR lamps, these uncomplicated fixture styles offer unpretentious aesthetics that blend well in any environment.

Close-Ups


Close-Ups

As the name implies, this compact, stylish lampholder hugs close to the track for minimum intrusion into a space. The softly sculpted back detail and metal shades are welcome design refinements for many interiors.

 
PAR30 - Open

	Catalog #	Finish	Lamp	Dimensions
	T230 WH	White	75W max. PAR30	 1 1/2" H 2 1/4" D 2 1/2" W

PAR30 - Enclosed

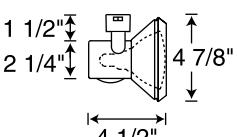	Catalog #	Finish	Lamp	Dimensions
	T231 WH	White	75W max. PAR30	 1 1/2" H 2 1/4" D 4 7/8" H 4 1/2" W
	T231 BL	Black		

PAR38 - Enclosed

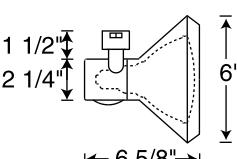	Catalog #	Finish	Lamp	Dimensions
	T239 WH	White	120W max. PAR38	 1 1/2" H 2 1/4" D 6" H 6 5/8" W
	T239 BL	Black		

The product and system may be covered by the following patents: U.S. Patent D376,026; Canada Patent 79,733

Open Back Gimbal

Open Back Gimbal

Gimbal rings are ever popular due to their long-standing use as an economical, general-purpose track lampholder.



Catalog

T363 WH


Finish

White

Lamp

75W max. PAR30

Dimensions

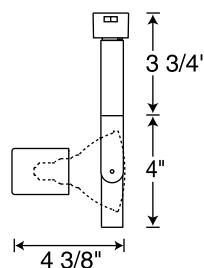

Catalog

T368 WH
T368 BL


Finish

White
Black

Lamp

150W max. PAR38

Dimensions

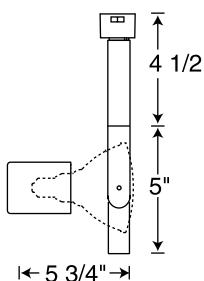




Accessories

For Fixtures	T368
Color Filters	CGF 469
Dichroic Filters	DGF 469
Diffusion Lens	DIFF 469
Uniformity Lens	SOLITE 469
UV Filter	UVF 469
Prismatic Spread Lens	PRISM 469
Linear Spread Lens	LSPREAD 469
Hexcell Louver	HCLBL 469
Cube Cell Louver	CCLBL 469
Snoot	SNOOTBL 469

Front Lamping Gimbals

Front Lamping Gimbals

A Juno innovation, the front-loading gimbal ring combines the practicality, versatility and economy of traditional gimbal ring track fixtures with a fixed socket housing to allow simplified front relamping.

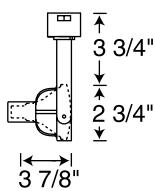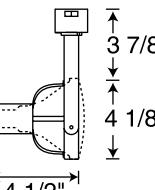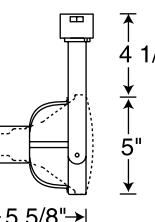	Catalog # T687 BL	Finish Black	Lamp 50W max. PAR20	Dimensions 
	Catalog # T689 WH T689 BL	Finish White Black	Lamp 75W max. PAR30	Dimensions 
	Catalog # T690 WH T690 BL T690 SL	Finish White Black Silver	Lamp 250W max. PAR38	Dimensions 

Note: T690 BL is available with TEK, GTYPE, HTYPE and LTYPE Alternate Mounting Adapters – see specification sheet for details.

Universals

Universals

These economical, universal lampholders accept a wide range of wattages and sizes of popular halogen PAR and incandescent R/BR lamps.



Catalog

T308 WH
T308 BL


Finish

White
Black

Lamp

50W max. R20/
50W max. PAR20/
85W max. BR30/
75W max. PAR30/
120W max. BR40/
150W max. PAR38

Dimensions

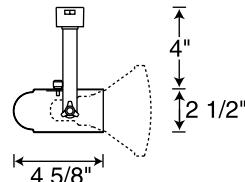

Catalog

T620 WH
T620 BL


Finish

White
Black

Lamp

50W max. R20/
50W max. PAR20/
85W max. BR30/
75W max. PAR30/
120W max. BR40/
150W max. PAR38

Dimensions

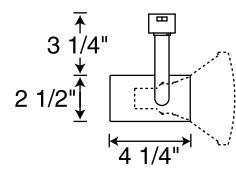

Catalog

T691 WH
T691 BL
T691 NAT


Finish

White
Black
Natural

Lamp

60W max. PAR16/
50W max. PAR20/
75W max. PAR30/
150W max. PAR38

Dimensions

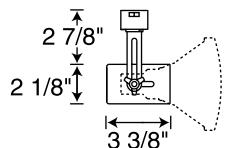

Notes:

T691 WH is available with GTYPE, HTYPE and LTYPE Alternate Mounting Adapters – see specification sheet for details.

The Natural (NAT) finish is merely a raw finish with a clear protective coating applied—inhconsistencies, scratches, and minor processing marks are part of the unique aesthetic created by this process and should be expected.

Flat Black Cylinders

Flat Back Cylinders

These long-standing traditional lampholders accept both halogen PAR and incandescent R/BR lamps and provide deep lamp shielding.



Catalog

T313 WHB WH

T313 BLB BL


Finish

White/White Baffle
Black/Black Baffle

Lamp

50W max. R20/
50W max. PAR20

Dimensions

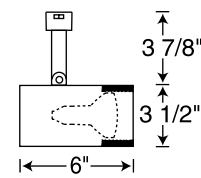

Catalog

T315 BLB BL


Finish

Black/Black Baffle

Lamp

75W max. BR30/
75W max. PAR30L

Dimensions

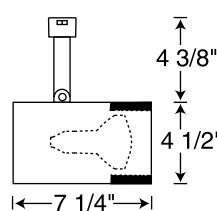

Accessories

For Fixtures	T313	T315
Accessory Holder	T560BL	-
Color Filters	CGF 375*	CGF 469*
Dichroic Filters	DGF 375*	DGF 469*
Diffusion Lens	DIFF 375*	DIFF 469*
Uniformity Lens	SOLITE 375*	SOLITE 469*
UV Filter	UVF 375*	UVF 469*
Prismatic Spread Lens	PRISM 375*	PRISM 469*
Linear Spread Lens	LSPREAD 375*	LSPREAD 469*
Hexcell Louver	HCLBL 375*	HCLBL 469*
Cube Cell Louver	CCLBL 375*	CCLBL 469*
Snoot	SNOOTBL 375*	SNOOTBL 469*
Barn Doors	T71BL 375	T72BL 469

* Filters, lenses and louver require accessory holder or barn doors for installation.



juno®