



JSBT 4in.



JSBT 6in. with Sensor

SlimBasics™ JSBT Tapered LED Surface Mount Disk Light

Available in Static, Switchable, Switchable + Sensor,
and Smart Solutions

juno®



JSBT Surface Mount Disk Lights

Designed to be the lowest total installed cost solution for residential spaces

SlimBasics™ JSBT Tapered LED Disk Light Series come in 4" and 6" sizes and provide even illumination where you need it most. The matte white aluminum housing is aesthetically pleasing bringing a design element that easily blends with any décor. The family consists of an economical, static solution, a flexible solution with switchable white technology, a convenient solution which offers both switchable white technology and motion sensing, and compatible solution that offer smart home technology. This diverse platform gives you an option for every room of a home. Perfect for use in kitchens, closets, hallways, bathrooms and laundry rooms in both single and multi-family homes, as well as in light commercial spaces such as self storage facilities.

Meet the JSBT Family

Static JSBT

Perfect when the color temperature needed is *known*.

Available in 4" & 6" sizes

4in, 750L & 6in, 990L

Available in 2700K & 3000K, 90 CRI

Most Economical Solution



Switchable + Sensor JSBT

Perfect when the choice of color temperature and use of a motion sensor is desired.

Available in a 6" size

6in, 1050L

Available in Switchable White Color Temperatures (3000K, 4000K, 5000K)

Includes Passive Infrared (PIR) Sensor

Most Convenient Solution



Smart JSBTC

Perfect when the choice of color temperature and use of smart home lighting is desired.


Available in 6" size

6in, 1050L

Available in Tunable White Color Temperatures (2700K to 5000K) Controlled via voice command or app.

Connects via Bluetooth® or Zigbee to pair with your mobile device or compatible smart hubs and is certified with Samsung® SmartThings, Amazon® Alexa, and Google Home platforms.

Most Compatible Solution

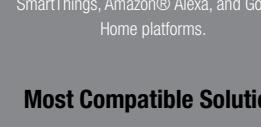

Switchable JSBT

Perfect when the color temperature desired is *unknown*.

Available in 4" & 6" sizes

4in, 750L & 6in, 1000L

Available in Switchable White Color Temperatures (3000K, 4000K, 5000K)

Most Flexible Solution



Create a Consistent Look Across the Entire Home



*Applications noted with  are perfect for the JSBT Switchable with PIR Sensor Solution.

Fast & Easy Installation

The Juno® SlimBasics™ JSBT pairs perfectly with an industry standard JBOX for new construction or retrofit over an existing box to upgrade the look of the space. It's wet location listing makes it great for bathrooms, patios, entryways and porches (non-sensor versions only).



Ordering Information

Ordering Example: JSBT 6IN 30K 90CRI WL MW

Static Solutions	Size	Color Temperature	CRI	Wet Location	Color Finish
JSBT Juno Slim Tapered Disk Light	4IN 4 inch	27K 2700K	90CRI 90+ CRI	WL Wet Location	MW Matte White
	6IN 6 inch	30K 3000K			

Ordering Information

Ordering Example: JSBT 6IN SWW2 90CRI WL MW

Switchable Solutions	Size	Switchable White Color Temperature	CRI	Wet Location	Color Finish
JSBT Juno Slim Tapered Disk Light	4IN 4 inch	SWW2 3000K / 4000K / 5000K	90CRI 90CRI	WL Wet Location	MW Matte White
JSBT Juno Slim Tapered Disk Light	6IN 6 inch				

Ordering Information

Ordering Example: JSBT 6IN SWW2 90CRI PIR MW

Switchable + Motion Sensor Solution	Size	Switchable White Color Temperature	CRI	Sensor	Color Finish
JSBT Juno Slim Tapered Disk Light	6IN 6 inch	SWW2 3000K / 4000K / 5000K	90CRI 90CRI	PIR	MW Matte White

Ordering Information

Ordering Example: JSBTC 6IN TUWH 90CRI WL MW

Smart Trim Series	Size	Tunable White Color Temperature	CRI	Wet Location	Color Finish
JSBTC Juno Slim Tapered Disk Light	6IN 6 inch	TUWH 2700K-5000K	90CRI 90CRI	WL Wet Location	MW Matte White

