


PERFORMANCE SERIES



"Generates 19% more airflow than our old Bronze Line"

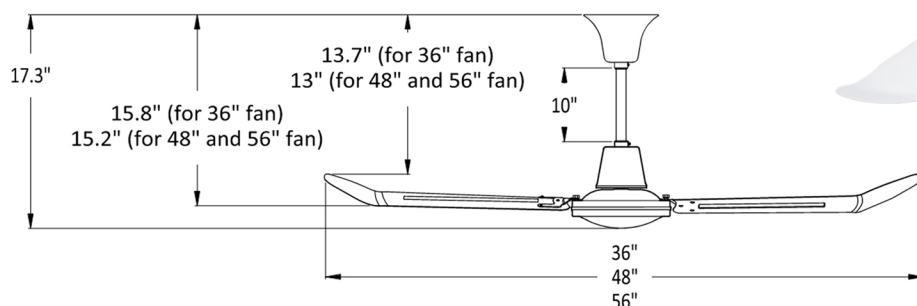

MODEL	FP36R	FP48R	FP56	FP56R
Motor	AC	AC	AC	AC
Safety Cable	72"	72"	72"	72"
Diameter Sweep	36"	48"	56"	56"
Downrod Length	10"	10"	10"	10"
Airflow CFM	3,364	5,216	6,683	6,683
CFM per Watt	84	87	89	89
Volts	120	120	120	120
Amps	0.35	0.5	0.63	0.63
Watts	40	60	75	75
RPM (max)	370	325	320	320
Wiring	3 + ground	3 + ground	plug-in	3 + ground
Direction	up & down	up & down	down only	up & down
Weight	10 lbs	11 lbs	13 lbs	13 lbs
Colour	White	White	White	White

FEATURES

- Standard 10" downrod
- All metal, no plastic
- Corrosion-resistant epoxy primer & finish coat on all metal housing & blades
- The aerodynamically curved-tip blade results in maximum air delivery
- Permanent lubricated double ball sealed bearings
- Totally enclosed heavy duty, impedance protected motor
- Heavy-duty capacitor
- 72" Pre-wired cord & built-in strain relief
- 18", 24" & 36" Downrod available
- Fan guards available