

LPDL™ Eco Choice

LPDL™ ECO Choice is the most economical solution for space-limited downlight applications. This slim downlight can be installed in any residential application, such as basements, hallways, living rooms, and more. It is also available in a 10-pack (white finish only).




 

Order code	Model number	Watts (W)	Volts (V AC)	Color temp. (K) ¹	Lumen output (lm) ²	Efficacy (lm/W)	CRI	Life L70 (hrs) ³	Beam angle (°)	Shape	Finish	Cable rating	Power factor	THD (%)	Master case qty
4" Round															
70144	LPDL4R-9A-5CWH-ECO/CHOICE	9	120	2 700/3 000/3 500/4 000/5 000	750	83.3	80+	50 000	110	Round	White	FT4	>0.9	<20	50
70556	LPDL4R-9A-5CWH-ECO/CHOICE	9	120	2 700/3 000/3 500/4 000/5 000	750	83.3	80+	50 000	110	Round	Black	FT4	>0.9	<20	50
10 Pack															
70145	LPDL4R-9A-5CWH-ECO/CHOICE 10P	9	120	2 700/3 000/3 500/4 000/5 000	750	83.3	80+	50 000	110	Round	White	FT4	>0.9	<20	4

¹ Typical color temperature range: +/- 5 %.

² Lumen values are derived from Energy Star reported data. Initial lumens range: +/- 10 %.

³ Life hours are derived from IESNA LM-80 testing report and projected per IESNA TM-21 extrapolations.

Dimensions

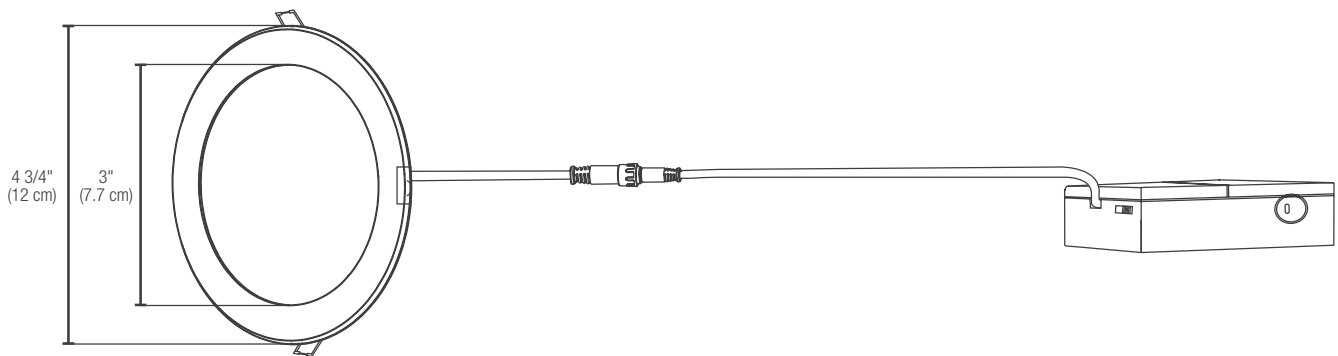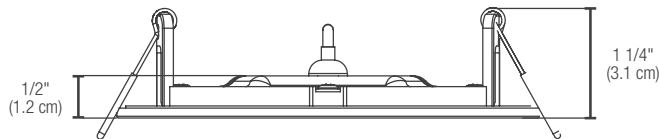

Accessories

Order code	Model number	Type	Inner diameter (in)	Outer diameter (in)	Master case qty
66821 ¹	ACC/MPLATE/4.25IN/HANG.BARS/STD	Mounting plate with hanger bars	4 1/4	-	24
66058	ACC/MPLATE/4.25/ADJ/STD	Adjustable mounting plate	4 1/4	-	24
66051	ACC/MPLATE/4.25/SQR/STD	Square mounting plate	4 1/4	-	96
66143	ACC/4/VAPOR BARRIER/STD	Vapor barrier extender	4 1/4	-	50
68986	GOOF RING-4.25IN	Goof rings	4 1/4	6 1/2	120

¹ Includes brackets and screws.

Lumen values are derived from photometric testing
For a complete list of compatible dimmers and ENERGY STAR
qualified products, please visit www.standardpro.com

