

 
# Swivel Gen. 2 LED Downlight

The LED SWIVEL Choice downlight has been specially designed to highlight specific zones by offering 360° rotation with a 90° tilt. Featuring great performance and quality with a CRI of 90+, this directional downlight is easy to install in any type of ceiling. The LED SWIVEL Choice downlight is a cost-effective solution for all residential applications.




| Order code | Model number              | Watts (W) | Volts (VAC) | Color temp. (K)               | Lumen output (lm) | Efficiency (lm/W) | CRI | Life L70 (hrs) | Beam angle (°) | Shape | Finish | Cable rating | Power factor | THD (%) | Case qty (master) |
|------------|---------------------------|-----------|-------------|-------------------------------|-------------------|-------------------|-----|----------------|----------------|-------|--------|--------------|--------------|---------|-------------------|
| <b>4"</b>  |                           |           |             |                               |                   |                   |     |                |                |       |        |              |              |         |                   |
| 70532      | SWDL4R-G2-9A-5CWH/CHOICE  | 9         | 120         | 2 700/3 000/3 500/4 000/5 000 | 805               | 89                | 90+ | 50 000         | 45             | Round | White  | FT4          | >0.9         | <20     | 32                |
| 70533      | SWDL4R-G2-9A-5CBK/CHOICE  | 9         | 120         | 2 700/3 000/3 500/4 000/5 000 | 805               | 89                | 90+ | 50 000         | 45             | Round | Black  | FT4          | >0.9         | <20     | 32                |
| <b>6"</b>  |                           |           |             |                               |                   |                   |     |                |                |       |        |              |              |         |                   |
| 70534      | SWDL6R-G2-13A-5CWH/CHOICE | 13        | 120         | 2 700/3 000/3 500/4 000/5 000 | 1 210             | 93                | 90+ | 50 000         | 45             | Round | White  | FT4          | >0.9         | <20     | 12                |

## Dimensions




Cutting hole  
4"

4"

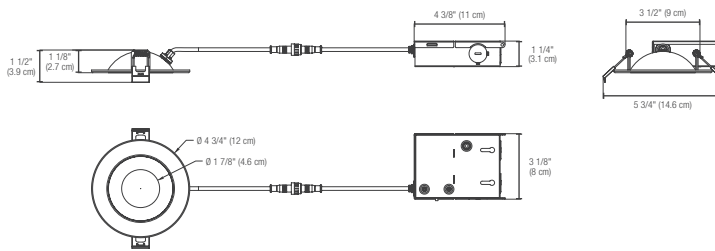


6"

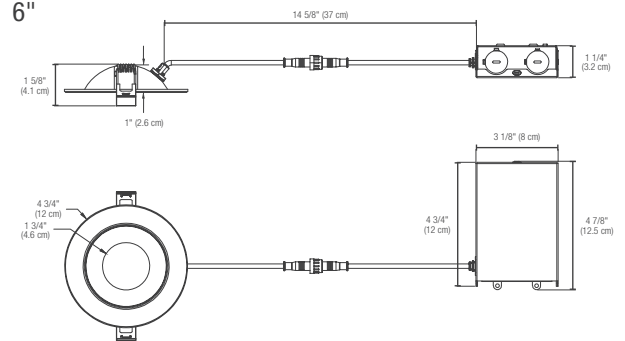

## Accessories (sold separately)

| Order code | Model number                    | Type                            | Opening diameter (in.) | Case qty (master) |
|------------|---------------------------------|---------------------------------|------------------------|-------------------|
| 62771      | ACC/MPLATE/3.75IN/HANG.BARS/STD | Mounting plate with hanger bars | 3 3/4                  | 20                |
| 66050      | ACC/MPLATE/3.75IN/SQR/STD       | Square mounting plate           | 3 3/4                  | 96                |
| 66057      | ACC/MPLATE/3.75IN/ADJ/STD       | Adjustable mounting plate       | 3 3/4                  | 24                |
| 68986      | GOOF RING-4.25IN                | Goof ring                       | 4 1/4                  | 120               |
| 64264      | LPDL/ACC/6FT/EXTCABLE/STD       | 6' Extension cord               | -                      | 96                |

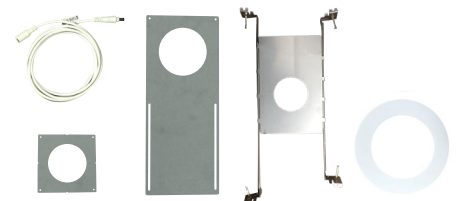

Lumen values are derived from photometric testing  
For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit [www.standardpro.com](http://www.standardpro.com)

