

CBF

COMMERCIAL BASEBOARD



A STURDY BASEBOARD THAT CAN BE RECESSED

The CBF commercial baseboard heater is a suitable choice for commercial buildings, passageways and any other public establishment where wall space is precious and recessed installation is ideal. Surface mountable as well, this heater looks great on its own or installed one end to end in a continuous fashion around the perimeter of a room or corridor.

- **CAN BE RECESSED**
DIRECTLY UNDER WINDOWS
- **OFFERED IN THREE WATT DENSITIES**
- **BLANK SECTIONS AVAILABLE**
FOR A CONTINUOUS LOOK

COLOURS

- **standard:** white
- **Orora (optional):** refer to stelpro.com/orora/

FINISH

- epoxy-polyester powdercoat

MANUFACTURING

- 18-gauge steel cabinet and 16-gauge steel front panel
- thermal protection with automatic reset
- full-length wireway
- pencil-proof openings of less than 1/4 in. (6.4 mm) prevent foreign objects from entering the unit

ELEMENT

- single tubular, stainless steel sheathed element with boxed aluminum fins for improved heat dissipation; the element is securely fastened at its centre, floating in nylon sleeves at each end, eliminating expansion and contraction noises

CONTROL

- wall thermostat (not included) – the use of an electronic thermostat is strongly recommended
- built-in tamper-proof thermostat accessible without removing front grille, installed in the left or right junction box (optional)
- low voltage relay kit installed in the left or right junction box (optional)

INSTALLATION

- surface mounted or wall recessed with four-piece trim frame (optional)
- wall or floor mounted with or without pedestal kit (optional)
- wiring compartments at both ends of unit
- blank sections (custom lengths) and accessories are available for a continuous look (optional)

WARRANTY

- three years

IDEAL FOR:

school, shopping mall, hospital

°STELPRO

Stelpro reserves the right to modify at any time the description, manufacturing, or price of its products. Additionally, Stelpro may apply restocking fees or refuse a refund based on one or more of the following criteria: optional color, custom product, assembly with low-demand options. For the latest product information and prices regarding the products, please visit the website www.stelpro.com.

TECHNICAL SPECIFICATIONS

DENSITY OF 250 W PER LINEAR FOOT		DENSITY OF 200 W PER LINEAR FOOT		DENSITY OF 150 W PER LINEAR FOOT		VOLTAGE	LENGTH		WEIGHT	
CODE	WATTS	CODE	WATTS	CODE	WATTS	VOLTS	MM	IN.	KG	LB
CBF6051W	500	CBF6041W	400	CBF6031W	300	120	600	23 5/8	6.4	14
CBF6058W	500	CBF6048W	400	CBF6038W	300	208	600	23 5/8	6.4	14
CBF6052W	500	CBF6042W	400	CBF6032W	300	240	600	23 5/8	6.4	14
CBF6053W	500	---	400	---	300	347	600	23 5/8	6.4	14
---	500	---	400	---	300	600	600	23 5/8	6.4	14
CBF9071W	750	CBF9061W	600	CBF9041W	450	120	900	35 7/16	9.1	20
CBF9078W	750	CBF9068W	600	CBF9048W	450	208	900	35 7/16	9.1	20
CBF9072W	750	CBF9062W	600	CBF9042W	450	240	900	35 7/16	9.1	20
CBF9073W	750	CBF9063W	600	CBF9043W	450	347	900	35 7/16	9.1	20
CBF9076W	750	---	600	---	450	600	900	35 7/16	9.1	20
CBF12101W	1000	CBF12081W	800	CBF12061W	600	120	1200	47 1/4	13.6	30
CBF12108W	1000	CBF12088W	800	CBF12068W	600	208	1200	47 1/4	13.6	30
CBF12102W	1000	CBF12082W	800	CBF12062W	600	240	1200	47 1/4	13.6	30
CBF12103W	1000	CBF12083W	800	CBF12063W	600	347	1200	47 1/4	13.6	30
CBF12106W	1000	CBF12086W	800	---	600	600	1200	47 1/4	13.6	30
CBF15121W	1250	CBF15101W	1000	CBF15071W	750	120	1500	59 1/16	16.8	37
CBF15128W	1250	CBF15108W	1000	CBF15078W	750	208	1500	59 1/16	16.8	37
CBF15122W	1250	CBF15102W	1000	CBF15072W	750	240	1500	59 1/16	16.8	37
CBF15123W	1250	CBF15103W	1000	CBF15073W	750	347	1500	59 1/16	16.8	37
CBF15126W	1250	CBF15106W	1000	CBF15076W	750	600	1500	59 1/16	16.8	37
CBF18151W	1500	CBF18121W	1200	CBF18091W	900	120	1800	70 7/8	20.0	44
CBF18158W	1500	CBF18128W	1200	CBF18098W	900	208	1800	70 7/8	20.0	44
CBF18152W	1500	CBF18122W	1200	CBF18092W	900	240	1800	70 7/8	20.0	44
CBF18153W	1500	CBF18123W	1200	CBF18093W	900	347	1800	70 7/8	20.0	44
CBF18156W	1500	CBF18126W	1200	CBF18096W	900	600	1800	70 7/8	20.0	44
---	1750	CBF21141W	1400	CBF21101W	1050	120	2100	82 11/16	23.1	51
CBF21178W	1750	CBF21148W	1400	CBF21108W	1050	208	2100	82 11/16	23.1	51
CBF21172W	1750	CBF21142W	1400	CBF21102W	1050	240	2100	82 11/16	23.1	51
CBF21173W	1750	CBF21143W	1400	CBF21103W	1050	347	2100	82 11/16	23.1	51
CBF21176W	1750	CBF21146W	1400	CBF21106W	1050	600	2100	82 11/16	23.1	51
---	2000	---	1600	CBF24121W	1200	120	2400	94 1/2	26.8	59
CBF24208W	2000	CBF24168W	1600	CBF24128W	1200	208	2400	94 1/2	26.8	59
CBF24202W	2000	CBF24162W	1600	CBF24122W	1200	240	2400	94 1/2	26.8	59
CBF24203W	2000	CBF24163W	1600	CBF24123W	1200	347	2400	94 1/2	26.8	59
CBF24206W	2000	CBF24166W	1600	CBF24126W	1200	600	2400	94 1/2	26.8	59
---	2250	---	1800	---	1350	120	2700	106 5/16	27.7	61
CBF27228W	2250	CBF27188W	1800	CBF27138W	1350	208	2700	106 5/16	27.7	61
CBF27222W	2250	CBF27182W	1800	CBF27132W	1350	240	2700	106 5/16	27.7	61
CBF27223W	2250	CBF27183W	1800	CBF27133W	1350	347	2700	106 5/16	27.7	61
CBF27226W	2250	CBF27186W	1800	CBF27136W	1350	600	2700	106 5/16	27.7	61
---	2500	---	2000	---	1500	120	2700	106 5/16	27.7	61
CBF27258W	2500	CBF27208W	2000	CBF27158W	1500	208	2700	106 5/16	27.7	61
CBF27252W	2500	CBF27202W	2000	CBF27152W	1500	240	2700	106 5/16	27.7	61
CBF27253W	2500	CBF27203W	2000	CBF27153W	1500	347	2700	106 5/16	27.7	61
CBF27256W	2500	CBF27206W	2000	CBF27156W	1500	600	2700	106 5/16	27.7	61

Consult the optional colours chart or contact your Stelpro representative for all other colours.

Models also available in 277 V and 480 V.

--- not available

ACCESSORIES


PRODUCT	DESCRIPTION
CBFT12*	built-in tamper-proof single pole thermostat
CBFT22*	built-in tamper-proof double pole thermostat
CBFRE153*	built-in electronic low voltage relay [15 A @ 120 V-347 V]
CBFRE156*	built-in electronic low voltage relay [6 A @ 600 V]
CBFRE153T*	built-in electronic low voltage relay c/w transformer 24 V [15 A @ 208 V-347 V]
CBFRM240T*	built-in electromechanical relay c/w transformer 24 V [6000 W @ 240 V and 5200 W @ 208 V]
CBFRM347T*	built-in electromechanical relay c/w transformer 24 V [6000 W @ 347 V]
CBFRM347C*	built-in electromechanical relay w/o transformer 24 V [6000 W @ 120 V-347 V]
CBFR841D1036*	built-in electromechanical relay w/o transformer 24 V [6000 W @ 600 V]
CBFR841C1151*	built-in electromechanical low voltage relay c/w transformer 24 V [6000 W @ 600 V]
PK2W	pedestal kit (kit of two)
CBFJSW	joiner strip (2 in. – 51 mm)
CBFIC90W	inside corner (back measures 5 7/8 in. (149 mm) long on each side)
CBFOC90W	outside corner (back measures 5 7/8 in. (149 mm) long on each side)
CBFTBW	four-piece trim frame
CBFCBW*	clean back (fully finished, no mounting holes or knockouts)

Electronic relays can receive a PWM (pulsed width modulation) or digital (on/off) signal.

* Factory installed

* Factory installation is strongly recommended.


TECHNICAL DRAWINGS

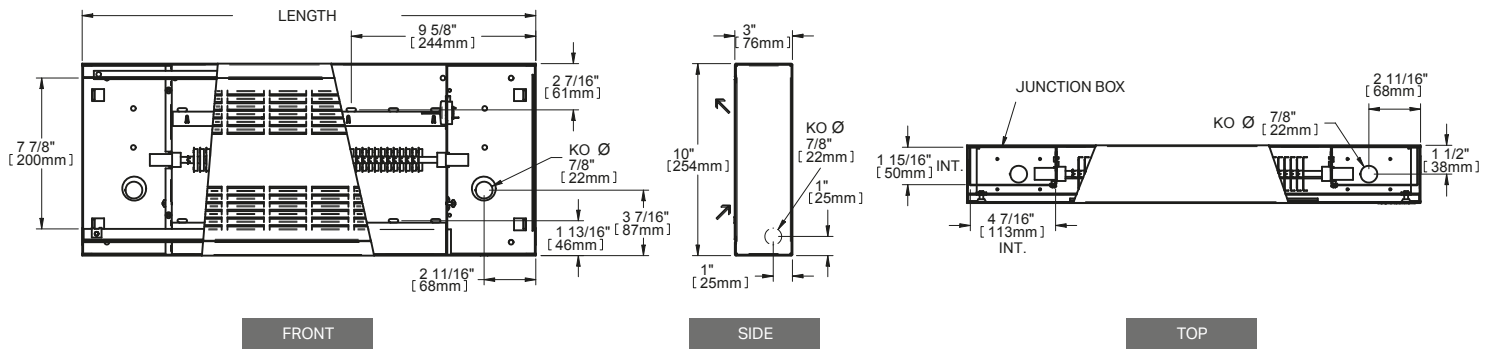

INSTALLATION

SURFACE MOUNTED

RECESSED OR SEMI-RECESSED WITH FOUR-PIECE TRIM FRAME (OPTIONAL)

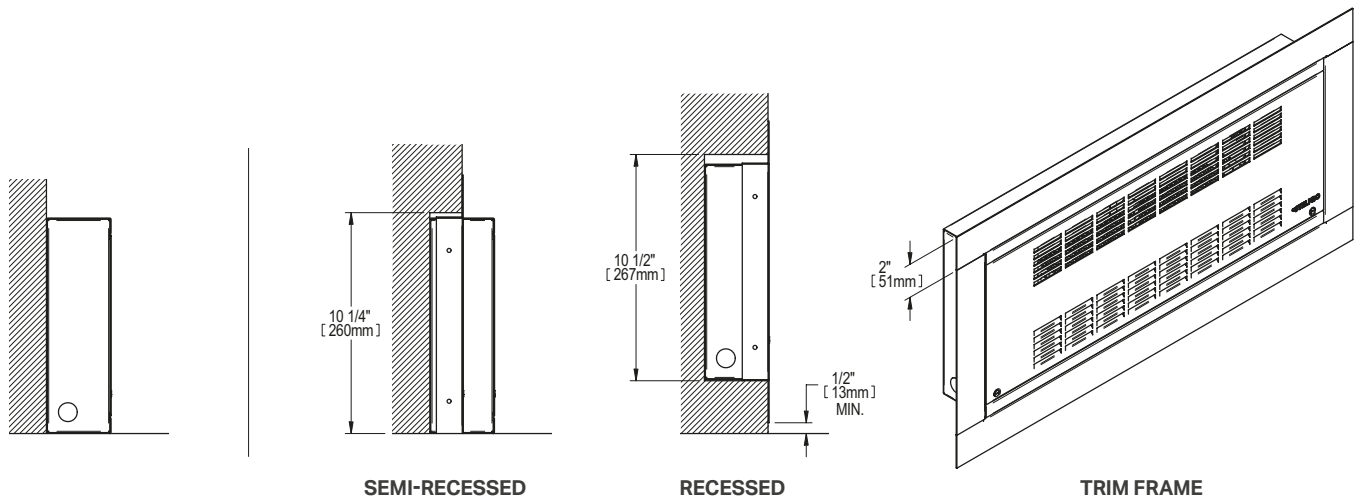

Stelpro reserves the right to modify at any time the description, manufacturing, or price of its products. Additionally, Stelpro may apply restocking fees or refuse a refund based on one or more of the following criteria: optional color, custom product, assembly with low-demand options. For the latest product information and prices regarding the products, please visit the website www.stelpro.com.

