


# MIR – MIRAGE™

## CONVECTOR

# MIRAGE™

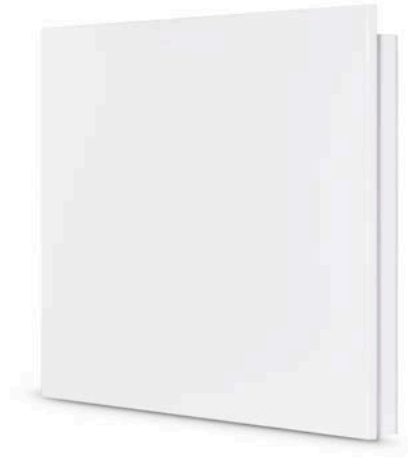

## THE MOST DISCREET ON THE MARKET!

The Mirage convector has a unique, modern and discreet look and offers unquestionable efficiency. Available with or without an ultra-precise integrated electronic thermostat and in several voltages, the Mirage is suitable for rooms in homes or businesses. With its simple facade and elegant design, the Mirage blends in with any decor.

- **BLENDS IN WITH ANY DECOR**
- **STURDY ONE-PIECE FRONT PANEL**
- **TOTALLY QUIET**
- **BUILT-IN ELECTRONIC THERMOSTAT (OPTIONAL) WITH BACKLIT SCREEN**
- **ADAPTS TO MULTIPLE MARKETS**  
AVAILABLE IN 120 V, 208 V, 240 V, 347 V AND 600 V



**BUILT-IN ELECTRONIC THERMOSTAT AVAILABLE FOR THE 120 V TO 240 V MODELS**



ALSO AVAILABLE  
**QUICK AND EASY PLUG-IN INTO 120 V OUTLET**

### IDEAL FOR:

kitchen, living room, bedroom, basement, commercial space, office

### COLOURS

- **standard:** white
- **Orora (optional):** refer to [stelpro.com/orora/](http://stelpro.com/orora/)

### FINISH

- epoxy-polyester powdercoat

### MANUFACTURING

- 20-gauge steel cabinet and front
- the cabinet height improves the chimney effect
- bottom air intake and top air discharge
- 6 ft (2 m) 16 gage molded cable with 3-prong grounded, 120 V plug (MIR1501P model)

### ELEMENTS

- two stainless steel tubular sheathed elements insulated with nylon sleeves reducing expansion and contraction noises

### CONTROL

- electronic thermostat required: built-in electronic thermostat with LCD screen (optional) or electronic wall thermostat (not included)
- automatic temperature lowering at night (Automatic mode)
- maximum temperature setpoint lock option (Security mode)

### INSTALLATION

- surface mounted only
- wall mounted at least 4 in. from the floor
- concealed mounting bracket (included)
- back entry plate with cable clamps (included)

### WARRANTY

- five years, \*three years on electronic components

# °STELPRO

Stelpro reserves the right to modify at any time the description, manufacturing, or price of its products. Additionally, Stelpro may apply restocking fees or refuse a refund based on one or more of the following criteria: optional color, custom product, assembly with low-demand options. For the latest product information and prices regarding the products, please visit the website [www.stelpro.com](http://www.stelpro.com).

# TECHNICAL SPECIFICATIONS

BUILT-IN THERMOSTAT		WITHOUT THERMOSTAT		POWER	VOLTAGE	HEIGHT		LENGTH		WEIGHT	
CODE	CODE	WATTS	VOLTS	MM	IN.	MM	IN.	KG	LB		
MIR0501W	MIR0501WCW	500	120	457	18	444	17 1/2	5.3	11.75		
MIR0508W	MIR0508WCW	500	208	457	18	444	17 1/2	5.3	11.75		
MIR0502W	MIR0502WCW	500/375	240/208	457	18	444	17 1/2	5.3	11.75		
---	MIR0503WCW	500	347	457	18	444	17 1/2	5.3	11.75		
MIR1001W	MIR1001WCW	1000	120	457	18	597	23 1/2	6.7	14.75		
MIR1008W	MIR1008WCW	1000	208	457	18	597	23 1/2	6.7	14.75		
MIR1002W	MIR1002WCW	1000/750	240/208	457	18	597	23 1/2	6.7	14.75		
---	MIR1003WCW	1000	347	457	18	597	23 1/2	6.7	14.75		
---	MIR1006WCW	1000	600	457	18	597	23 1/2	6.7	14.75		
MIR1501W	MIR1501WCW	1500	120	457	18	749	29 1/2	8	17.75		
MIR1508W	MIR1508WCW	1500	208	457	18	749	29 1/2	8	17.75		
MIR1502W	MIR1502WCW	1500/1125	240/208	457	18	749	29 1/2	8	17.75		
---	MIR1503WCW	1500	347	457	18	749	29 1/2	8	17.75		
---	MIR1506WCW	1500	600	457	18	749	29 1/2	8	17.75		
MIR2008W	MIR2008WCW	2000	208	457	18	902	35 1/2	9.4	20.75		
MIR2002W	MIR2002WCW	2000/1500	240/208	457	18	902	35 1/2	9.4	20.75		
---	MIR2003WCW	2000	347	457	18	902	35 1/2	9.4	20.75		
---	MIR2006WCW	2000	600	457	18	902	35 1/2	9.4	20.75		
<b>MODEL WITH 120 V PLUG (RESIDENTIAL OUTLET)</b>											
MIR1501PW*	---	1500	120	457	18	749	29 1/2	8	17.75		

Consult the optional colour chart and contact your Stelpro representative for all other colours.

Mechanical wall thermostats are not compatible with the without thermostat model (WC). An electronic thermostat is required. Models also available in 277 V and 480 V.

\* Available in white only

--- not available

# ACCESSORIES

PRODUCT	DESCRIPTION
MIRRE153*	built-in electronic low voltage relay [15 A @ 120 V-347 V]
MIRRE156*	built-in electronic low voltage relay [6 A @ 600 V]
MIRRE153T**	built-in electronic low voltage relay w/ transformer 24 V [15 A @ 208 V-347 V]

Electronic relays can receive a PWM (pulsed width modulation) or digital (on/off) signal.

\* Factory installed

\* Transformer is supplying 27.5 Vac to thermostat when triac is used at 347 Vac. Here is the voltage supplied by the transformer when triac is used at other voltages:

VOLTAGE TRIAC			
347 Vac	277 Vac	240 Vac	208 Vac
27.5 V	21.2 V	19.0 V	16.5 V

# TECHNICAL DRAWINGS

