


# T87K1015

THERMOSTAT – LOW VOLTAGE / 24 V

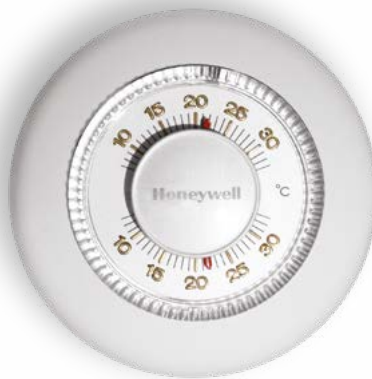

24 V



This model can be installed in any room of the house. Its round design houses a dimmer switch and sports a charming retro look.

- **TWO-WIRE THERMOSTAT (R, W)**
- **COMPATIBLE WITH ALL RE, RM AND R841 RELAYS**
- **TEMPERATURE IN DEGREES CELSIUS**
- **SUITABLE FOR 24 V HEATING UNITS**

#### COLOUR

- white

#### VOLTAGE

- 1 A @ 24 Vac

#### CONTROL

- two-wire connection
- all or nothing (on/off) @ 24 Vac
- compatible with all RE, RM and R841 model relays
- temperature in degrees Celsius

#### TEMPERATURE RANGE

- 10 to 30 °C (50 to 86 °F)

#### WARRANTY

- one year

## TECHNICAL SPECIFICATIONS

PRODUCT	DESCRIPTION
T87K1015	low voltage thermostat (24 V)

DIMENSIONS: 3 11/16 in. diameter x 1 3/4 in. (93.7 mm diameter x 44.5 mm)

°**STELPRO**

Stelpro reserves the right to modify at any time the description, manufacturing, or price of its products. Additionally, Stelpro may apply restocking fees or refuse a refund based on one or more of the following criteria: optional color, custom product, assembly with low-demand options. For the latest product information and prices regarding the products, please visit the website [www.stelpro.com](http://www.stelpro.com).