


STF362PTS – CONCERTO TOUCH

TOUCH SCREEN THERMOSTAT FOR FLOOR HEATING

PROGRAMMABLE

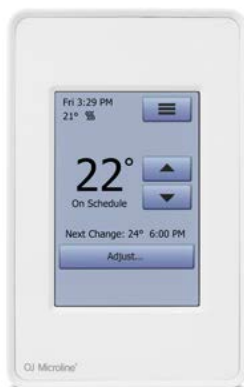

ULTIMATE COMFORT AT YOUR FINGERTIPS

With CONCERTO Touch, say goodbye to wasting time repeatedly pressing the physical up and down buttons to program your thermostat. With its touch screen and intuitive programming, all you need to do is slide your fingers across the screen to set your ideal comfort level.

- **LARGE 3.5-INCH COLOUR TOUCHSCREEN**
CLEARLY AND EASILY DISPLAYS INFORMATION
- **BUILT-IN INSTALLATION WIZARD TO GUIDE YOU THROUGH PROGRAMMING YOUR DEVICE**
- **EASY 7-DAY PROGRAMMING**
SET UP TO FOUR WEEKDAY EVENTS, ACCORDING TO YOUR ROUTINE
- **ENERGY CONSUMPTION LOG**
TRACK OF YOUR FLOOR'S ENERGY CONSUMPTION
- **GROUND FAULT CIRCUIT INTERRUPTER (GFCI CLASS A)**
PROTECTS USERS AND THE INSTALLATION

COLOUR

- White

FINISH

- Moulded plastic

MANUFACTURING

- Fitted with an integrated ground fault circuit interrupter (GFCI) and a test indicator light.
- Terminal block connection / DPST with 2-pole disconnects
- Floor sensor (15 ft/4.5 m) included*

POWER AND VOLTAGE

- Maximum of 1800 W @ 120 V
- Maximum of 3120 W @ 208 V
- Maximum of 3600 W @ 240 V

CONTROL

- Pre-programmed with four weekday events and two weekend events
- Option of controlling Floor temperature (F), Room temperature (R), Room with Floor limit (RF) or in Controller mode (without temperature reading)
- Possibility of setting a maximum temperature setpoint (to protect the floor and users)

- Adaptive function (Early start) – allows heating to reach the setpoint as soon as the program starts
- Temperature can be displayed in degrees Celsius or Fahrenheit

PRECISION

- Precise control of floor or ambient air temperature
- Temperature reading with thermistor

TEMPERATURE RANGE

- Floor: 5 to 40°C (41 to 104°F)
- Ambient: 0 to 40°C (32 to 104°F)

WARRANTY

- Three years

*This thermostat is also compatible with floor sensors produced by other manufacturers.

TECHNICAL SPECIFICATIONS

PRODUCT	WATTS	VOLTAGE	AMPERAGE	FREQUENCY	GFCI
CODE	MAXIMUM	VOLTS	AMPS	HZ	MA
STF362PTS	1800/3120/3600	120/208/240	15	50/60	5

°STELPRO

Stelpro reserves the right to modify at any time the description, manufacturing, or price of its products. Additionally, Stelpro may apply restocking fees or refuse a refund based on one or more of the following criteria: optional color, custom product, assembly with low-demand options. For the latest product information and prices regarding the products, please visit the website www.stelpro.com.