

# SKS

## KICK SPACE HEATER



### HIDE 'N HEAT

"Hide 'n heat" is what the SKS kick space heater by Stelpro offers. Its sleek, redesigned grille is slimmer than ever for easy installation in narrow spaces under kitchen or bathroom cabinets or in stair risers. Enjoy comfortable forced-air heating from the most discreet fan heater on the market.

- **POWER SELECTOR SWITCH**
- **EASY INSTALLATION**
- **ATTRACTIVE GRILLE**  
ONE-PIECE, FRAMELESS

#### COLOURS

- **standard:** white
- **luxury finish:** stainless steel
- **Orora (optional):** refer to [stelpro.com/orora/](http://stelpro.com/orora/)

#### FINISH

- epoxy-polyester powdercoat

#### MANUFACTURING

- 22-gauge steel cabinet and 16-gauge steel front
- quiet, 50 CFM capacity
- thermal protection with automatic reset
- added protection provided by a fuse-link (must be replaced once activated)

#### WATTAGE AND VOLTAGE

- power selector switch

#### ELEMENT

- tubular element sheathed with spiral-wound fins for improved heat dissipation

#### CONTROL

- wall thermostat (not included) – the use of an electronic thermostat is strongly recommended
- built-in thermostat (optional), 3 control knobs included (white, soft white and black)

#### INSTALLATION

- recessed

#### WARRANTY

- five years, \*three years on electronic components

#### IDEAL FOR:

under a kitchen or bathroom cabinet, in a stair riser

# °STELPRO

Stelpro reserves the right to modify at any time the description, manufacturing, or price of its products. Additionally, Stelpro may apply restocking fees or refuse a refund based on one or more of the following criteria: optional color, custom product, assembly with low-demand options. For the latest product information and prices regarding the products, please visit the website [www.stelpro.com](http://www.stelpro.com).



## TECHNICAL SPECIFICATIONS


PRODUCT	POWER	VOLTAGE	THROW DISTANCE (IN FRONT)		HEAT RISE		WEIGHT	
			CODE	WATTS	VOLTS	M	FT	°C
<b>SKS1001</b>	500 OR 1000	120	1.2	4	55	99	4.5	10
<b>SKS1002</b>	500/375 OR 1000/750	240/208	1.2	4	55	99	4.5	10

Add W for white or SS for stainless steel (consult the optional colours chart or contact your Stelpro representative for all other colours).

## ACCESSORIES

PRODUCT	DESCRIPTION
<b>SKST1</b>	built-in single pole thermostat
<b>SKST2</b>	built-in double pole thermostat
<b>SKSRW</b>	extended white grille (23 5/8 in. x 3 3/4 in. – 600 mm x 95 mm) allows to cover gaps or imperfections for a renovation project
<b>SKSRSS</b>	extended stainless steel grille (23 5/8 in. x 3 3/4 in. – 600 mm x 95 mm) allows to cover gaps or imperfections for a renovation project

## TECHNICAL DRAWINGS

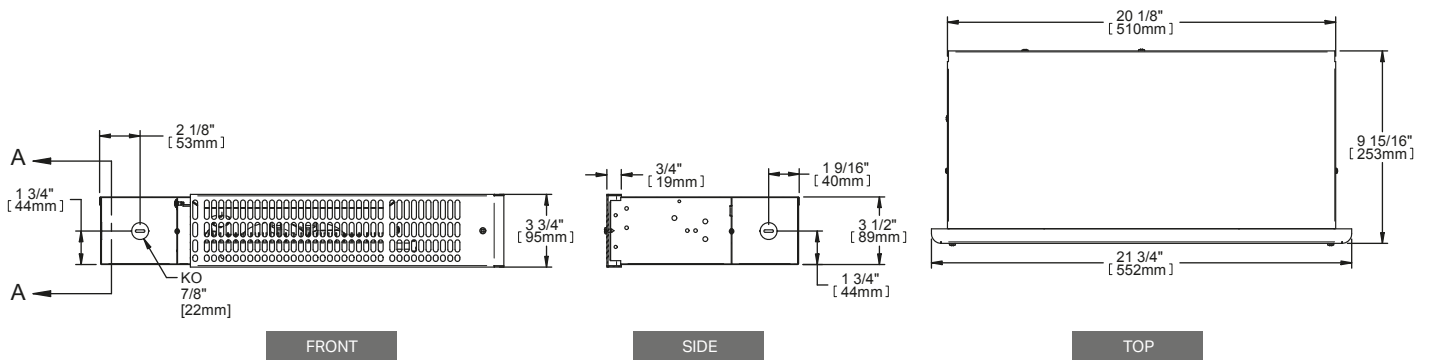

Stelpro reserves the right to modify at any time the description, manufacturing, or price of its products. Additionally, Stelpro may apply restocking fees or refuse a refund based on one or more of the following criteria: optional color, custom product, assembly with low-demand options. For the latest product information and prices regarding the products, please visit the website [www.stelpro.com](http://www.stelpro.com).