

# SLIM-PROFILE MAGNETIC MINI RATCHET

Superior access in tight spaces and strong magnetic capability



**FINGER LOOP**  
Offers one-handed use and easy storage

**REMOVABLE 4-BIT STORAGE**

**TWO-WAY ADJUSTMENT**  
Easily switch ratchet direction


**SLIM PROFILE DESIGN**  
Superior access in tight spaces

0.54"  
(1.4 cm)

4.28" (10.9 cm)

## 90-TOOTH RATCHET

For effective range and controlled turning in tight spaces VS. standard 72-tooth

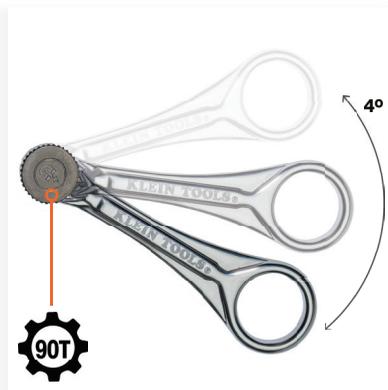

## MAGNETIC MINI RATCHET WITH REMOVABLE 4-BIT STORAGE

Includes #2 Phillips, 1/4-Inch Slotted, #2 Square, & 1/4-Inch Nut Driver Adapter



## STRONG MAGNETIC CAPABILITY

Allows bit to transfer magnetism and hold onto metal fasteners hands free



Cat. No.	UPC	Description	Overall Length
65200MAG	7-83423-02111-0	Slim-Profile Magnetic Mini Ratchet	4.28" (10.9 cm)

⚠ Visit [www.kleintools.com](http://www.kleintools.com) for warnings and instructions.

See our complete line of Socket Wrenches. • [www.kleintools.com](http://www.kleintools.com)



© 2026 Klein Tools, Inc. • Lincolnshire, IL 60069 • Rev. A • 01/26