




Used for bending wires in panels, disconnects, LB's and wire-ways. The Bulldog Bender will prove to be a valuable tool to add to your arsenal. As with any specialty tool, with practice you will learn how to use the Bender to its full bending potential. Designed and manufactured by an electrician for electricians.

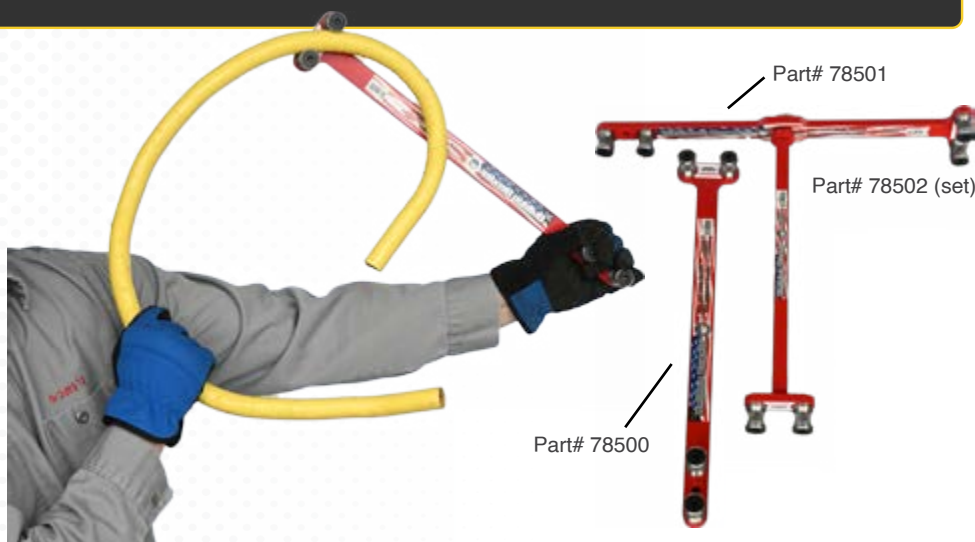

Bends up to 500 mcm

78500 - Bulldog Original
78501 - Bulldog Pro with Adaptor
78502 - Bulldog 3 Piece Set (original & Pro)

Bends up to 750 MCM

78600 - Bulldog Big Daddy 3 Piece Set

Bends up to 4/0

78400 - Bulldog Pup
78402 - Bulldog 'Pup Pro' 2 piece set
78403 - Bulldog Pup 3 piece set

Bend-All

Bend Large Wire in the Tightest Locations

A cable bender that attaches to a 1/2" ratchet for extra leverage, easily bending stiff wires in tight spaces without damage. The Sr. can bend up to 600 MCM with an increased surface area for extra leverage. The Original can bend up to 500 MCM and takes the struggle out of working in a small meter base, LB fitting or distribution panel.



COMING SOON

Bend-All Sr.
Bends up to 600 MCM
Part# 77460

Bend-All Original
Bends up to 500 MCM
Part# 77455

Features:

- Made with Aircraft Grade Aluminum.
- Made in Canada.



HOPPY BENDER

EASIEST, FASTEST & MOST ACCUARATE PIPE BENDER ON THE MARKET

The most innovative and smartest pipe bender on the market. We have revolutionized the way electricians bend pipe - it has never been easier or faster than it is now with the Hoppy Bender. Even the most complicated bends are made As Easy As 1,2,3. Offsets, 3 & 4-point saddles, 90-degree bends always perfect and done in a fraction of the time!

EASY AS 1,2,3!

The Hoppy Bender is hands down the smartest & most innovative bender on the market. We have revolutionized the way electricians bend pipe - it has never been easier or faster than it is now with the Hoppy Bender.

STEP ONE

Read table and mark pipe



Part#

- 57050 - 1/2" Hoppy Bender
- 57075 - 3/4" Hoppy Bender
- 57002 - Replacement Handle
- 57005 - Replacement Thumb Screw
- 57050LAB - 1/2" Replacement Label
- 57057 - 1/2" Replacement Swing-Stop
- 57075LAB - 3/4" Replacement Label
- 57077 - 3/4" Replacement Swing-Stop

STEP TWO

Set Stop



STEP THREE



Features:

- A "Stop" attached to the Bender head used to create exact and repeatable bends every time.
- Simplified "Multipliers" engraved into the bender for placing the "Stop" prior to making offsets and four-point saddles.
- Special 22.5 and 45-degree marks engraved into the bender for placement of conduit bend marks as well as standard degree marks for stop placement, used together for bending three-point saddles without reversing the conduit in the shoe.
- Handy reference charts attached to the handle for locating bend marks.

Part# #57090



KICK WEDGE

Level Out Your 90-Degree Kicks

A lightweight, affordable tool that levels your 90-degree conduit bends before adding a kick or second bend. It solves the problem of uneven surfaces or bender placement raising your 90 differently each time, ensuring consistent results every time.


Features:

- Compatible with: 1/2", 3/4", 1" and 1-1/4" conduit sizes.



THE FERRET

4m - #EP04M
8m - #EP08M

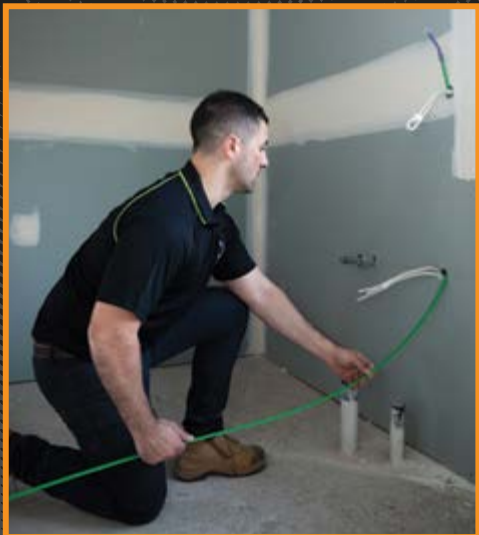

LEADER WHEEL ACCESSORY

The Ferret is a game-changer for wire fishing, effortlessly tackling challenges like fishing wires through insulation or tight spaces. A tough, flexible wire fishing tool designed for accuracy and durability. Its guide wheel glides over obstacles, and its fiberglass-reinforced body handles tight spaces and impacts with ease. A steel hook accessory makes grabbing cables fast and efficient, perfect for solo jobs!

Features:

- Available in 4 m (13 ft) and 8 m (26 ft) lengths.
- Made of durable fiberglass-reinforced polymer.
- Long enough to fish wires up two-story walls (8 m model).
- Versatile for horizontal, vertical, and angled wiring.



FIBER RODDERS

1/2"

#FS12657

Ideal for big wire fishing, with threaded ends for four attachments and a cantilevered frame for better leverage and balance.

Features:

- Fiberglass-reinforced plastic with a durable coating
- Rubber wheels for smooth, reliable transport



3/16"

#FS316300

Fiberglass-reinforced fish tape with a durable, low-friction coating. Features a lightweight, anti-corrosion steel frame.

Features:

- Brass ends with embedded pins hold up to 300 lbs.
- Adjustable knob for wheel speed control.
- Threaded brass ends fit pulling eye or flexible guide leads.
- Made of fiberglass-reinforced plastic with a 0.16" diameter.



1/4"

(FS14600, FS14500, FS14400, FS14300)

Can handle up to 600 ft., tackles big jobs with threaded ends for four attachments and a balanced cantilevered frame for easy transport.

Features:

- Fiberglass-reinforced plastic with low-friction coating for smooth pulls
- 1430 lbs. breaking strength
- Available in various lengths
- Brass pulling eye with large eyelet for easy access
- Lightweight, durable steel frame with anti-corrosion treatment
- Adjustable knob for controlling wheel rotation speed



Fibre Rodders Splice Kit



FS12.END - End Repair for 1/2" Fibersnake
FS12.EYE - Eye-Loop for 1/2" Fibersnake
FS12.SPL - Splice Repair for 1/2" Fibersnake
FS14.END - End Repair for 1/4" Fibersnake
FS14.SPL - Splice Repair for 1/4" Fibersnake