

4 in. Octagonal boxes

Conduit knockouts

01 **BCOBEX**
Octagonal box extension.

02 **BC56111**
Ceiling pan.

03 **BC54151-K**
Concentric knockouts.

04 **CI54151-KSSX**
Concentric knockouts.
"Wraparound" bracket for 2½ in. and 3⅝ in. steel studs. With integral support bracket.

05 **BC55151-K**
Extension ring with ground screw.
Concentric knockouts.

06 **C54171-K**
Concentric knockouts.

07 **CI54151-KSSX**
Concentric knockouts.
"Wraparound" bracket for 2½ in. and 3⅝ in. steel studs. With integral support bracket.

08 **CI54171-KSSX-1**
Mounting strap (offset for 2 x ½ in. drywall thicknesses).

09 **CI55171-K**
Extension ring with ground screw, concentric knockouts.




01



02



03

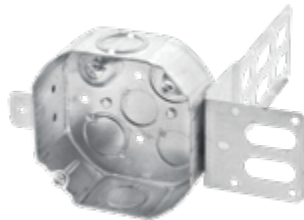


04



05



06

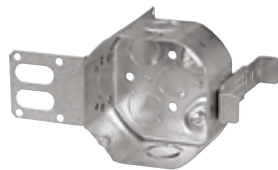

07



08



09



Cat. No.	Description
½ in. deep – extensions	
BCOBEX	Extension for octagonal boxes. ½ in. non-adjustable depth. Complete with mounting screws (5 cu. in.)

Cat. No.	Volume (Cu. in.)	Bracket	Features				Knockouts	
			Raised Ground Screw	½ in. sides	½ in. bottom	¾ in. sides	¾ in. bottom	
½ in. deep								
BC56111	5.0	–	yes	–	4	–	–	–
1½ in. deep								
BC54151-K	15.0	–	yes	4	4	2	2	2
CI54151-KSSX	15.0	"SSX"	yes	2	4	2	2	2
BC55151-K	15.0	–	yes	4	–	2	–	–
2⅛ in. deep								
BC54171-K	21.0	–	yes	4	4	2	2	2
CI54171-KSSX	21.0	"SSX"	yes	2	4	2	2	2
CI54171-KSSX-1	21.0	"SSX-1"	yes	2	4	2	2	2
CI55171-K	21.0	–	yes	4	–	2	–	–

4 in. Octagonal boxes

Nonmetallic sheathed cable clamps

01 **BC54151-L**
Prepositioned depth tabs recessed $\frac{1}{2}$ in.

02 **BC54151-LB**
Side bracket, with holding prongs and prepositioned depth tabs.

03 **BC54151-LD**
"Swing-arm" rework brackets. Max. wall thickness: $\frac{3}{4}$ in., Max. load capacity: 12 lb (5.5 kg).

04 **BC54171-L**

05 **BC54171-LB**
Side bracket, with holding prongs.

06 **CI54171-LF**
Ceiling fan box.
(Supplied with 2 #10-32 machine screws and star washers.) Max. load capacity: 35 lb (15.6 kg).



01



02



03



04



05



06



Cat. No.	Volume (Cu. in.)	Features			Knockouts		Pryouts	
		Bracket	Raised Ground Screw	$\frac{1}{2}$ in. sides	$\frac{1}{2}$ in. bottom	Sides	Bottom	
$\frac{1}{2}$ in. deep								
BC54151-L	15.0	–	yes	2	1	4	4	
BC54151-LB	15.0	"B"	yes	1	1	4	4	
BC54151-LD	15.0	rework	yes	–	1	4	4	
CI54151-LF	15.0	–	yes	2	1	4	4	
$\frac{2}{8}$ in. deep								
BC54171-L	21.0	–	yes	2	1	4	4	
BC54171-LB	21.0	"B"	yes	1	1	4	4	
BC54171-LD	21.0	rework	–	–	1	4	4	
CI54171-LF	21.0	–	yes	2	1	4	4	

For use with nonmetallic sheathed cable only.

Note: CEC 2012 rule 30-302: Subrule (4) requires that a ceiling-mounted luminaire weighing 23 kg or less be supported on a ceiling outlet box attached directly to the building structure. A bar hanger may also be used to attach a ceiling outlet box to the building structure when the luminaire weighs 23 kg or less.

4 in. Octagonal boxes

Armoured cable clamps

01 BC54151-LA

02 BC54151-LSSAX
 "Wraparound" bracket for 2¹/₂ in. and 3-⁵/₈ in. steel studs. With integral support bracket.


03 BC54171-LSSAX

04 BC54171-L


05 BC54171-LSSAX-5/8
 Brackets for use with 5/8 in. drywall.



01

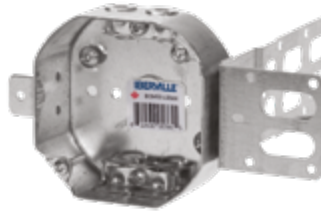

02

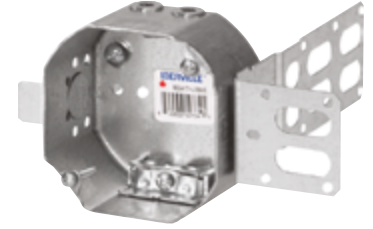

03



04



05



Cat. No.	Volume (Cu. in.)	Features			Knockouts		Pryouts	
		Bracket	Raised Ground Screw	1/2 in. sides	1/2 in. bottom	Sides	Bottom	
1¹/₂ in. Deep								
BC54151-LA	15.0	-	yes	2	1	4	-	
BC54151-LSSAX	15.0	"SSX"	yes	-	1	4	-	
2¹/₈ in. Deep								
BC54171-LA	21.0	-	yes	2	1	4	-	
BC54171-LSSAX	21.0	"SSX"	yes	-	1	4	-	
BC54171-LSSAX-5/8	21.0	"SSX"	yes	-	1	4	-	

4 in. Octagonal boxes

Covers



BC54-C-1



BC54-C-6



CI54-C-64



BC54-C-65



BC54-C-94



BC54-COV



BC54-COV-1



Cat. No.	Description
4 in. round covers	
BC54-C-1	Flat blank
BC54-C-6	Flat with 1/2 in. conduit knockout
CI54-C-64	Flat for 1 13/32 in. diameter. 15 A single receptacle. Device mounting screws included
BC54-C-65	Flat for duplex receptacle. Device mounting screw included
BC54-C-94	Flat for toggle switch. Device mounting screws included
5 in. round covers (white enamel paint)	
BC54-COV	Flat with 1/2 in. conduit knockout. Mounting screws included
BC54-COV-1	Flat blank. Mounting screws included
Flat colored covers	
BC54-C-1-YE	Yellow
BC54-C-1-OR	Orange
BC54-C-1-RED	Red
BC54-C-1-PU	Purple
BC54-C-1-BLU	Blue
BC54-C-1-GRN	Green
BC54-C-1-GRY	Grey
BC54-C-1-BRO	Brown
BC54-C-1-WH	White
BC54-C-1-BK	Black