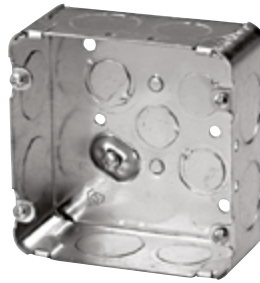
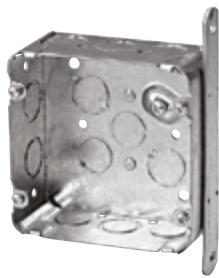
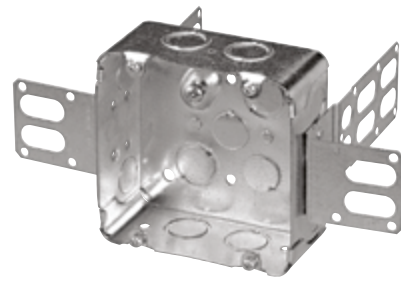


4 11/16 in. Square boxes

Conduit knockouts

—
01—
02—
03—
04—
05—
06—
07

—
01 CI72151-K
Concentric knockouts.

—
02 BC73151-K
Concentric knockouts.

—
03 CI72171-1
1" knockouts.

—
04 BC72171-K
Concentric knockouts.

—
05 CI72171-KSB
Concentric knockouts
with side bracket.

—
06 CI72171-KSSX
Concentric knockouts
with lateral support.
"Wraparound" brackets for
2 1/2 in. and 3 5/8 in. steel
studs.

—
07 BC73171-K
Concentric knockouts.



Cat. No.	Volume (Cu. in.)	Features							Knockouts
		Bracket	Raised Ground Screw	1/2 in. sides	1/2 in. bottom	3/4 in. sides	3/4 in. bottom	1 in. sides	
1½ in. deep									
CI72151-K	30.0	–	yes	10	4	6	2	–	
BC73151-K	30.0	–	–	10	–	6	–	–	
2⅛ in. deep									
CI72171-1	42.0	–	yes	–	4	2	2	6	
BC72171-K	42.0	–	yes	10	4	6	2	–	
CI72171-KSB	42.0	“SB”	yes	8	4	2	2	–	
CI72171-KSSX	42.0	“SSX”	yes	4	4	4	2	–	
CI72171-1-SSX	42.0	“SSX”	yes	–	4	2	2	4	
BC73171-K	42.0	–	–	10	–	6	–	–	

4 11/16 in. Square boxes

Mud / Plaster ring covers




BC72-C-1



BC72-C-6



CI72-C-10 / CI72-C-13

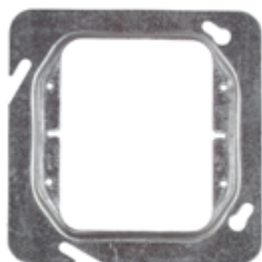

72 C 17



72 C 14 5/8



72 C 18 5/8



CI72-A-52



Cat. No.	Description
Flat covers	
BC72-C-1	Blank
BC72-C-6	With concentric 1/2 in. and 3/4 in. conduit knockout
Single device covers	
CI72-C-10	Raised 1/8 in. (1.7 cu. in.)
CI72-C-13	Raised 1/2 in. (4.3 cu. in.)
72 C 14*	Raised 3/4 in. (5.0 cu. in.)
72 C 14 5/8*	Raised 5/8 in. (4.0 cu. in.)
Two device covers	
72 C 17*	Raised 1/2 in. (6.3 cu. in.)
72 C 18 5/8*	Raised 5/8 in. (7.5 cu. in.)
Adaptors	
CI72-A-52	To install 4 in. square covers on 4 11/16 in. square boxes. Raised 1/4 in. (3.0 cu. in.)
Flat colored covers	
BC72-C-1-YE	Yellow
BC72-C-1-OR	Orange
BC72-C-1-RED	Red
BC72-C-1-PU	Purple
BC72-C-1-BLU	Blue
BC72-C-1-GRN	Green
BC72-C-1-GRY	Grey
BC72-C-1-BRO	Brown
BC72-C-1-WH	White
BC72-C-1-BK	Black

* UL Listed and CSA certified