



Juno® Wafer™ LED Downlights

Canless Downlights - No Housing Required



Juno®
Better by Design™

Juno® Wafer™

Slim design, installs virtually anywhere, no housing needed

The Juno® Wafer™ Downlight family features a slim, canless design that installs directly into the ceiling eliminating the need for traditional recessed housings. Both the fixture and driver box are IC rated allowing them to be installed in direct contact with insulation, and they can fit into as little as 3 inches of plenum. Whether you're looking for a budget friendly downlight or your next solution for a light commercial space, Juno Wafer Downlights have you covered.



Outdoor



Kitchen



Bathroom



Fast, Easy, Housing-Free Installation

Wafers redefine recessed downlighting installations! With their slim design and remote driver box, Wafers fit into confined spaces with shallow plenums that traditional recessed housings do not fit in.

Make installation quick & simple with the Wafer family!



Driver box is big enough for easy wiring, but small enough for tight spaces. Plus, the length of cord provides flexibility.


Just 4 Simple Steps



1 Create Opening with Hole Saw



2 Wire the Driver Box

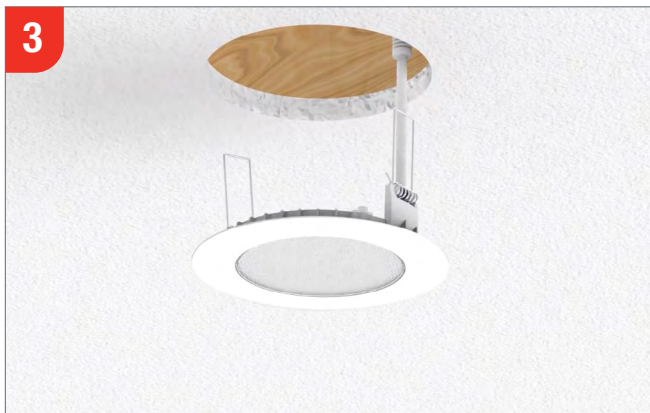

3 Secure the Wafer Module




4 Turn on the Light

Flexibility at Your Fingertips

Switchable White CCT Feature (SWW)




The innovative switchable white feature provides the option to choose from 5 color temperature settings during installation. Too warm or too cool? Simply toggle the integrated switch to your desired setting and you are done! Whatever your application, Wafers with switchable white are sure to give you the feel and flexibility you desire.

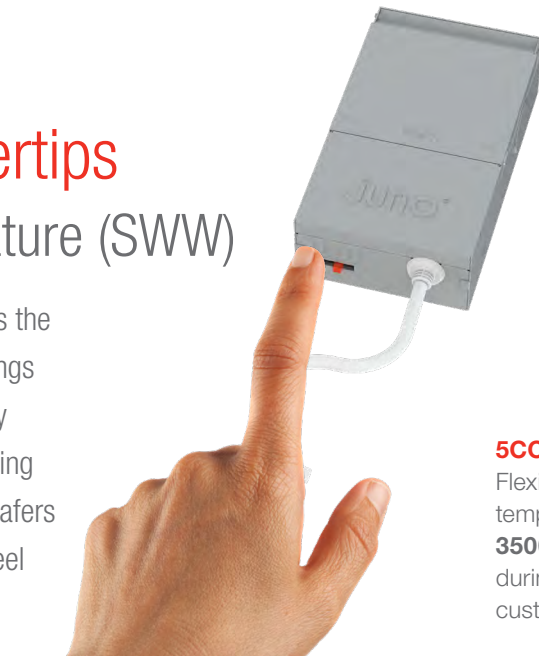

5CCT Options

Flexibility to switch color temperature to **2700/3000/3500/4000/5000K** CCT during installation to customize any application.

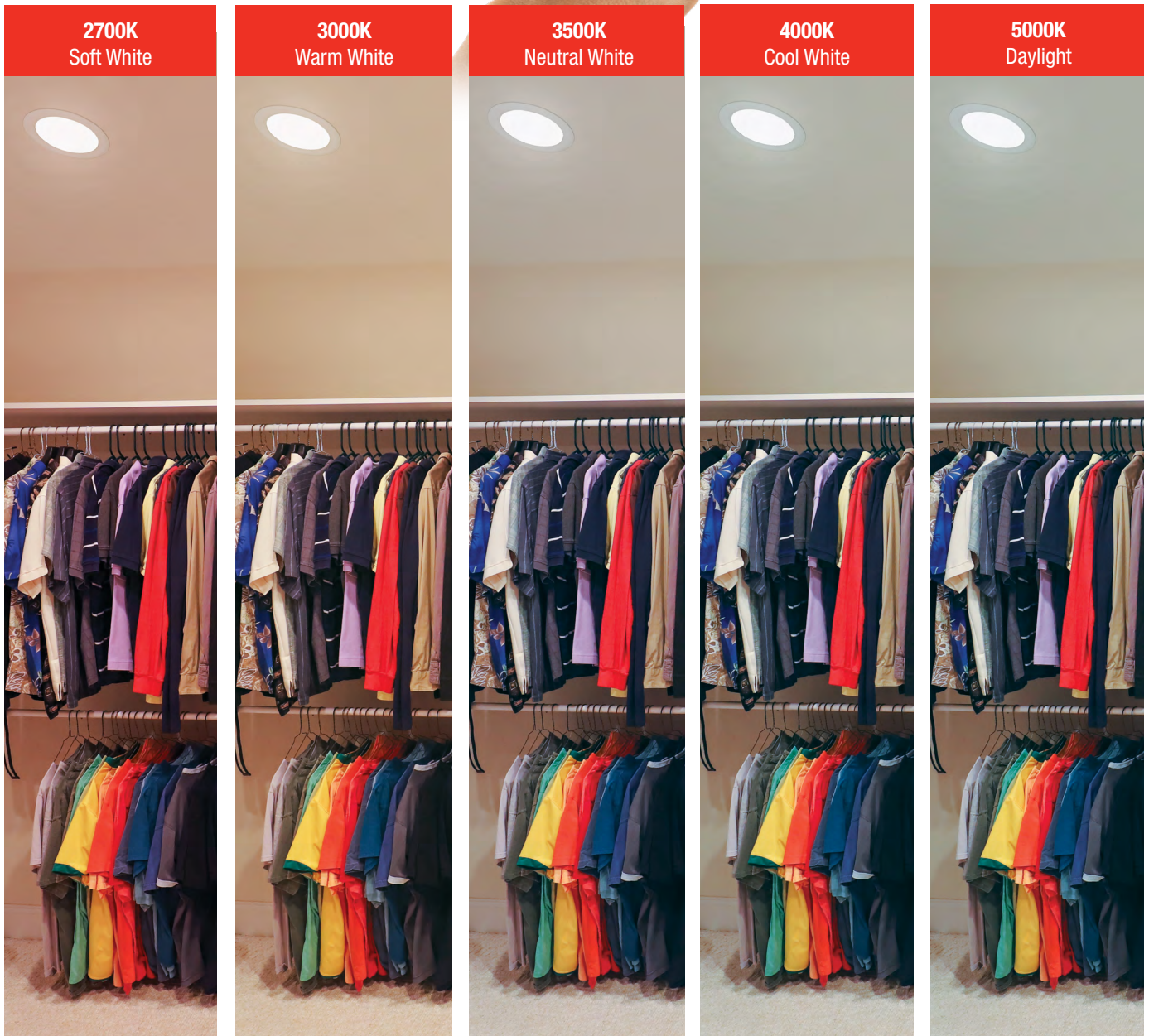



Task Lighting

General Lighting

Accent Lighting

Application Flexibility



Flexibility at Your Fingertips Adjustable Lumen Output Feature (ALO)

The convenient adjustable lumen output settings switch (ALO) is designed to provide 3 lumen settings in one product. Too dim or too bright? Simply toggle the integrated switch to your desired setting and you are done! This feature is perfect for areas needing extra light or for higher ceilings.



ALO Options
Flexibility to switch lumen outputs between low, medium, and high settings during installation to customize any application.



Five Styles to Choose From

Flat

Modern Aesthetic
2", 4", 6", 8" Sizes



You Choose



5 CCT + ALO



*Available in 120V and MVOLT



Matte White



Matte Black



Brushed Nickel



Oil Rubbed Bronze

Scan for more information



Deep Regressed

Traditional Aesthetic
2", 4", 6" Sizes



5 CCT + ALO



Smooth

Baffle



Matte White



Matte Black



Brushed Nickel



Oil Rubbed Bronze

Scan for more information



Semi-Regressed

Baffle Aesthetic
4", 6" Sizes



Matte White

Scan for more information



Adjustable

20° Tilt
4" & 6" Sizes



Matte White



Matte Black



Brushed Nickel

Scan for more information



Square

Modern Aesthetic
4" & 6" Sizes



5 CCT + ALO



Matte White



Scan for more information



New Construction Mounting Frames

WF8643 Pan
Fits: 3", 4", 6", & 8"
downlights



2NCMFLP Pan
Fits: 2" downlights



Stock Shipped Same Day

Providing the right products, that are readily available and with trusted performance that you can count on. These are in stock and available for same-day shipment.



Readily Available



Right Products



Trusted Performance


Coverage for Every Job

Flat



Light designed for wide coverage

Ideal Spaces:
Hallways
Living Rooms
Bedrooms

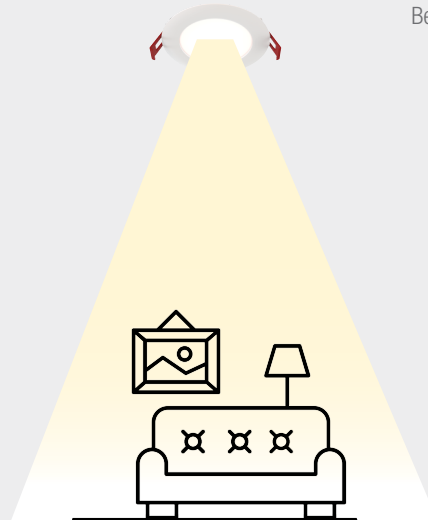


Deep Regressed



Light designed for a more focused illumination

Ideal Spaces:
Kitchens
Home Office
Dinning Rooms

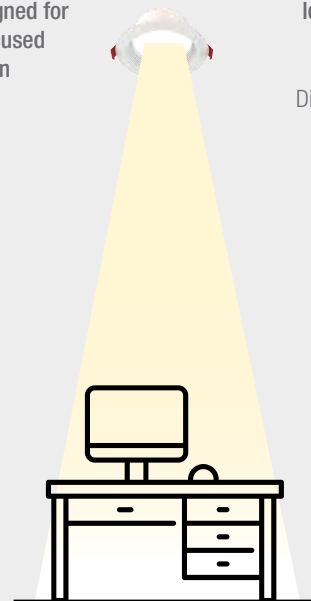

Featuring Flat Wafer™ Downlights

Private Residence

Loganville, GA





Better by Design™

Ordering Information



Wafer™ - Flat Trim										
Trim Series	Trim Style		Lumen Output		Color Temperature		Rendering Index		Finish	
WF2	2" Downlight	RD	Flat	ALO25	Adjustable Lumens (517/689/826)	SWW5	Switchable White (2700K, 3000K, 3500K, 4000K, 5000K)	90CRI	90+ CRI	MW Matte White MB Matte Black ORB Oil-Rubbed Bronze BN Brushed Nickel
WF4	4" Downlight	(blank)	Flat Smooth	(blank)	670L	SWW5	Switchable White (2700K, 3000K, 3500K, 4000K, 5000K)	90CRI	90+ CRI	
WF4	4" Downlight	(blank)	Flat Smooth	ALO25	Adjustable Lumens (700/900/1100)	SWW5	Switchable White (2700K, 3000K, 3500K, 4000K, 5000K)	90CRI	90+ CRI	
WF6	6" Downlight	(blank)	Flat Smooth	(blank)	970L	SWW5	Switchable White (2700K, 3000K, 3500K, 4000K, 5000K)	90CRI	90+ CRI	
WF6	6" Downlight	(blank)	Flat Smooth	ALO25	Adjustable Lumens (800/1050/1300)	SWW5	Switchable White (2700K, 3000K, 3500K, 4000K, 5000K)	90CRI	90+ CRI	
WF8	8" Downlight	(blank)	Flat Smooth	(blank)	1640L	SWW5	Switchable White (2700K, 3000K, 3500K, 4000K, 5000K)	90CRI	90+ CRI	
WF8	8" Downlight	(blank)	Flat Smooth	ALO42	Adjustable Lumens (1500, 1750, 1950)	SWW5	Switchable White (2700K, 3000K, 3500K, 4000K, 5000K)	90CRI	90+ CRI	

Wafer™ - Semi-Regressed Trim										
Trim Series	Trim Style		Lumen Output		Color Temperature		Rendering Index		Finish	
WF4	4" Downlight	(blank)	Flat Smooth	(blank)	650L	SWW5	Switchable White (2700K, 3000K, 3500K, 4000K, 5000K)	90CRI	90+ CRI	MW Matte White
WF6	6" Downlight	(blank)	Flat Smooth	(blank)	950L	SWW5	Switchable White (2700K, 3000K, 3500K, 4000K, 5000K)	90CRI	90+ CRI	MW Matte White

Wafer™ - Deep Regressed Trim										
Trim Series	Trim Style		Lumen Output		Color Temperature		Rendering Index		Finish	
WF2	2" Downlight	DREG SM	Deep Regressed Smooth	ALO25	Adjustable Lumens (544/725/907)	SWW5	Switchable White (2700K, 3000K, 3500K, 4000K, 5000K)	90CRI	90+ CRI	MW Matte White (Color Trim Rings Available - See Spec Sheet)
WF4	4" Downlight	DREG B	Deep Regressed Baffle	ALO25	Adjustable Lumens (544/725/907)	SWW5	Switchable White (2700K, 3000K, 3500K, 4000K, 5000K)	90CRI	90+ CRI	
WF4	4" Downlight	DREG SM	Deep Regressed Smooth	ALO19	Adjustable Lumens (700/900/1100)	SWW5	Switchable White (2700K, 3000K, 3500K, 4000K, 5000K)	90CRI	90+ CRI	
WF6	6" Downlight	DREG B	Deep Regressed Baffle	ALO19	Adjustable Lumens (700/900/1100)	SWW5	Switchable White (2700K, 3000K, 3500K, 4000K, 5000K)	90CRI	90+ CRI	
WF6	6" Downlight	DREG SM	Deep Regressed Smooth	ALO20	Adjustable Lumens (800/1050/1300)	SWW5	Switchable White (2700K, 3000K, 3500K, 4000K, 5000K)	90CRI	90+ CRI	

Wafer™ - Square Trim										
Trim Series	Trim Style		Lumen Output		Color Temperature		Rendering Index		Finish	
WF4	4" Downlight	(blank)	Flat Smooth	ALO19	Adjustable Lumens (700/900/1100)	SWW5	Switchable White (2700K, 3000K, 3500K, 4000K, 5000K)	90CRI	90+ CRI	MW Matte White
WF6	6" Downlight	(blank)	Flat Smooth	ALO20	Adjustable Lumens (800/1050/1300)	SWW5	Switchable White (2700K, 3000K, 3500K, 4000K, 5000K)	90CRI	90+ CRI	MW Matte White

Wafer™ - Adjustable										
Trim Series	Trim Style		Lumen Output		Color Temperature		Rendering Index		Finish	
WF4	4" Downlight	(ADJ)	Adjustable	(blank)	729L	SWW5	Switchable White (2700K, 3000K, 3500K, 4000K, 5000K)	90CRI	90+ CRI	MW Matte White MB Matte Black BN Brushed Nickel
WF6	6" Downlight	(ADJ)	Adjustable	(blank)	1007L	SWW5	Switchable White (2700K, 3000K, 3500K, 4000K, 5000K)	90CRI	90+ CRI	

Accessories									
Series									
2-inch			4-inch			6-inch			
2NCMFLP U	2in New Construction Mounting Frame with Lip		WF8643 PAN U	Universal New Construction Pan		WF8643 PAN U	Universal New Construction Pan		
2NCMFLP R6	2in New Construction Mounting Frame with Lip, Retail Pack of 6		WF4 PAN R12	4" New Construction Pan, Retail Pack of 12		WF4 PAN R12	4" New Construction Pan, Retail Pack of 12		
WFJB U	Remodel Joist Bar		WF4GR MW JZ	4" Goof Ring		WF4GR MW JZ	4" Goof Ring		
WFEXC6 SW3PIN FT4	3-Pin 6FT Cable		WFJB U	Remodel Joist Bar		WFJB U	Remodel Joist Bar		
WFEXC10 SW3PIN FT4	3-Pin 10FT Cable		WFEXC6 SW3PIN FT4	3-Pin 6FT Cable		WFEXC6 SW3PIN FT4	3-Pin 6FT Cable		
WFEXC20 SW3PIN FT4	3-Pin 20FT Cable		WFEXC10 SW3PIN FT4	3-Pin 10FT Cable		WFEXC10 SW3PIN FT4	3-Pin 10FT Cable		
WF2GR MW JZ	2" Wafer Goof Ring 2.75" ID x 4.75" OD		WFEXC20 SW3PIN FT4	3-Pin 20FT Cable		WFEXC20 SW3PIN FT4	3-Pin 20FT Cable		

